
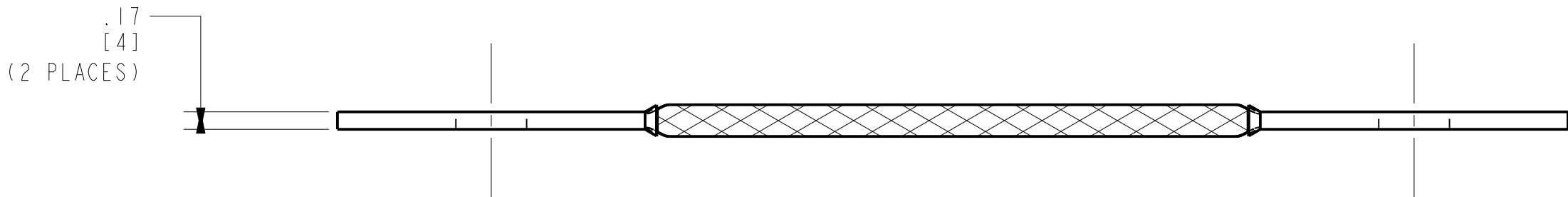
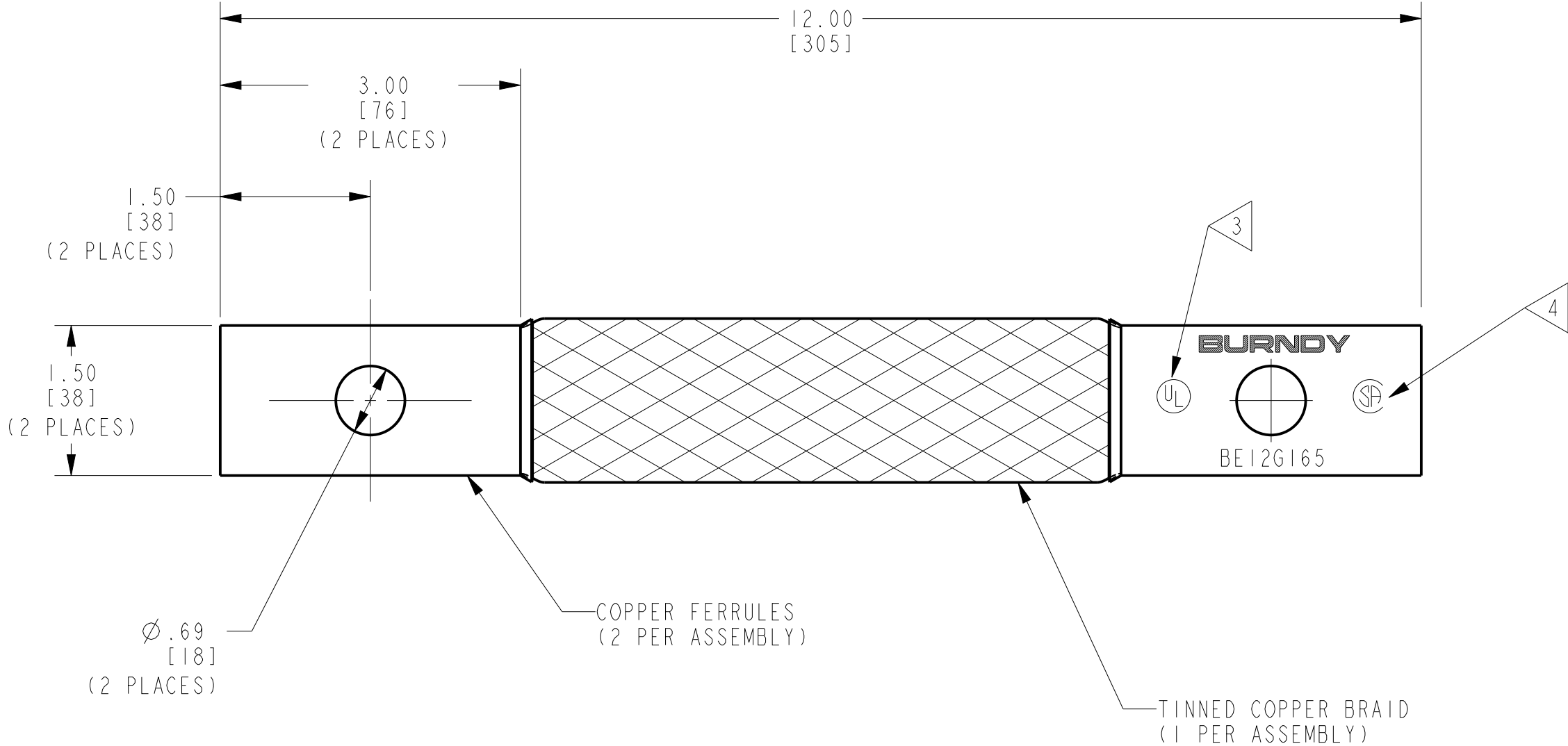


| REV | DATE                   | DESCRIPTION  | ECO   | BY | C'H'K. |
|-----|------------------------|--------------|-------|----|--------|
| B   | 05/05/2017 09:20:00 AM | LOGO UPDATED | 46677 | SM | MB     |

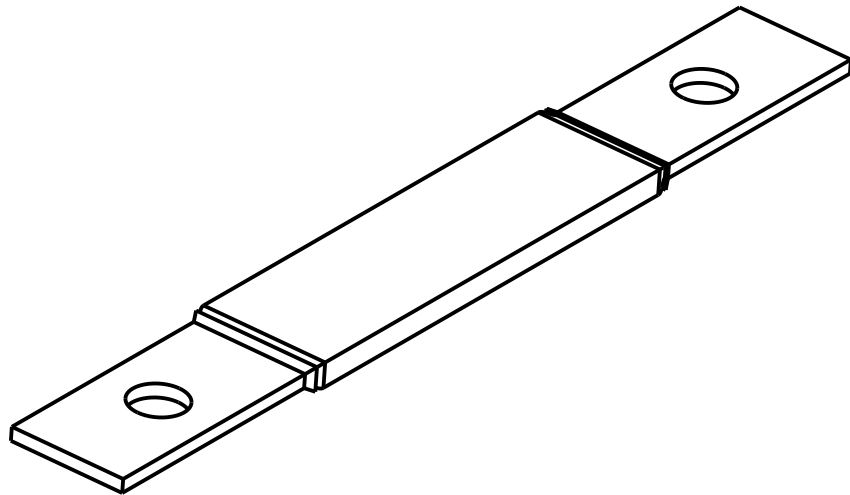

NOTES:

- DIMENSIONS IN BRACKETS [ ] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED, AND ARE FOR REFERENCE ONLY.
- APPROXIMATE AMP RATING: 340 INDOOR, 405 OUTDOOR  
THIS MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID AND OTHER SERVICE CONDITIONS.
- 'UL' SYMBOL FOR INTERNAL SPECIFICATION L4219, LOCATION AND SIZE TO BE DETERMINED BY MANUFACTURING.
- 'CSA' SYMBOL PER INTERNAL SPECIFICATION L4591, LOCATION AND SIZE TO BE DETERMINED BY MANUFACTURING.

TO ORDER BURNDY® PRODUCTS CALL  
UNITED STATES:  
1-800-346-4175 (LONDONDERRY, NH)

CANADA:  
1-800-361-6975 (QUEBEC)  
1-800-387-6487 (ALL OTHER PROVINCES)

FOR PRODUCT INFO: <http://www.burndy.com>

BRAID

ITEM NO: 10102098

CAT. NO: BE12G165

|            |             |          |
|------------|-------------|----------|
| DRAWN BY:  | R. BOISVERT | 09/09/09 |
| CHECKER:   | J. PARKER   | 09/10/09 |
| DSN APPVL: | J. PARKER   | 08/20/09 |
| MFG APPVL: | C. MARTINEZ | 09/03/09 |
| QA APPVL:  | J. BRODEUR  | 09/01/09 |
| MKT APPVL: | P. THERRIEN | 08/20/09 |

**BURNDY**

|                |          |            |     |
|----------------|----------|------------|-----|
| PROD FAM:      | --       | DRAWING NO | REV |
| PROJECT #:     | --       | SIZE       |     |
| DOCUMENT TYPE: | Sales    | C          | B   |
| REL LEVEL:     | Released |            |     |