


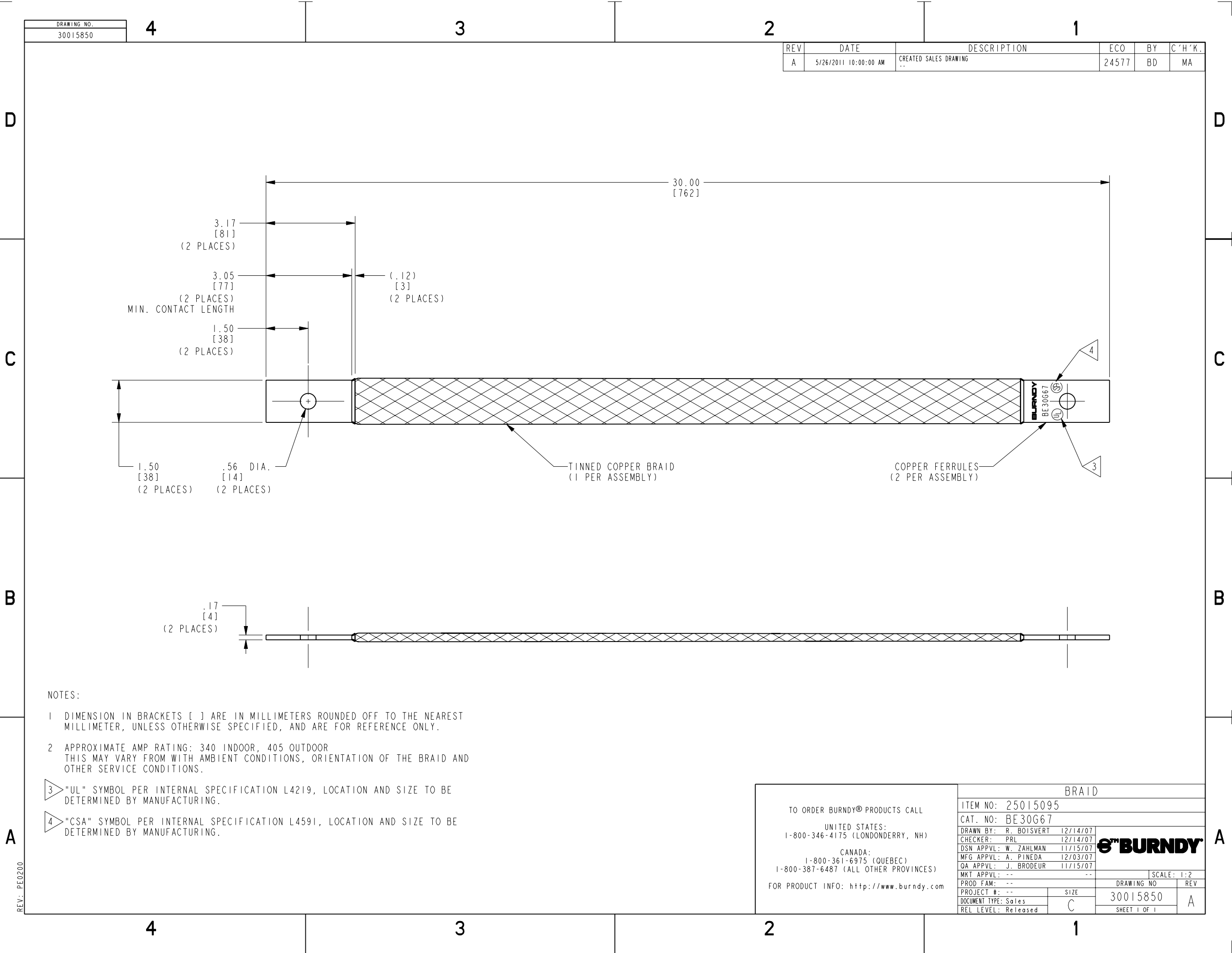

NOTES:

- 1 DIMENSION IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED, AND ARE FOR REFERENCE ONLY.
- 2 APPROXIMATE AMP RATING: 340 INDOOR, 405 OUTDOOR
THIS MAY VARY FROM WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID AND OTHER SERVICE CONDITIONS.
- 3 "UL" SYMBOL PER INTERNAL SPECIFICATION L4219, LOCATION AND SIZE TO BE DETERMINED BY MANUFACTURING.
- 4 "CSA" SYMBOL PER INTERNAL SPECIFICATION L4591, LOCATION AND SIZE TO BE DETERMINED BY MANUFACTURING.

REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
A	5/26/2011 10:00:00 AM	CREATED SALES DRAWING	24577	BD	MA

TO ORDER BURNDY® PRODUCTS CALL		BRAID	
UNITED STATES:		ITEM NO: 25015095	
1-800-346-4175 (LONDONDERRY, NH)		CAT. NO: BE30G67	
CANADA:		DRAWN BY: R. BOISVERT 12/14/07	
1-800-361-6975 (QUEBEC)		CHECKER: PRL 12/14/07	
1-800-387-6487 (ALL OTHER PROVINCES)		DSN APPVL: W. ZAHLMAN 11/15/07	
FOR PRODUCT INFO: http://www.burndy.com		MFG APPVL: A. PINEDA 12/03/07	
		QA APPVL: J. BRODEUR 11/15/07	
		MKT APPVL: --	
		SCALE: 1:2	
		PROD FAM: --	DRAWING NO
		PROJECT #: --	30015850
		DOCUMENT TYPE: Sales	REV
		REL LEVEL: Released	A