


## BFB640T58

by Burndy

Catalog ID: BFB640T58

Industry-exclusive Compression Solution for flexible Bus Bar Applications

- Industry Exclusive! Only offered by BURNDY®
- Eliminates the need to drill through copper sheets, ensuring a cleaner, faster installation
- Full inspectability with the BURNDY® Engineered System
- 1-hole and 2-hole options available to accommodate spacing requirements
- Most flexible bus bar sizes accommodated
- Locator lines on terminals provide for accurate and consistent crimping
- UL Recognized to UL67 for Panelboard Equipment

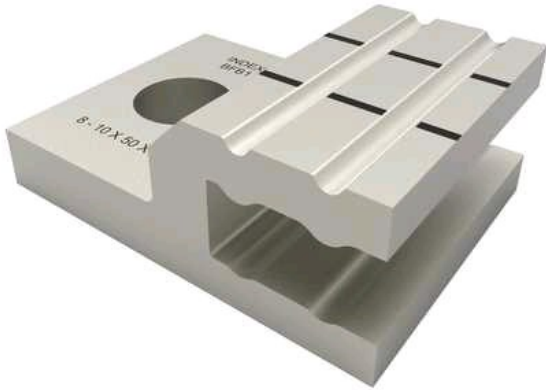

## Product Details

### General

|                 |                                                                                                     |
|-----------------|-----------------------------------------------------------------------------------------------------|
| Application     | Typically used in panelboards, switchboards, transformers, control panels, and similar applications |
| Number of Holes | 1                                                                                                   |
| UPC             | 621945526884                                                                                        |

### Dimensions

|                            |         |
|----------------------------|---------|
| Dimension - Stud Size inch | 5/8 in  |
| Height                     | 1.58 in |
| Length                     | 2.75 in |

### Logistics

|                       |   |
|-----------------------|---|
| Minimum Pack Quantity | 1 |
|-----------------------|---|

**For further technical assistance, please contact us**

**BURNDY Headquarters**  
47 East Industrial Park Drive  
Manchester, New Hampshire 03109

**Customer Service Hours:**  
8 AM - 8 PM Eastern Monday-Friday  
Emergency Service 24-hours/365 Days  
Phone: 1-800-346-4175  
1-603-647-5299 (International)