
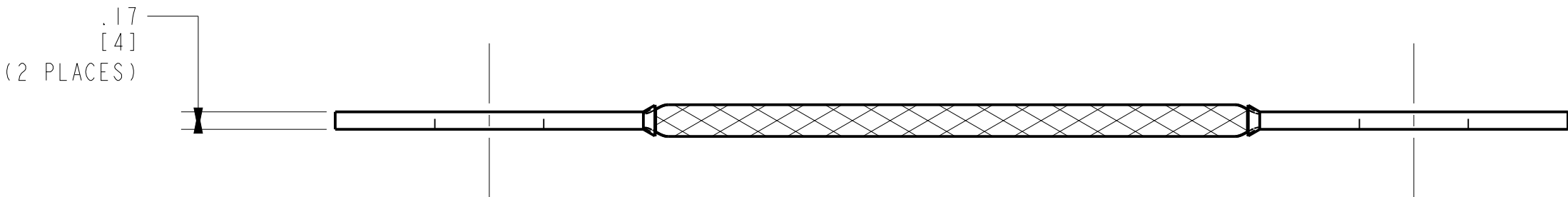
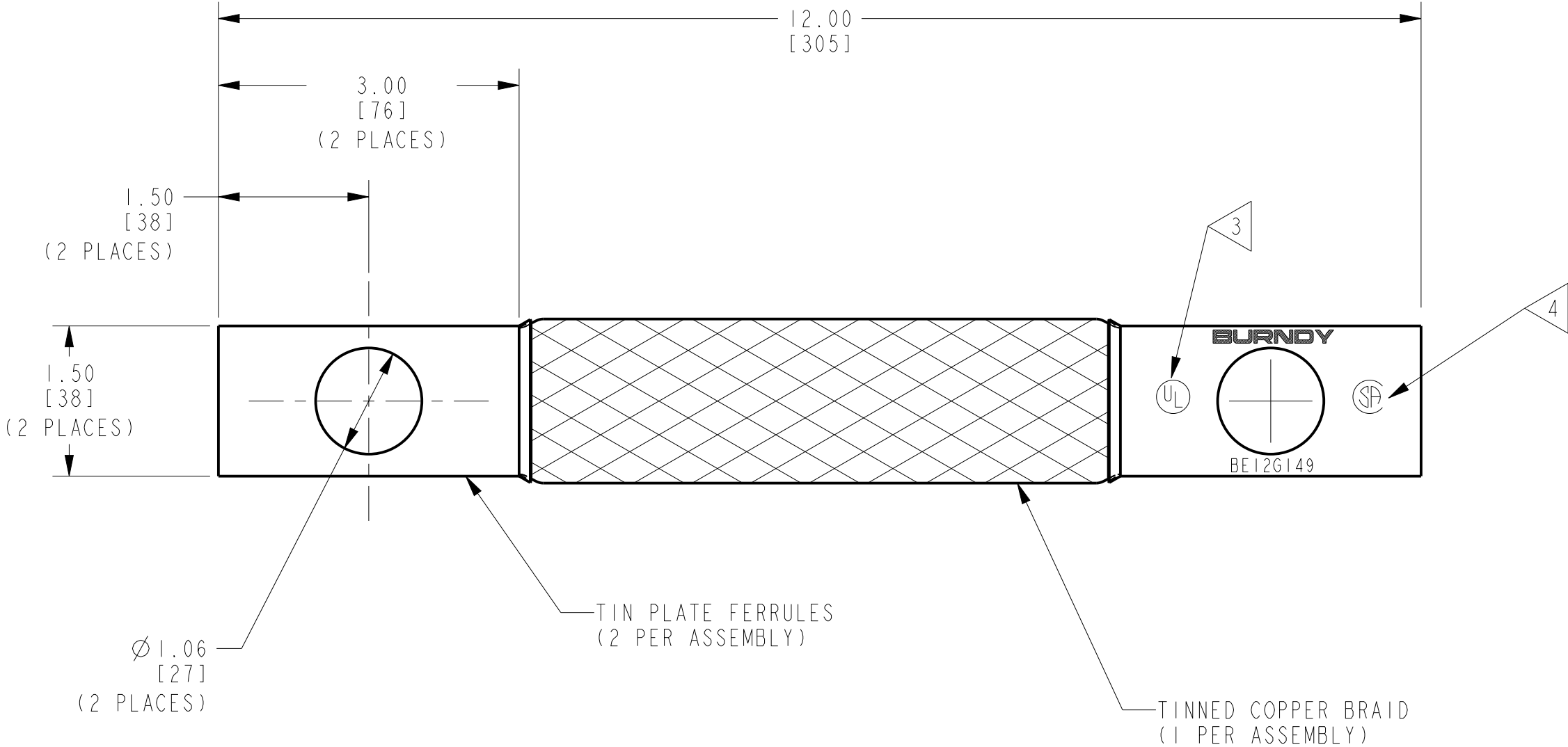


REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
B	05/05/2015 09:20:00 AM	LOGO UPDATED	46677	SM	MB

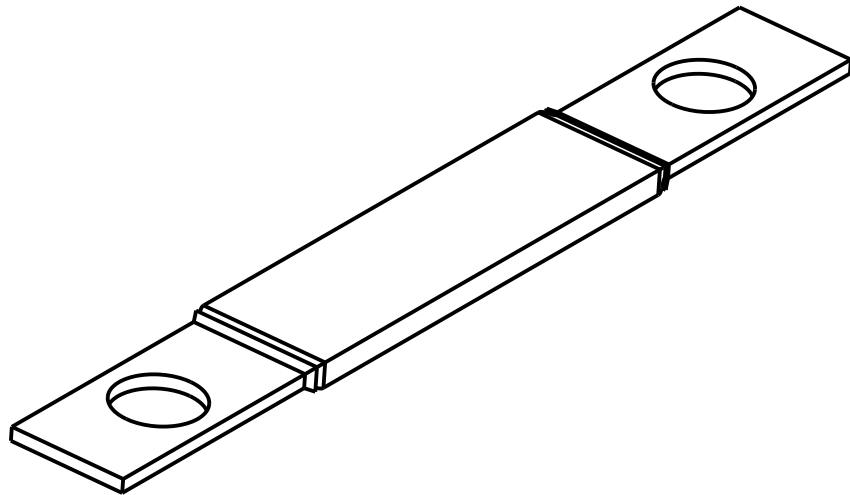

NOTES:

- DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED, AND ARE FOR REFERENCE ONLY.
- APPROXIMATE AMP RATING: 340 INDOOR, 405 OUTDOOR
THIS MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID AND OTHER SERVICE CONDITIONS.
- 'UL' SYMBOL FOR INTERNAL SPECIFICATION L4219, LOCATION AND SIZE TO BE DETERMINED BY MANUFACTURING.
- 'CSA' SYMBOL PER INTERNAL SPECIFICATION L4591, LOCATION AND SIZE TO BE DETERMINED BY MANUFACTURING.

TO ORDER BURNDY® PRODUCTS CALL UNITED STATES: 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES) FOR PRODUCT INFO: http://www.burndy.com		BRAID	
		ITEM NO: 10039704	
		CAT. NO: BE12G149	
		DRAWN BY: R. BOISVERT	09/09/09
		CHECKER: J. PARKER	09/10/09
		DSN APPVL: J. PARKER	08/20/09
		MFG APPVL: C. MARTINEZ	09/03/09
		QA APPVL: J. BRODEUR	09/01/09
		MKT APPVL: P. THERRIEN	08/20/09
		PROD FAM: --	SCALE: 3:4
		PROJECT #: --	DRAWING NO
		DOCUMENT TYPE: Sales	REV
		REL LEVEL: Released	

