


REV.	DATE	DESCRIPTION	ECO	BY	C.H.K.
B	05/08/2017 00:00:00 AM	LOGO UPDATED	46696	CV	MB

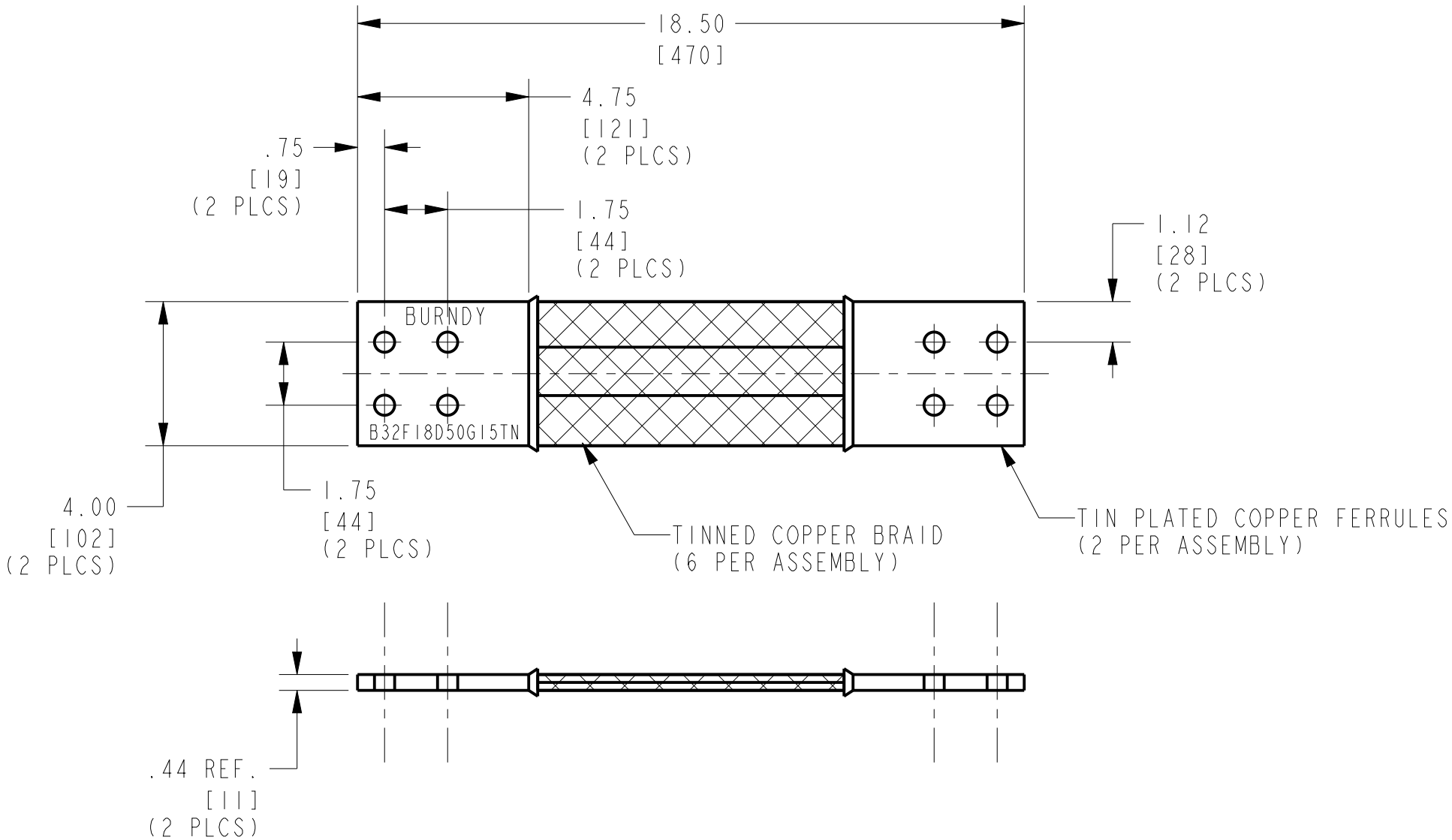

NOTES:

- APPROXIMATE AMP RATING: 1,500
THIS RATING MAY VARY WITH AMBIENT CONDITIONS,
ORIENTATION OF THE BRAID AND OTHER SERVICE CONDITIONS.
- DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS
ROUNDED OFF TO THE NEAREST MILLIMETER,
UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.

TO ORDER BURNDY® PRODUCTS CALL UNITED STATES: 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES) FOR PRODUCT INFO: http://www.burndy.com		BRAID, FLEXIBLE	
		ITEM NO: 10043751	
		CAT. NO: B32F18D50G15TN	
		DRAWN BY: R.L. BOISVERT	--
		CHECKER: P. LAPONTUS	--
		DSN APPVL: J. MICHAUD	--
		MFG APPVL: N/A	--
		QA APPVL: J. BRODEUR	--
		MKT APPVL: R. BROOKS	--
		PROD FAM: --	SCALE: 1:4
		PROJECT #: --	DRAWING NO
		DOCUMENT TYPE: Sales	10044128
		REL LEVEL: Released	B
		SIZE	B
		SHEET 1 OF 1	B