


REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
A	09/18/2012	CREATE SALES DRAWING	28743	BD	MB

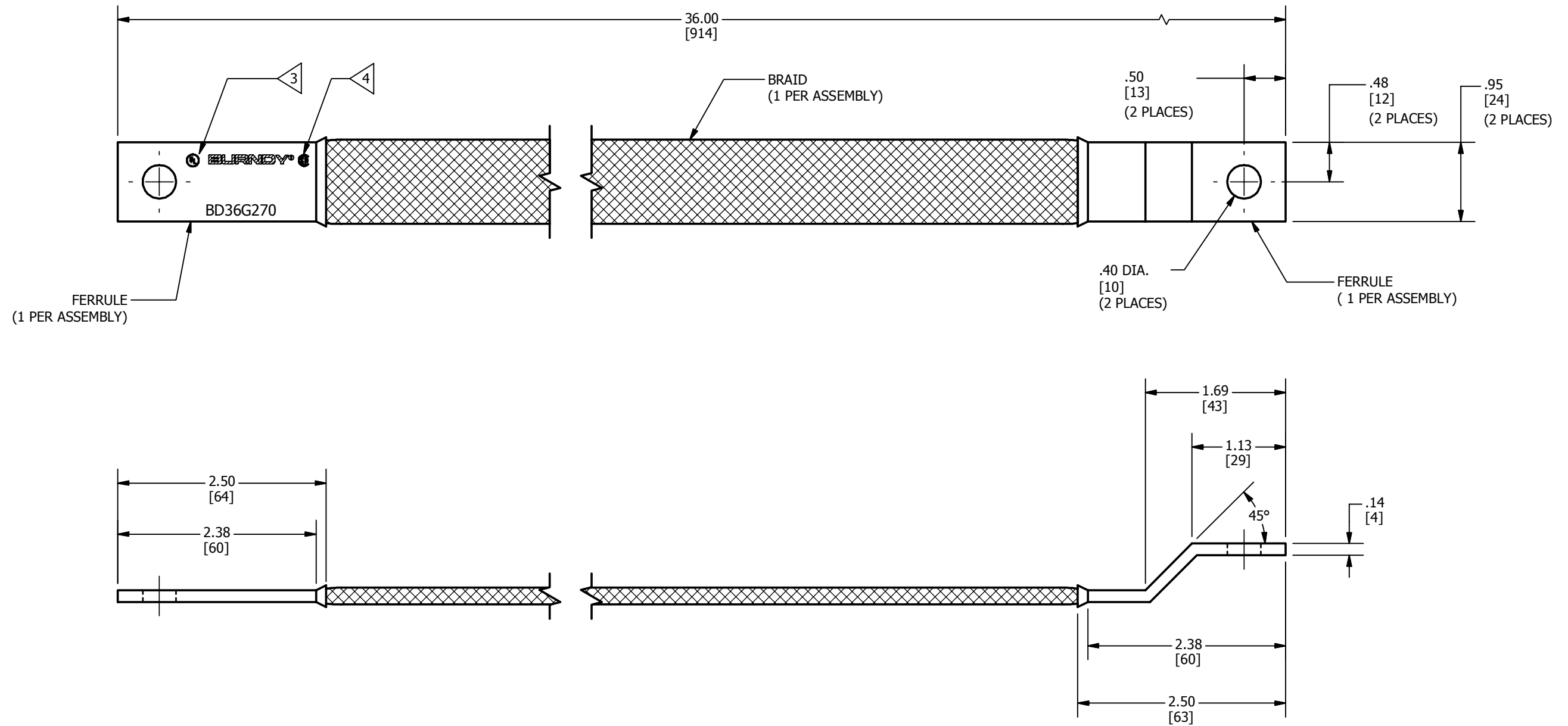

NOTES:

1. APPROXIMATE AMP RATING: 190 INDOOR, 225 OUTDOOR. THIS RATING MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID, AND OTHER SERVICE CONDITIONS.
2. DIMENSIONS IN BRACKETS [ ] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.

3 > BRAID IS LISTED TO UL 467 GROUNDING & BONDING EQUIPMENT STANDARDS.

4 > BRAID IS LISTED TO CSA 22.2 NO.41 GROUNDING & BONDING EQUIPMENT STANDARDS.

TO ORDER BURNDY PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)  CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES)  FOR PRODUCT INFO: <a href="http://www.burndy.com">http://www.burndy.com</a>		BRAID FOR GROUND SHIELD CONNECTOR	
		ITEM NO: 50008592	
		CAT. NO: BD36G270	
		DRAWN BY: B.DURATCHAMY	9/24/2012
		CHECKER: R.CRUZ	9/29/2012
		DSN APRVL: E.MARTIN	9/28/2012
		MFG APRVL: --	--
		QA APRVL: J.MEDINA	10/27/2012
		MKT APRVL: K.ROBICHEAU	9/28/2012
		PROD FAM: MECHANICAL GROUNDING	
		PROJECT #:	SIZE
		DOCUMENT TYPE: SALES	
		REL LEVEL: Released	
		DRAWING NO	REV
		50008593	A
		SHEET 1 OF 1	