



SIGNAL REFERENCE GRID WIRE CLAMP, #8 STRANDED-#4 STRANDED

CATALOG NUMBER

RGC



FEATURES

Provides a quick method to support a signal grid to computer floor pedestals

Slots in fastener grip wire to provide positive contact with post

Clamps grid wire directly to post allowing a low resistance connection across bare metal contacts

Installs easily with a screwdriver or nut driver

PRODUCT ATTRIBUTES

Material: Steel

Finish: Electrogalvanized

Conductor Size: #8 Stranded - #4 Stranded


Diameter 1: 3/4" – 1"

Diameter 2: 0.146" – 0.280"

ADDITIONAL PRODUCT DETAILS

RGC can be installed on 3/4" to 1" round or square pedestals.

DIAGRAMS

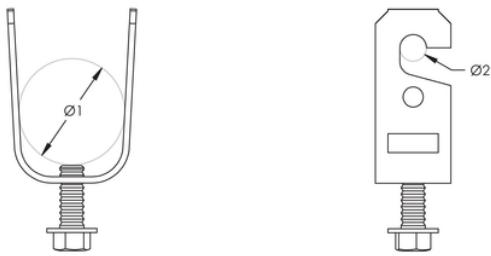

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER