

SIDE COVER

SPECIFICATIONS

- Attach to enclosure frame with low-profile, flat head screws
- Door can be reversed without removing the side covers
- Used on the sides of the PROLINE G2 frame
- Depths greater than 800 mm are 14 gauge (1.75 mm) mild steel; depths less than or equal to 800 mm are 16 gauge (1.5 mm)
- Not suitable as a barrier between enclosures (instead use the PROLINE G2 barrier panel)
- Two grounding studs
- All mounting hardware included

FINISH

- Polyester powder paint; RAL 7035 textured light gray standard
- Custom colors available

LOAD RATING

- 300/136kg, safety factor 1.5; frame size: 2000x600x800 mm (load ratings vary by frame size)

ACCESSORIES

- Support Bracket Kit

BULLETIN: P40
APPLICATION


PROLINE G2 Solid Sides enclose the open sides of the modular enclosure frame and have innovative design elements incorporated to ensure fast installation and enhanced structural support.

FEATURES

- Hinge hanger on top for easy alignment
- Formed steel hems on the sides of the covers for enhanced structural support and to protect user from sharp edges
- Seamless polyurethane gasket (UL component recognized) provides a watertight, dust-tight seal against moisture and contaminants

Standard Product

Catalog Number	H (mm)	H (in.)	W (mm)	W (in.)	Gauge	Fits Frame HxW (mm)
P2CS64	583	23.0	364	14.3	16	600x400
P2CS66	583	23.0	564	22.2	16	600x600
P2CS68	583	23.0	764	30.1	16	600x800
P2CS84	783	30.8	364	14.3	16	800x400
P2CS86	783	30.8	564	22.2	16	800x600
P2CS88	783	30.8	764	30.1	16	800x800
P2CS104	983	38.7	364	14.3	16	1000x400
P2CS105	983	38.7	464	18.3	16	1000x500
P2CS106	983	38.7	564	22.2	16	1000x600
P2CS108	983	38.7	764	30.1	16	1000x800
P2CS124	1183	46.6	364	14.3	16	1200x400
P2CS125	1183	46.6	464	18.3	16	1200x500
P2CS126	1183	46.6	564	22.2	16	1200x600
P2CS128	1183	46.6	764	30.1	16	1200x800
P2CS145	1383	54.4	464	18.3	16	1400x500
P2CS146	1383	54.4	564	22.2	16	1400x600
P2CS164	1583	62.3	364	14.3	16	1600x400
P2CS165	1583	62.3	464	18.3	16	1600x500
P2CS166	1583	62.3	564	22.2	16	1600x600
P2CS168	1583	62.3	764	30.1	16	1600x800
P2CS184	1783	70.2	364	14.3	16	1800x400
P2CS185	1783	70.2	464	18.3	16	1800x500
P2CS186	1783	70.2	564	22.2	16	1800x600
P2CS204	1983	78.1	364	14.3	16	2000x400
P2CS205	1983	78.1	464	18.3	16	2000x500
P2CS206	1983	78.1	564	22.2	16	2000x600
P2CS2010	1983	78.1	964	38.0	14	2000x1000
P2CS224	2183	85.9	364	14.3	16	2200x400
P2CS225	2183	85.9	464	18.3	16	2200x500
P2CS226	2183	85.9	564	22.2	16	2200x600
P2CS2210	2183	85.9	964	38.0	14	2200x1000

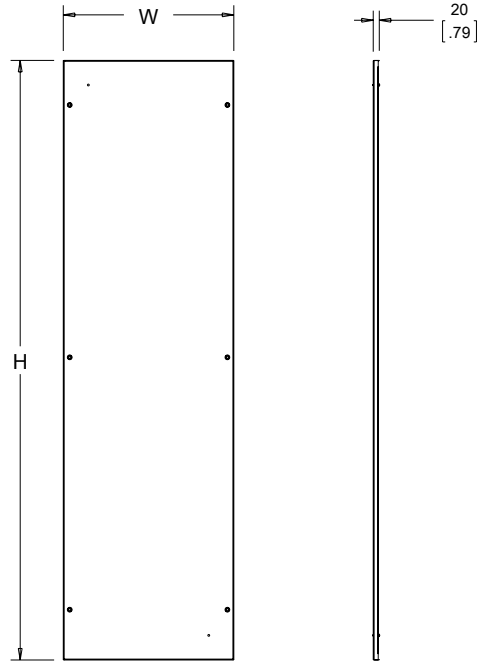

89129478

Model	Component	Type	Height	Depth	Specialty	Catalog Number
P2	C	S	20	6	Blank	= P2CS206
PROLINE G2	Cover	Blank = cover S = side cover B = barrier panel	mm 22 = 2200 20 = 2000 18 = 1800 16 = 1600 14 = 1400 12 = 1200 10 = 1000 8 = 800 6 = 600	mm 10 = 1000 8 = 800 6 = 600 5 = 500 4 = 400	Blank = standard HF = EMC protected	

NOTE: Not every combination is available as a standard product.