


## DRESS FRAME

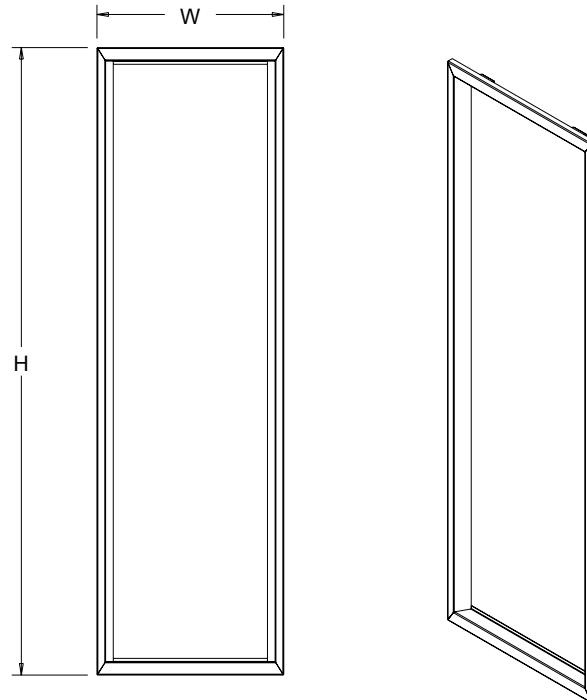

89129480

### APPLICATION

A PROLINE G2 Dress Frame provides a decorative trim when a front door or cover is not used. It is frequently used for open rack applications.

### SPECIFICATIONS

- Provides a clean, finished aesthetic for open rack applications
- Snap-in design for easy, tool-free installation

### FINISH

- Polyester powder paint; RAL 7035 textured light gray standard
- Custom colors available

### ACCESSORIES

- 19-Inch Rack Angles
- Rack Panels
- Rack-Mount Fixed Shelf
- Rack Mount Pull-Out Shelf
- Guides
- Slides
- Rack-Angle Mounted Drawer
- Writing Surface

### BULLETIN: P40

Standard Product

Catalog Number	H (mm)	H (in.)	W (mm)	W (in.)	Fits Frame Height x Width mm
P2DF126	1192	46.9	593	23.4	1200x600
P2DF146	1392	54.8	593	23.4	1400x600
P2DF148	1392	54.8	793	31.2	1400x800
P2DF166	1592	62.7	593	23.4	1600x600
P2DF168	1592	62.7	793	31.2	1600x800
P2DF186	1792	70.6	593	23.4	1800x600
P2DF188	1792	70.6	793	31.2	1800x800
P2DF206	1992	78.4	593	23.4	2000x600
P2DF208	1992	78.4	793	31.2	2000x800
P2DF226	2192	86.3	593	23.4	2200x600
P2DF228	2192	86.3	793	31.2	2200x800

Model	Component	Type	Height	Width	Specialty	Catalog Number
P2	D	F	20	8	Blank	= P2DF208
PROLINE G2	Door	Blank = single door O = double door W = window door A = side door adapter DR = disconnect right DL = disconnect left DR2 = disconnect right large cutout F = dress frame	mm 22 = 2200 20 = 2000 18 = 1800 16 = 1600 14 = 1400 12 = 1200 10 = 1000 8 = 800 6 = 600 4 = 400	mm 8 = 800 6 = 600	Blank = standard HF = EMC protected	

NOTE: Not every combination is available as a standard product.

## Notes