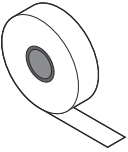

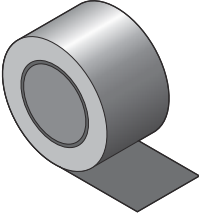



## CONNECT AND PROTECT

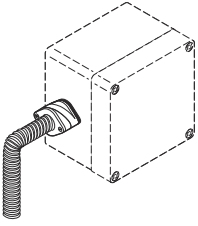
### ATTACHMENT PRODUCTS

Catalog number	Part number	Description
<b>GT-66</b> 	C77220-000	66 ft (20 m) roll of glass tape for attaching heating cable to pipe. Not for stainless steel pipes or for installation temperatures below 40°F (5°C).
<b>GS-54</b> 	C77221-000	54 ft (16.5 m) roll of glass tape for attaching heating cable to pipe. For stainless steel pipes or for any installation below 40°F (5°C).
<b>AT-180</b> 	158139-000	180 ft (55 m) roll of aluminum tape for attaching heating cables and thermostat sensors to pipes and tanks. Minimum installation temperature: 32°F (0°C). Dimensions: 2.5 in wide, 5 mils thick.
<b>Pipe straps</b> 	PS-01 C77211-000 PS-03 C77212-000 PS-10 C77213-000 PS-20 C77216-000	For conduit ≤ 1 in For connection kits on pipes with dimensions ≤ 2 in For connection kits on pipes with dimensions 2 in – 10 in For connection kits on pipes with dimensions 10 in – 19.5 in Used to secure connection kits and brackets to pipes. Order by pipe diameter, as shown above.

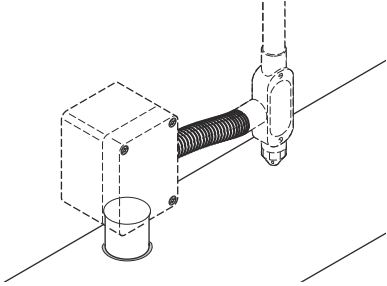
### LABELS

Catalog number	Part number	Description
<b>ETL</b> 	C77203-000	"Electric Traced" label for identifying traced pipes and tanks.

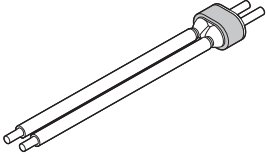
## GLAND ENTRY KIT

Catalog number	Part number	Description	Kit Contents	
			Qty	Description
<b>C75-100-A</b>	000539-000	<p>A NEMA 4X-rated gland kit used to transition heating cables into a junction box when making connections off of a pipe or tank. It may be used for power, splice, or tee connections. For use with nVent RAYCHEM brand BTV, QTVR, XTV, KTV<sup>(1)</sup>, HTV, VPL, and LBTV2-CT<sup>(2)</sup> heating cables. The kit does not include the junction box, flexible tubing, or tape that are required to make a complete connection.</p> <p>(1) For KTV only, order PMK-GP-10 grommet (P/N 700823)</p> <p>(2) For LBTV2-CT only, order HCS-100-A heat-shrink core sealer (P/N 257649) and PMK-GK-10 grommet (P/N 222724)</p>	1	Red grommet
			1	Gland with threaded inserts
			1	Gland with screws
			1	Gland gasket
			1	Locknut
			1	Green / yellow tube
			1	CS-100 core sealer
			1	Terminal block

 
## SINGLE-ENTRY TRANSITION KIT

Catalog number	Part number	Description	Kit Contents	
			Qty	Description
<b>JS-100-A</b>	166639-000	<p>Junction box stand for use with nVent RAYCHEM brand BTV, QTVR, XTV, KTV, HTV and VPL heating cables. A separate customer-supplied NEMA 4X junction box is required.</p>	1	Stand assembly
			1	Lubricant
			1	Adapter for small pipes
			1	Cable tie
			1	Green / yellow tube
			1	CS-100 cold-applied core sealer
			1	JS-100 transition
			1	1-inch locknut


 
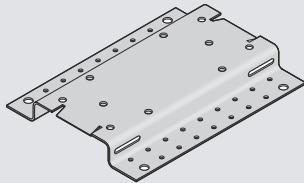
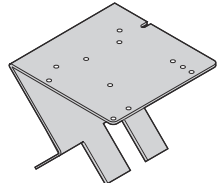
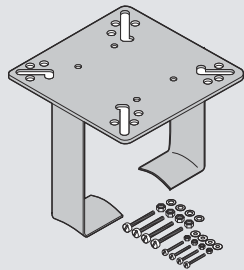
## COLD-APPLIED CORE SEALER

Catalog number	Part number	Description
<b>CS-100-A</b>	232949-000	Replacement cold-applied core sealer for nVent RAYCHEM brand BTV, QTVR, XTV, KTV, HTV and VPL heating cables
		

 
## CONDUIT DRAIN

Catalog number	Part number	Description
<b>JB-DRAIN-PLUG-3/4IN</b>	278621-000	nVent recommends the use of this 3/4-in conduit drain with each JBS-100 and JBM-100, and other enclosures with associated conduits, to prevent condensate from collecting in the box.
		

## BRACKETS, ADAPTERS

Catalog number	Part number	Description
<b>JBS-SPA</b> 	E90515-000	Adapter for mounting E-100, JBS-100, and JS-100 to small pipe ( $\leq 1$ inch nominal diameter).
<b>JBM-SPA</b> 	D55673-000	Adapter for mounting JBM-100 and T-100 to small pipe ( $\leq 1$ inch nominal diameter).
<b>SB-100-T</b> 	279613-000	Adapter for mounting E-100, E-100-L, and JBS-100 connection kits on a tank surface.
<b>UMB</b> 	263757-000	Universal mounting bracket for mounting thermostats and other equipment on a pipe.
<b>JB-SB-25</b> 	471139-000	Stainless-steel mounting bracket for RAYSTAT-EX-03-A thermostat.

## HELICAL FLEXIBLE PLASTIC TUBING

Catalog number	Part number	Description
<b>HCTE-1000</b> 	3679754004	Helical flexible plastic tubing for C75-100-A and HAK-C-100 connection kits.

**North America**

Tel +1.800.545.6258  
Fax +1.800.527.5703  
thermal.info@nVent.com

**Europe, Middle East, Africa**

Tel +32.16.213.511  
Fax +32.16.213.604  
thermal.info@nVent.com

**Asia Pacific**

Tel +86.21.2412.1688  
Fax +86.21.5426.3167  
cn.thermal.info@nVent.com

**Latin America**

Tel +1.713.868.4800  
Fax +1.713.868.2333  
thermal.info@nVent.com



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**