



LED PAR30 S/L

10PAR30L/LED/830/F40/DIM/ULW/120V 6/1FB

Philips LED spots with a single optic beam, provide a clean beam that's free from shadows with beam angles from 15 and 40 degrees to suit every general lighting application.

Product data


General information		Starting Time (Nom)	
Cap-Base	E26 [Single Contact Medium Screw]		0.5 s
EU RoHS compliant	Yes	Warm Up Time to 60% Light (Nom)	0.5 s
Nominal Lifetime (Nom)	25000 h	Power Factor (Nom)	0.9
Switching Cycle	25000X	Voltage (Nom)	120 V
Technical Type	10-75W		
Light technical		Temperature	
Color Code	830 [CCT of 3000K]	T-Case Maximum (Nom)	67 °C
Beam Angle (Nom)	40 °		
Luminous Flux (Nom)	850 lm	Controls and dimming	
Luminous Intensity (Nom)	1600 cd	Dimmable	Yes
Color Designation	White (WH)		
Correlated Color Temperature (Nom)	3000 K	Mechanical and housing	
Luminous Efficacy (rated) (Nom)	85.00 lm/W	Bulb Finish	Clear
Color Consistency	<6	Bulb Material	Glass
Color Rendering Index (Nom)	80	Bulb Shape	PAR30L [PAR 3.75 inch/95mm Long]
LLMF At End Of Nominal Lifetime (Nom)	70 %		
Operating and electrical		Approval and application	
Input Frequency	50 to 60 Hz	Suitable For Accent Lighting	Yes
Power (Nom)	10 W	Energy Consumption kWh/1000 h	- kWh
Lamp Current (Nom)	86 mA		
Wattage Equivalent	75 W	Product data	
		Order product name	10PAR30L/LED/830/F40/DIM/ULW/120V
			6/1FB
		EAN/UPC - Product	046677529741

LED PAR30 S/L

Order code	929001322104
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929001322104

Net Weight (Piece)	0.285 kg
--------------------	----------


Dimensional drawing

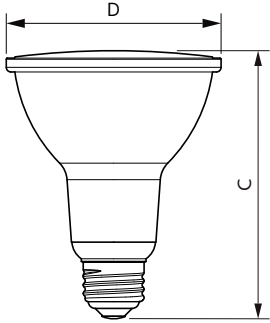


10PAR30L/LED/830/F40/DIM/ULW/120V 6/1FB

Product	D	C
10PAR30L/LED/830/F40/DIM/ULW/120V 6/1FB	94 mm	118 mm


Photometric data

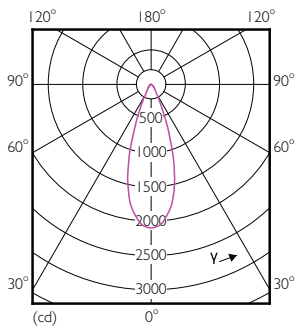

10-75W E26 PAR30L 40D 830 3000K

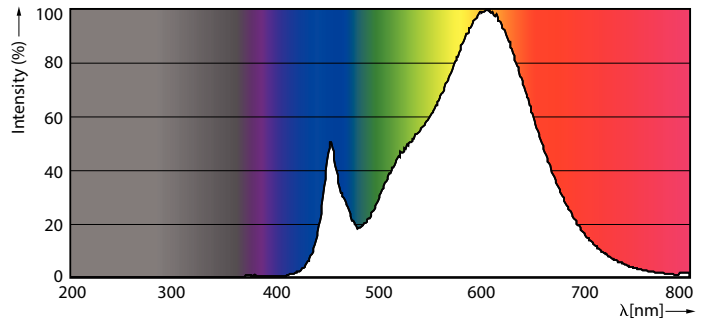


10-75W E26 PAR30L

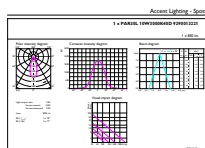

10-75W E26 PAR30L 40D 830 3000K

LED PAR30 S/L

Lifetime

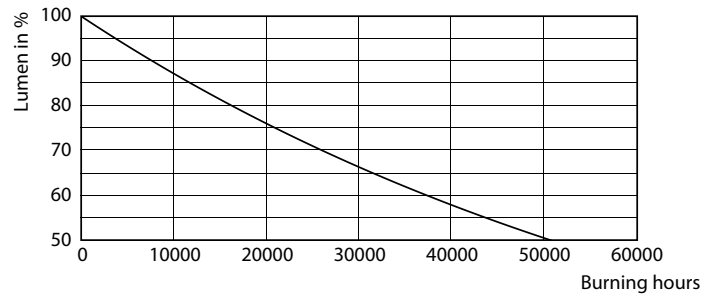

14-120W E26 PAR38

14-120W E26 PAR38

