
 
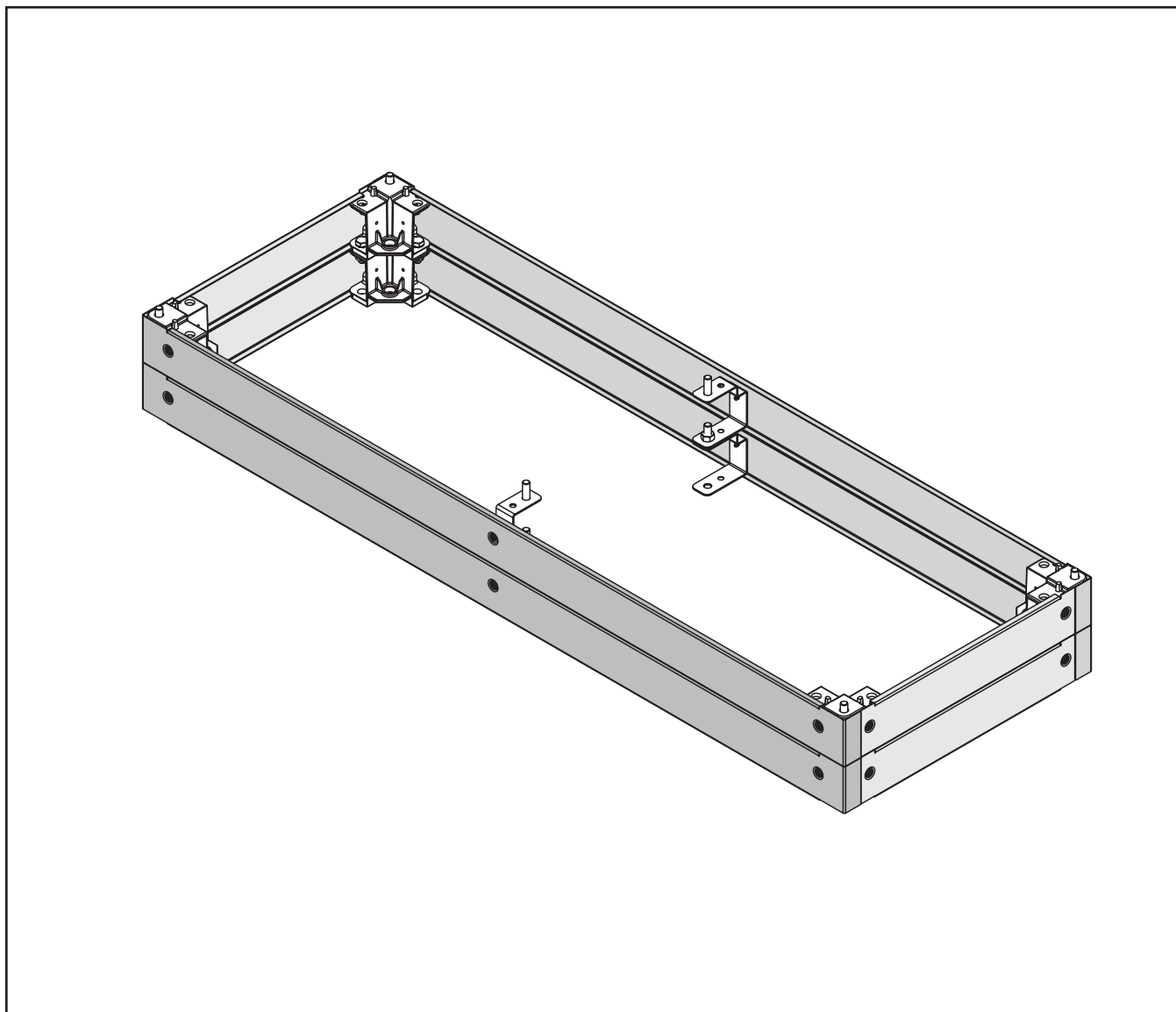

 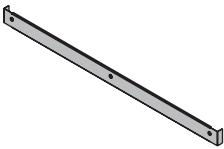
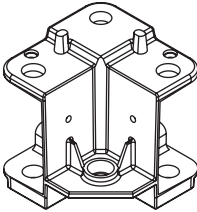
 
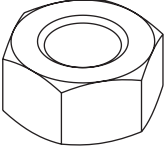

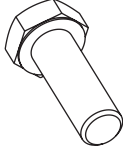






PROLINE G2

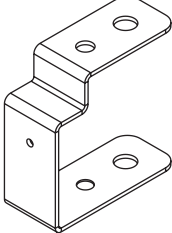

1  (4x)	2  (4x)	3  (8x)
4 M5X10  (20x)	5 M12  (10x)	6 M12  (16x)
7 M12X35  (16x)	8  (4x)	

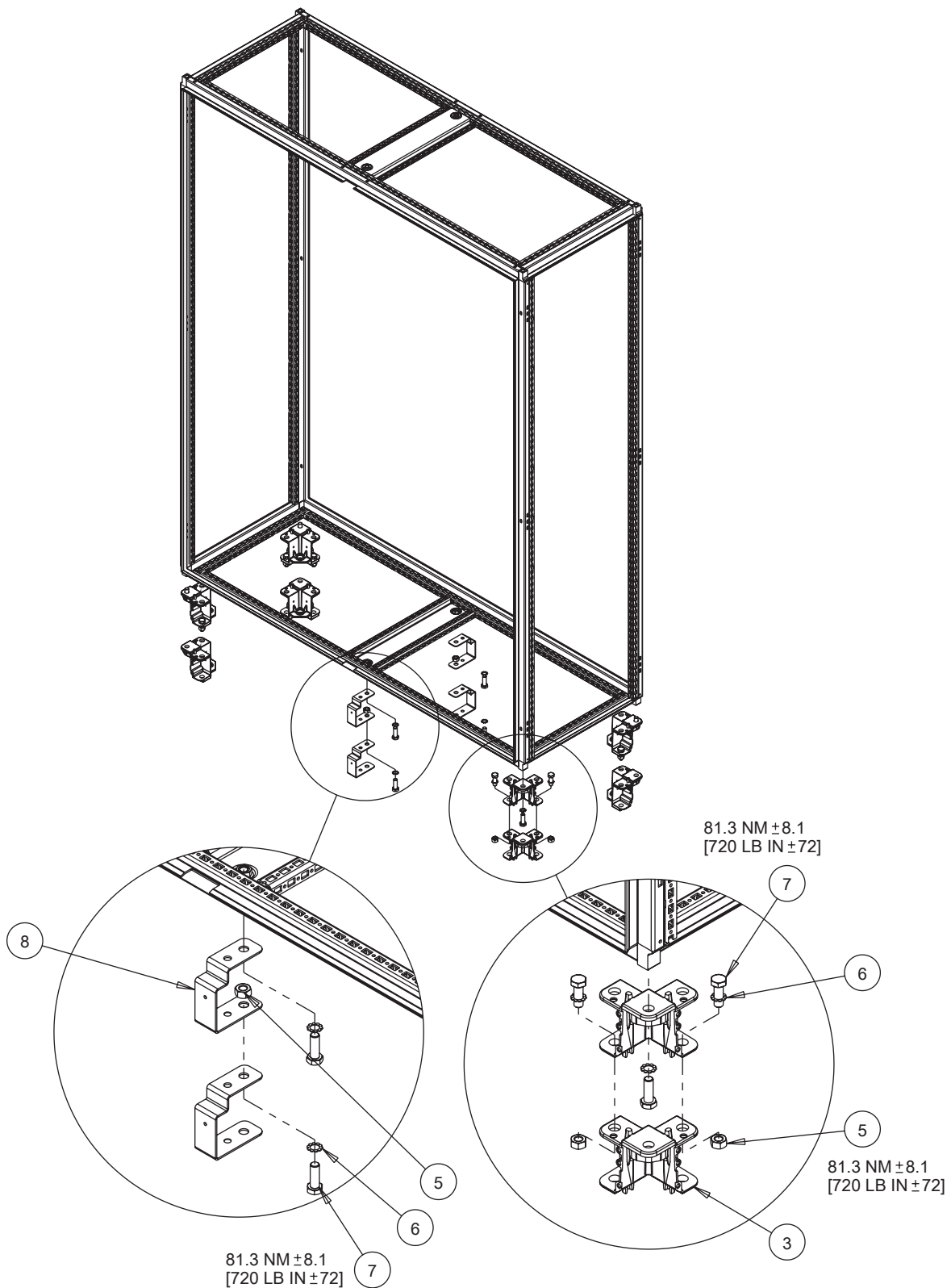


1

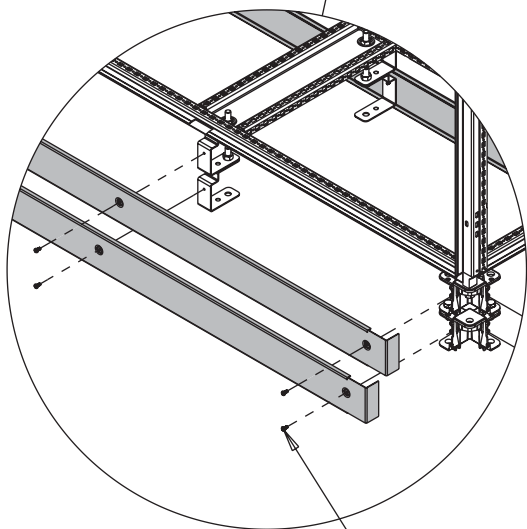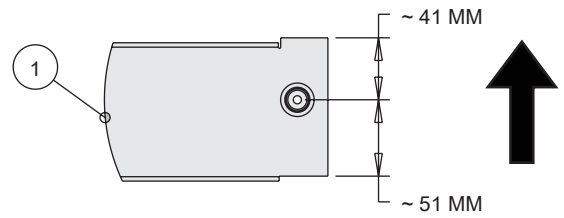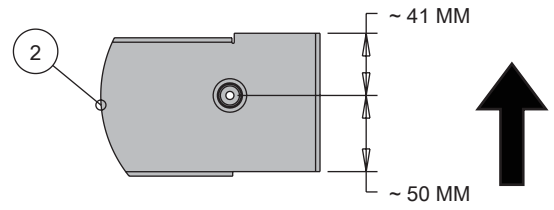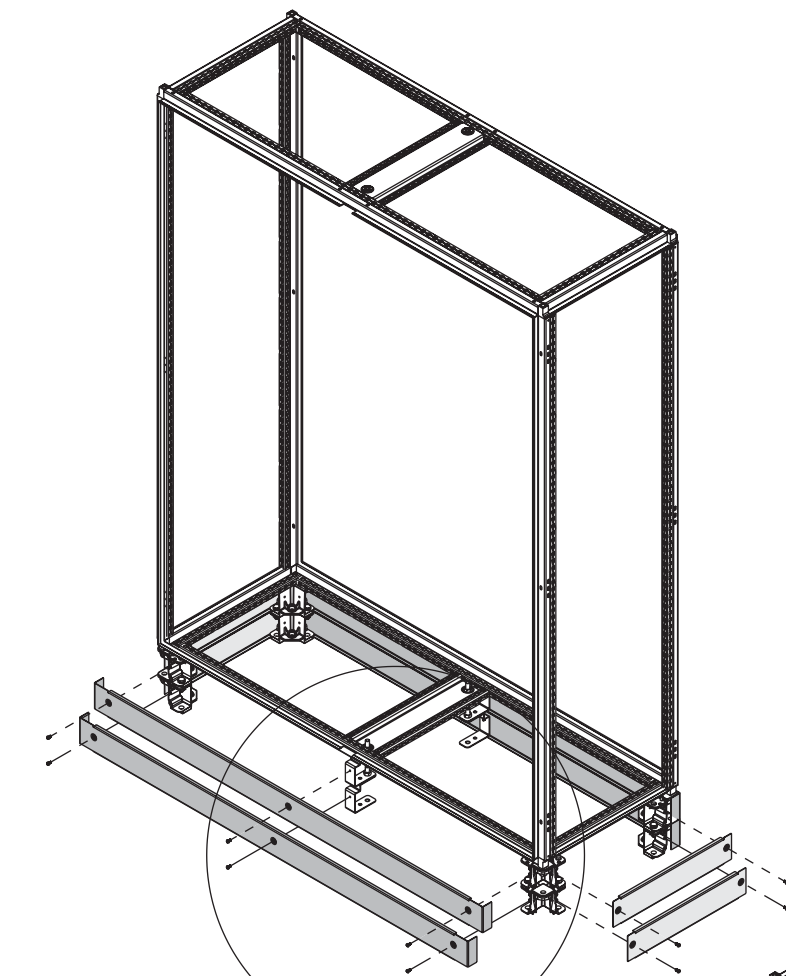

4 $2.8 \text{ NM} \pm 0.3$
[25 LB IN ± 2.5]

2

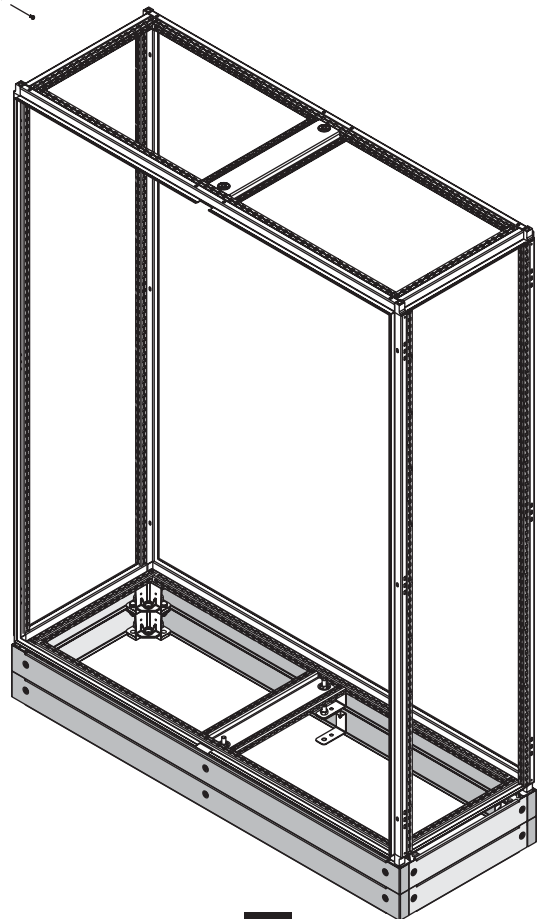

3