





HOFFMAN

PROLINE G2

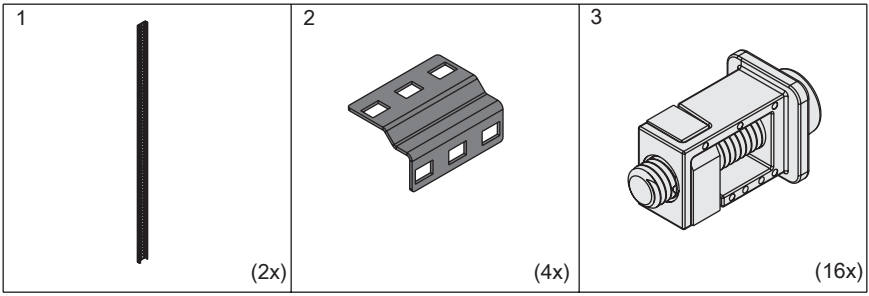




$4.5 \pm 0.5 \text{ N}^*\text{M}$
 $[40 \pm 4.0 \text{ LBF}^*\text{IN}]$

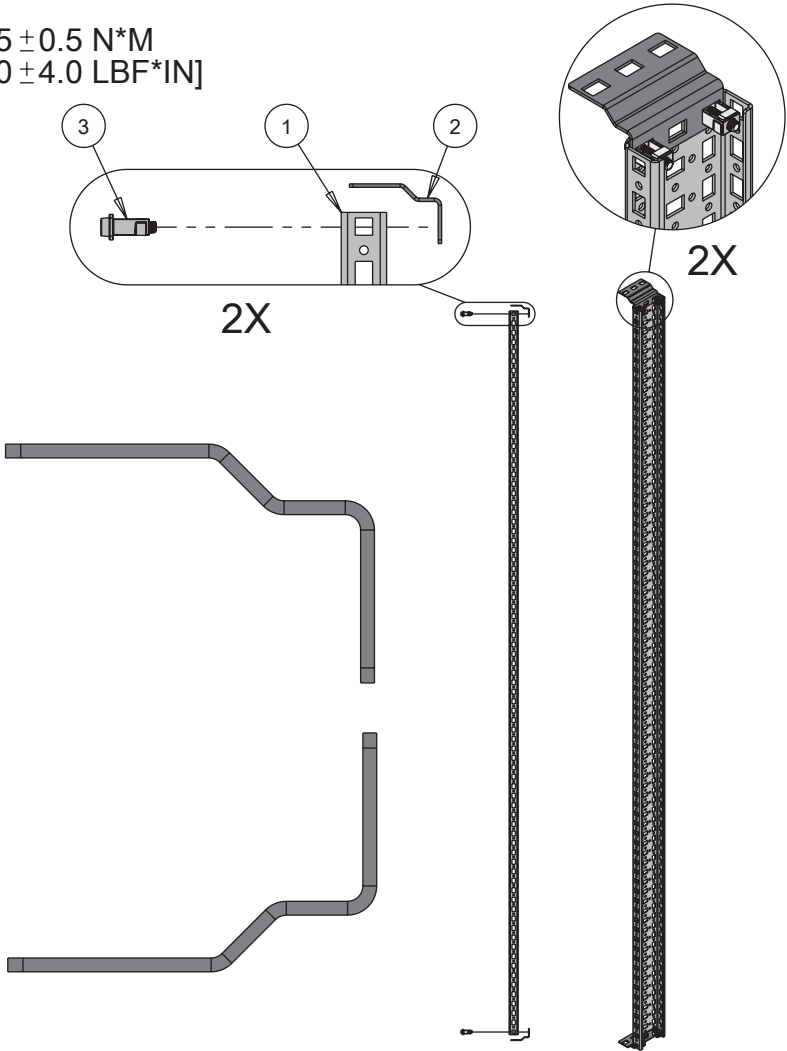


1


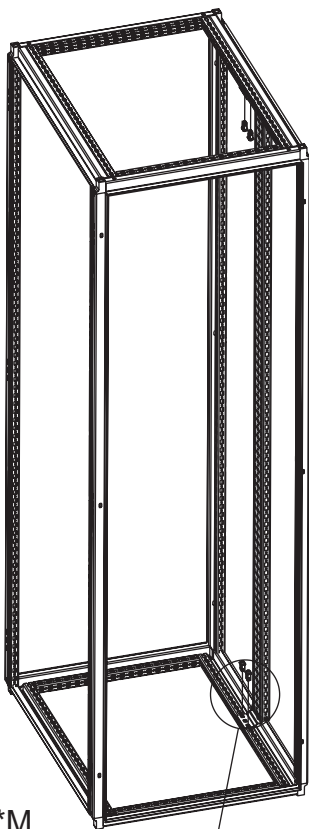


$4.5 \pm 0.5 \text{ N}\cdot\text{M}$
 $[40 \pm 4.0 \text{ LBF}\cdot\text{IN}]$


3

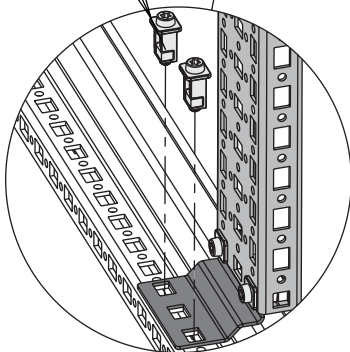

2X

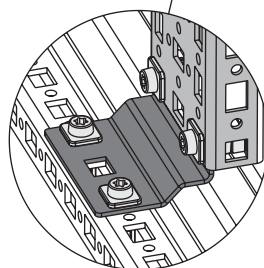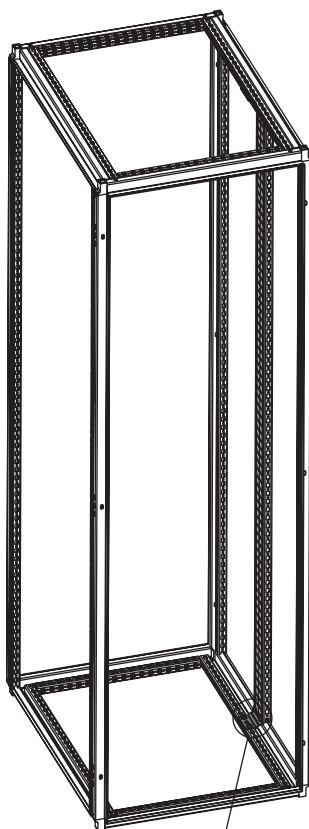

2X

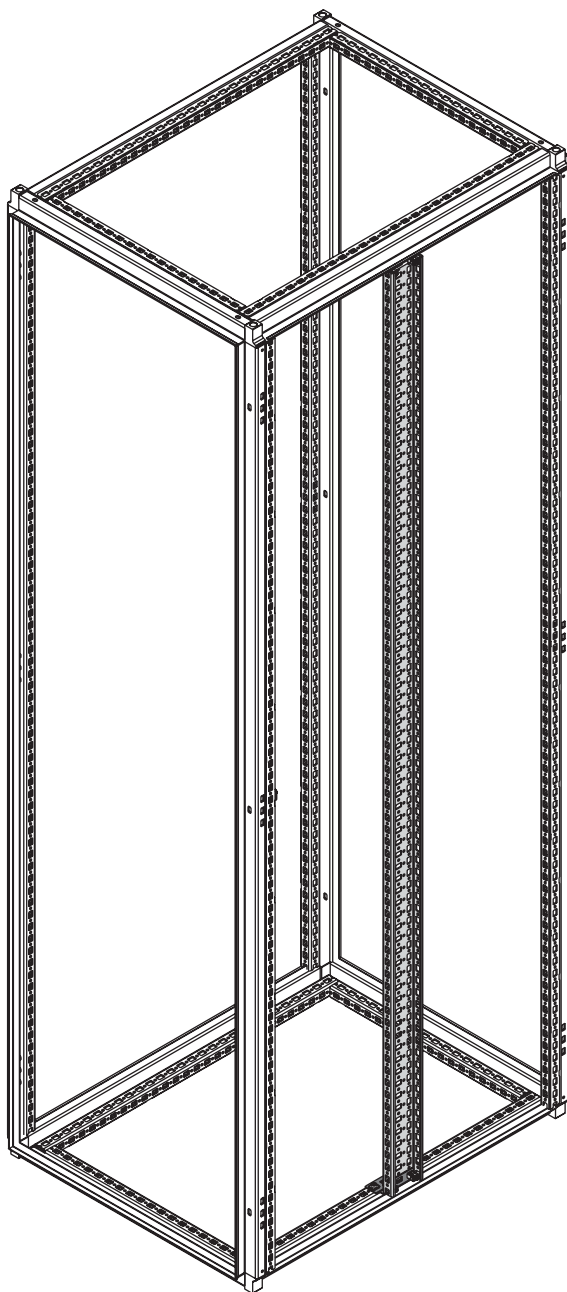

3