




adorne Collection  
adorne® 15A Two-Gang Pop-Out™ Outlet, Magnesium  
Part No. ARPTR152GM2

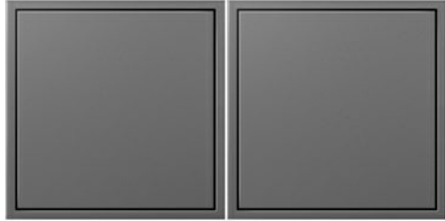

The cleverest way to add power and style, this 15A pop-out wall outlet extends to offer 3-plug access, then uniquely disappears back into the wall with a simple push when not in use. This designer outlet is sized for use within an adorne 2-Gang Screwless Wall Plate (sold separately) when paired with a second adorne device. Specialty frame included.

## Features & Benefits

Perfect anywhere you'd like to hide outlets when not in use, for added style and safety

Provides additional power with 3-plug access when extended from wall

Disappears back into the wall with a simple push when not needed

Installs easily in as little as 15 minutes

Comes with a special frame for mounting and requires a deep electrical outlet (22.5 cubic inches). No new wires required for typical installation

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisi-shutters" for an invisible effect

More color options available to fit any style, including finishes to match current hardware and lighting trends.

Complete the look with a stunning, screwless adorne® Wall Plate, not included. Available in a range of contemporary colors and finishes. Coordinate with other designer switches & outlets

## Specifications

### General Info

|                    |                |                       |              |
|--------------------|----------------|-----------------------|--------------|
| Product Line       | Pass & Seymour | Color                 | Magnesium    |
| Finish             | Frosted        | UPC Number            | 786776178630 |
| Country Of Origin  | China          | Number of Receptacles | 3            |
| Application Sector | Residential    | Standard              | CULUS        |

### Additional Information

Prop 65 Warning Required No

---

## Technical Information

---

|                 |                          |                          |  |
|-----------------|--------------------------|--------------------------|--|
| Phase           | Single                   | Connection               | Side and Back Wire                     |
| Number of Wires | 3                        | Number of Gangs          | 1                                      |
| Number of Poles | Double Pole              | Wire Size                | #14 - #10 AWG                          |
| Indoor/Outdoor  | Indoor                   | NEMA Configuration Code  | 5-15R                                  |
| Mounting Type   | Box                      | Voltage                  | 125 VAC                                |
| Connection Type | Internal Pressure Plates | Environmental Conditions | 95 (relative humidity, non-condensing) |

---