




Pass and Seymour  
LS Trademaster CFL/LED/Incandescent Single-Pole, Non-Preset Dimmer, White  
Part No. LSCL450W

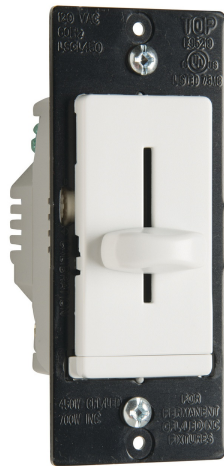

Works with select dimmable CFL/LED or incandescent lighting loads and features a sleek, sculpted ergonomic design for smooth, easy operation and precise control.

## Features & Benefits

CFL/LED dimmable bulb compatible (except for 0-10V LED drivers).	Works with dimmable CFL/LED or Incandescent lighting loads at 450W CFL/LED & 700W Incandescent
Built-in electromagnetic and radio-frequency interference protection.	No dirt-catching crevices.
Tough, impact-resistant thermoplastic housing makes it a perfect choice for new home construction. Matching, unbreakable TradeMaster wall plates available for all models.	Preset ON/OFF switch automatically returns controlled lights to preset level without re-adjusting dimmer setting.
Exclusive, screw-pressure-plate back wire terminals save time, space and money. Designed for 12 and 14 gauge wire, stranded or solid. No-wire-lead design eliminates wire nuts.	Superior heat management.
Patented Snap-In Light Module (sold separately) transforms the dimmer into an illuminated dimmer.	Rating: 450W LED & CFL: 700W Incandescent: 120VAC 60Hz.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	White
UPC Number	785007040555	Country Of Origin	China
Application Sector	Residential	Standard	cULus, RoHS
Type	Dimmer		

### Technical Information

Frequency Rating	120VAC 60Hz Hz	Connection	Screw Terminals
------------------	----------------	------------	-----------------

---

Number of Poles	Single Pole	Wattage	450 W
Voltage	120 V	Load	CFL/LED/Incandescent
Environmental Conditions	Humidity: Less than 95% non condensing		

---