







**HOFFMAN**


## PROLINE G2

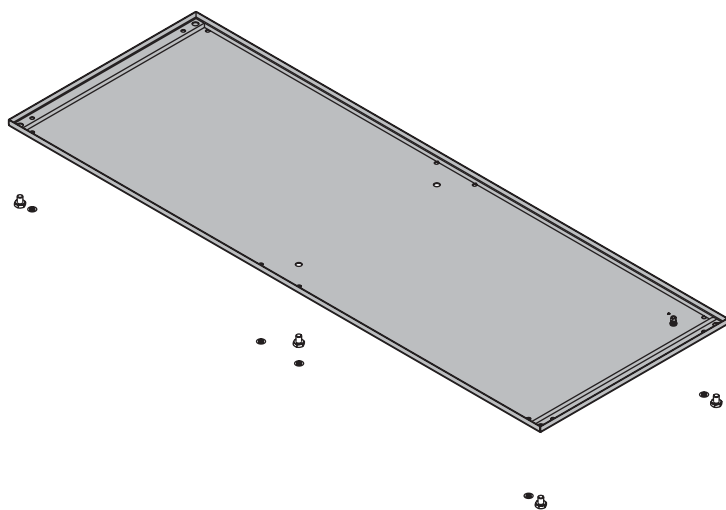


 $\geq 1200$  mm
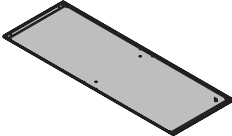
|                                                                                   |                                                                                   |                                                                                   |   |
|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|---|
| 1                                                                                 | M12-1.75X16                                                                       | 2                                                                                 | 3 |
|  |  |  |   |
| (6x)                                                                              | (8x)                                                                              | (1x)                                                                              |   |

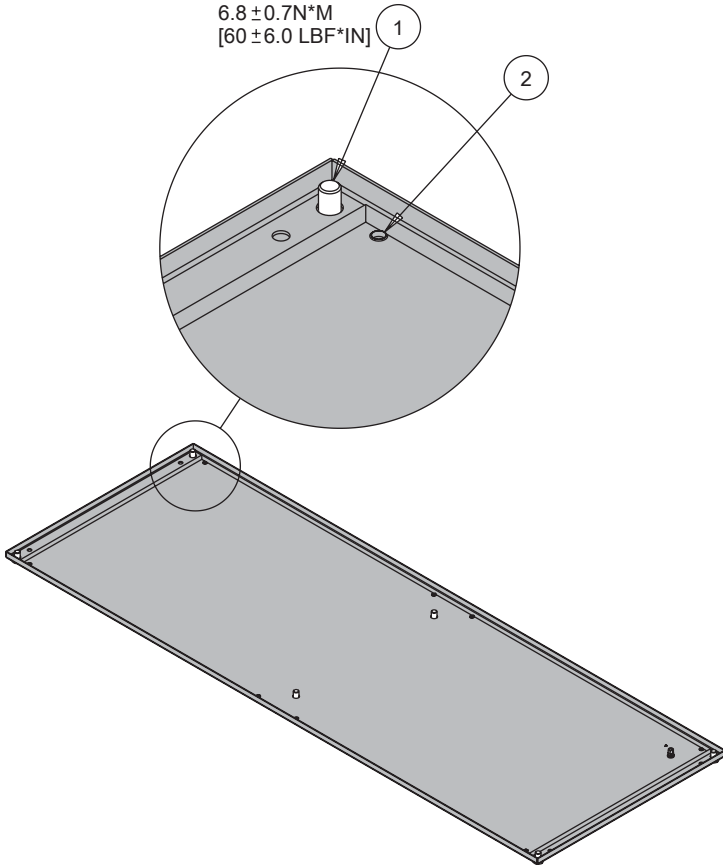

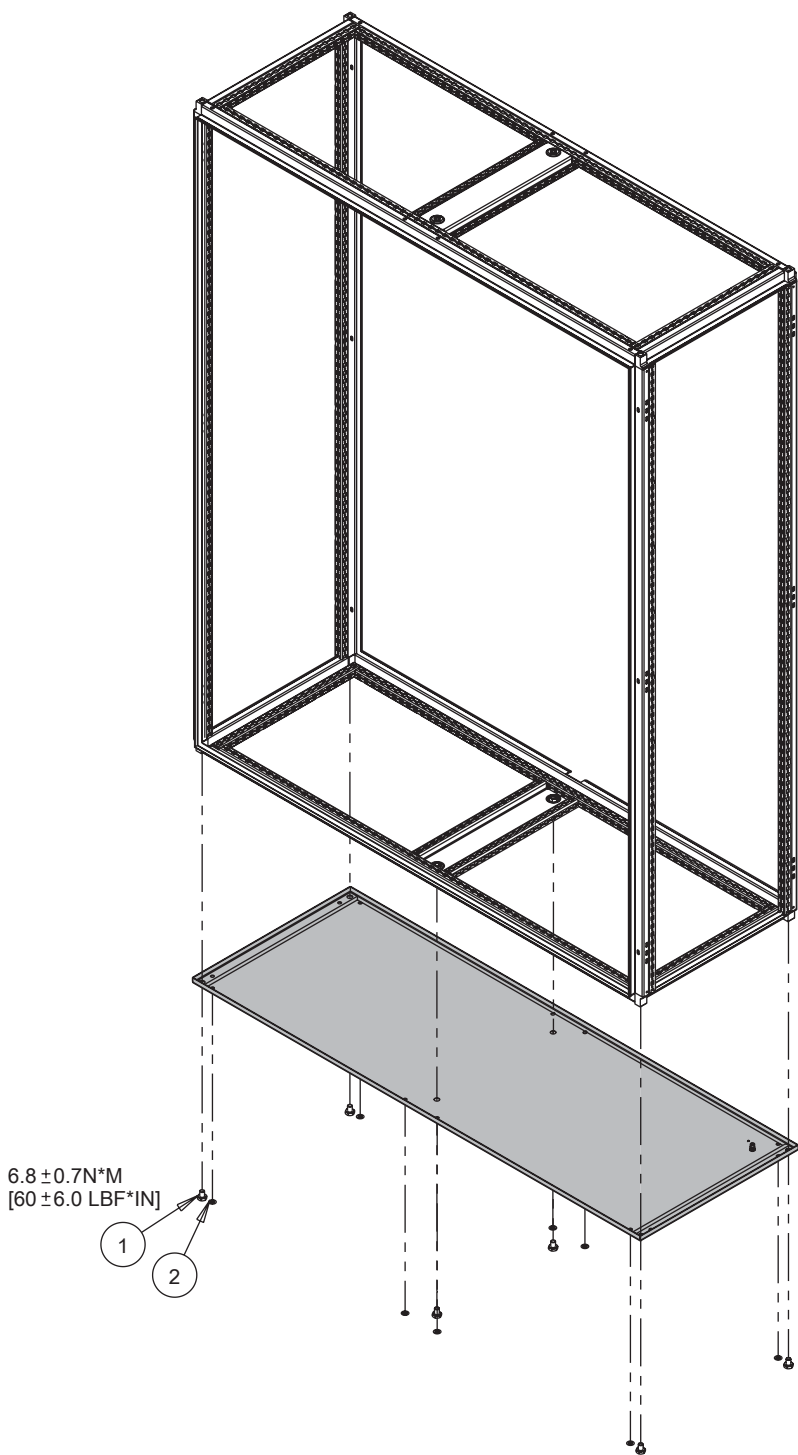

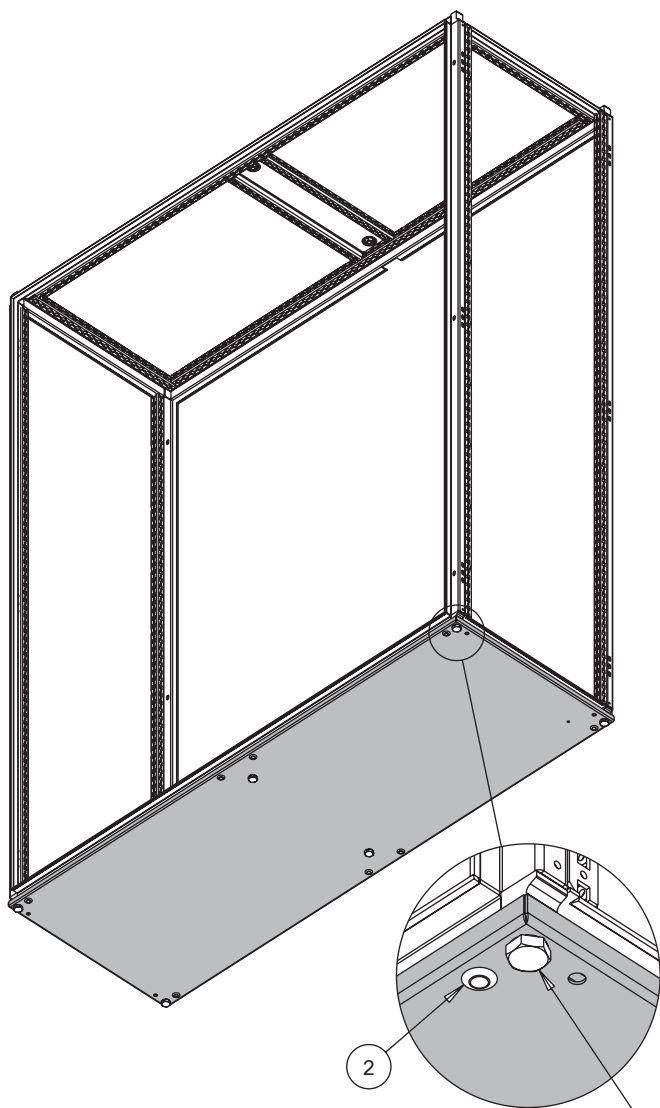

6.8 ± 0.7 N\*M  
[60 ± 6.0 LBF\*IN]