


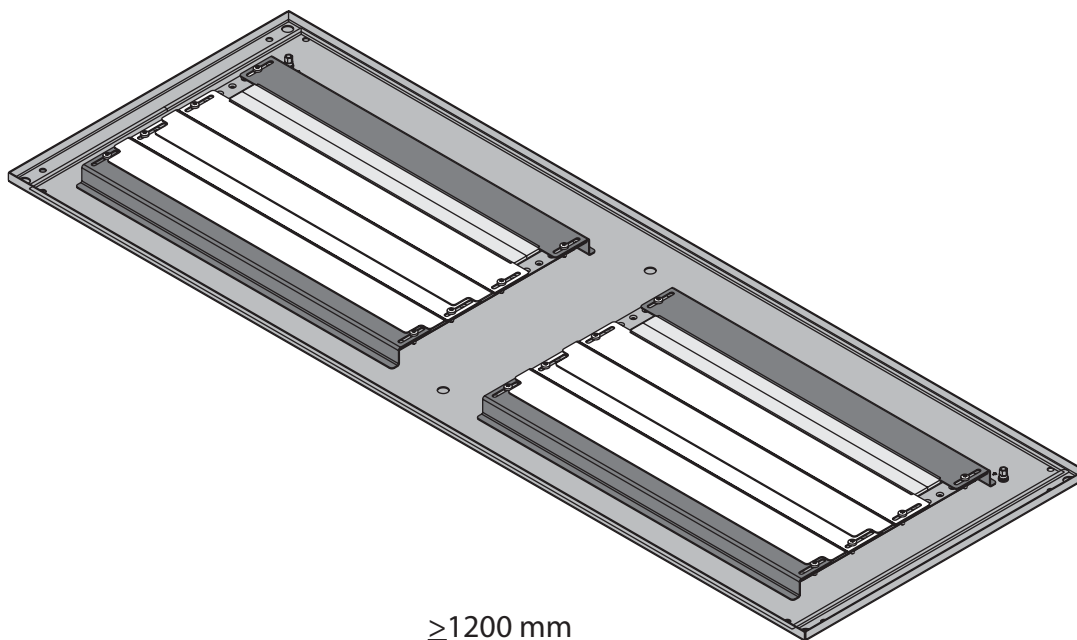
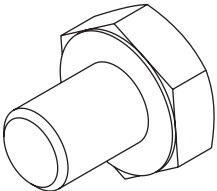
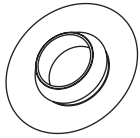
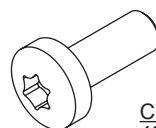
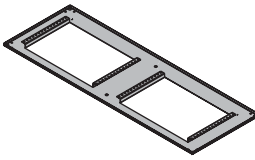
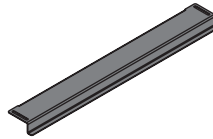




PROLINE G2

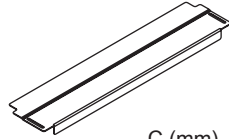


1 M12X16  (6x)	2  (4x)	3 M6X16  C (mm) 400.....(8x) 500.....(12x) 600.....(16x) 800.....(24x) 1000.....(32x)
4  (1x)	5  (4x)	6  C (mm) 400.....(0x) 500.....(2x) 600.....(4x) 800.....(8x) 1000.....(12x)

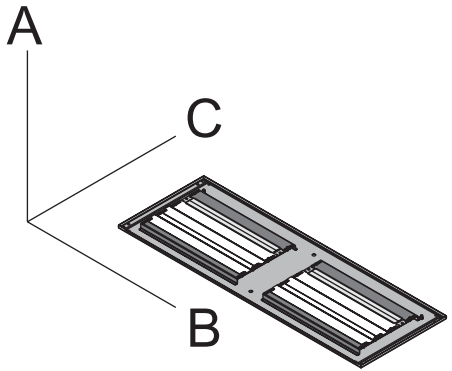

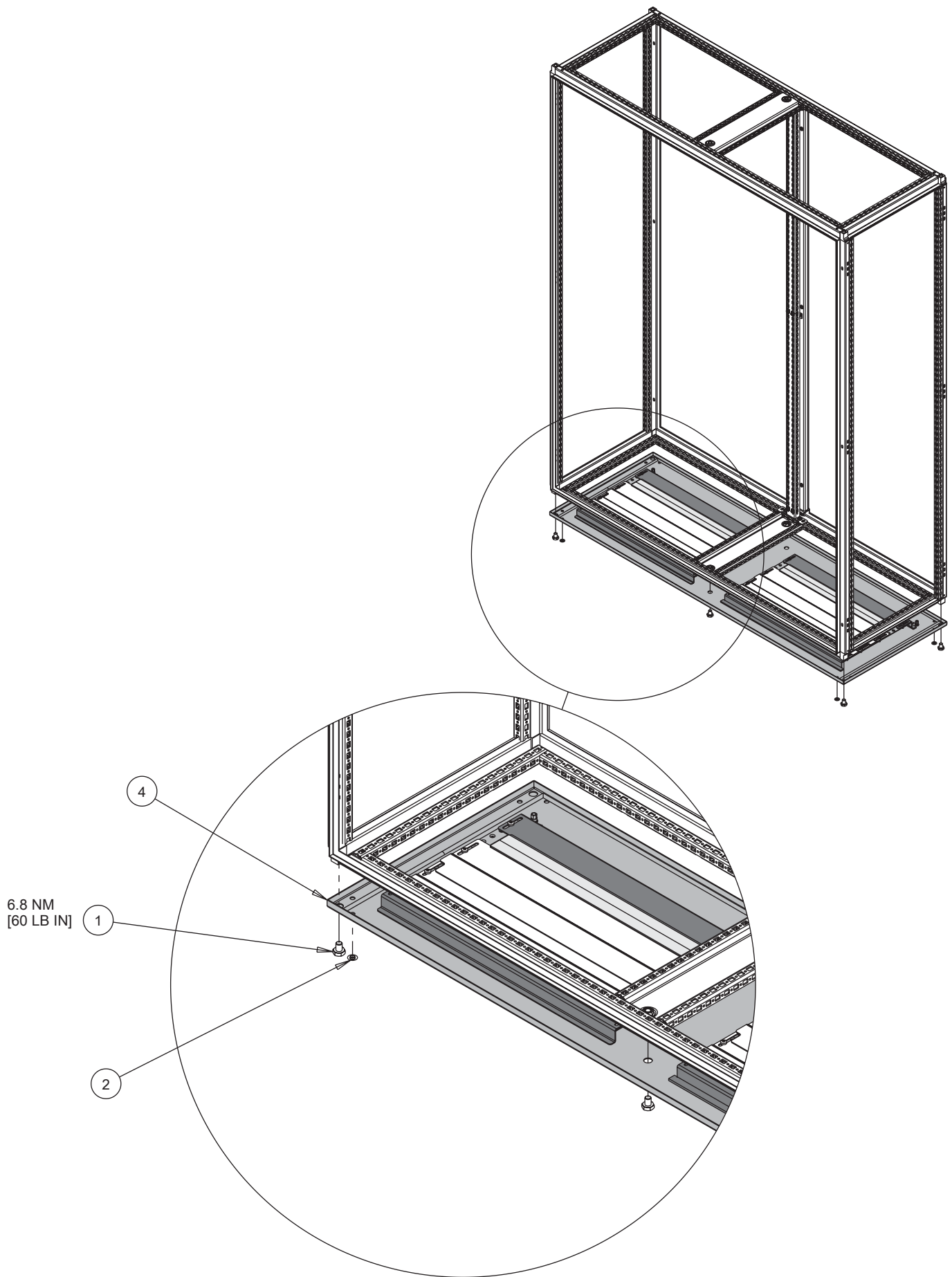


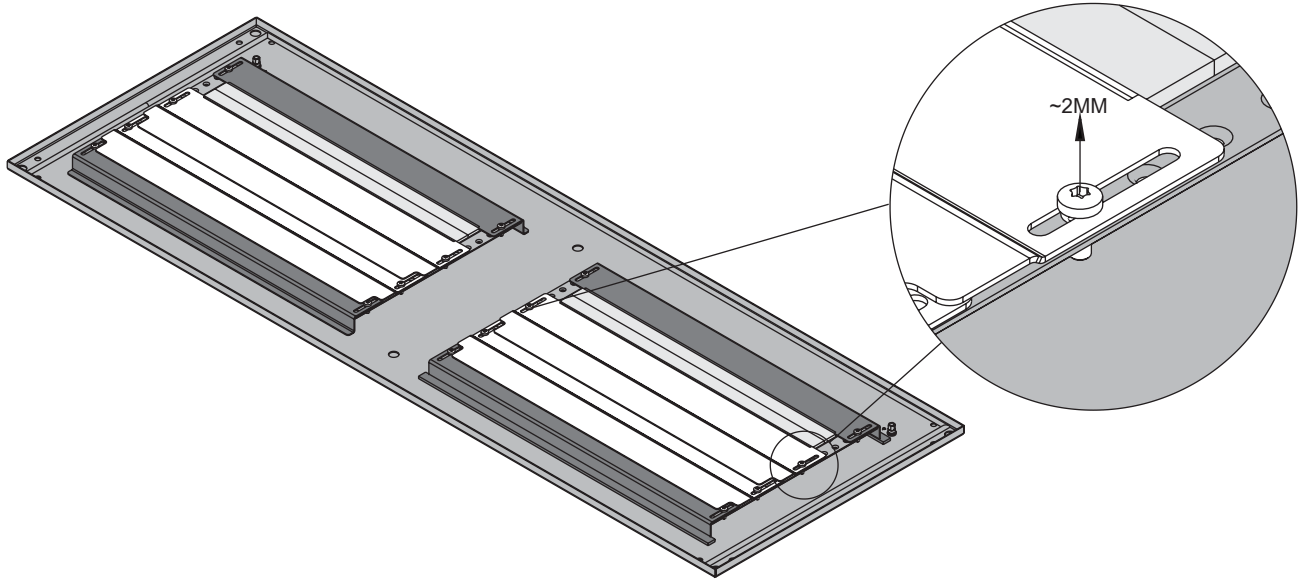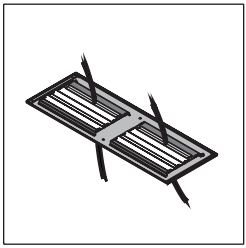



1

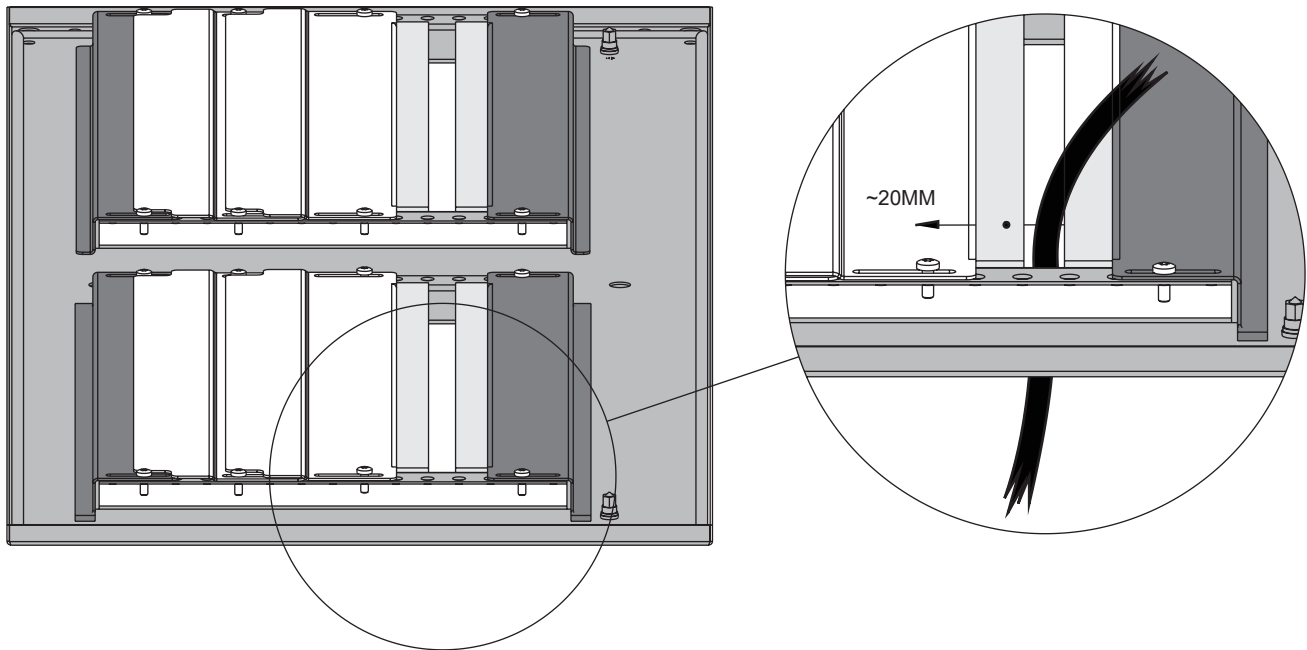


2

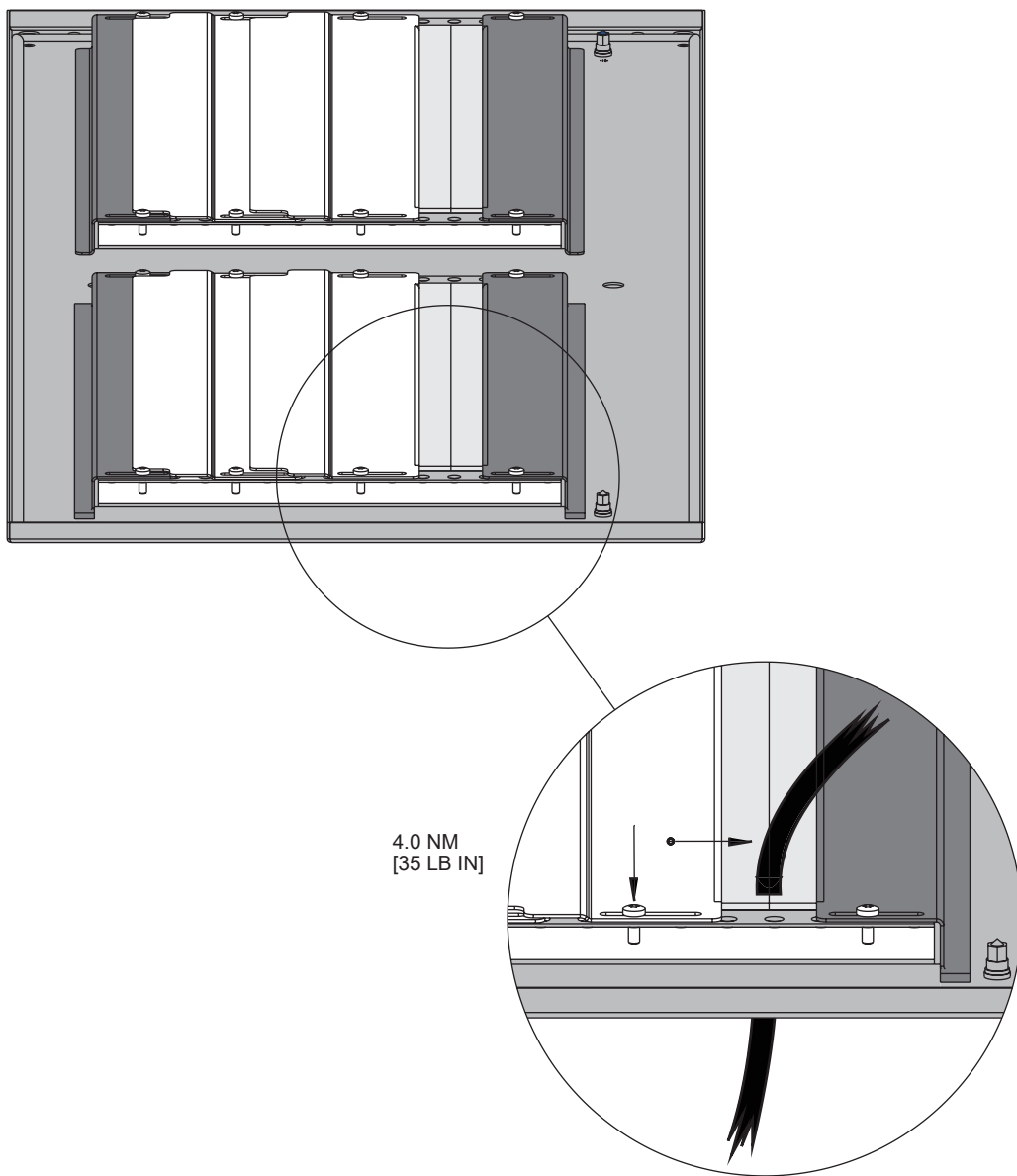

3

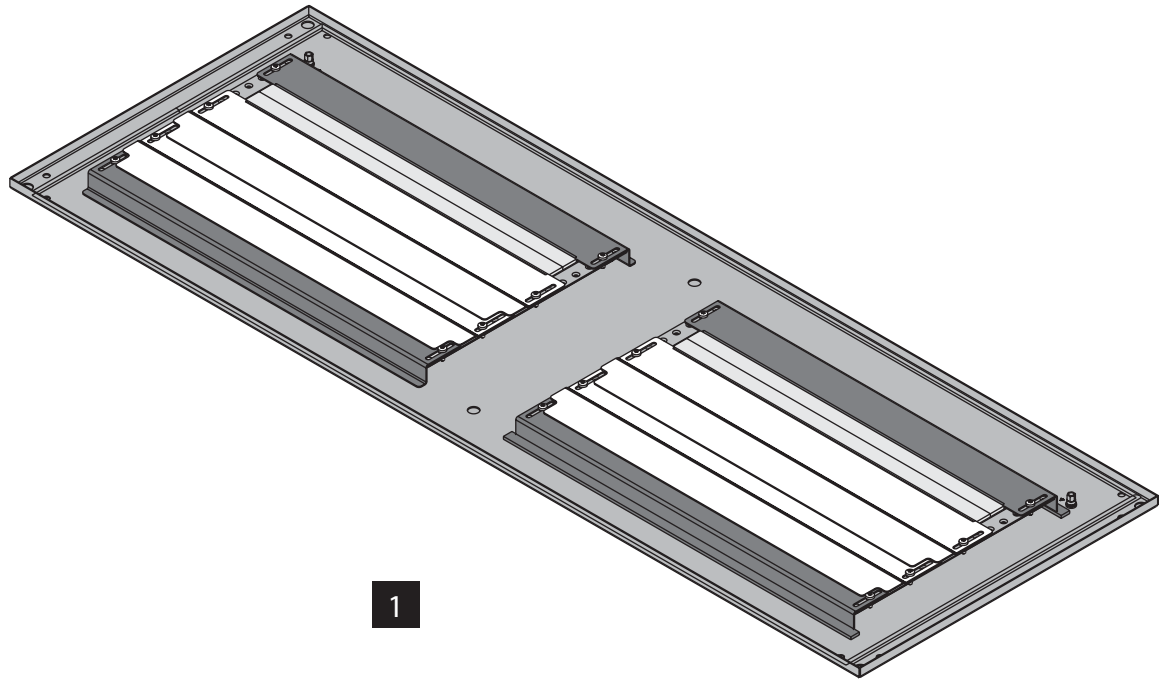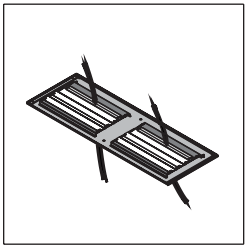

1

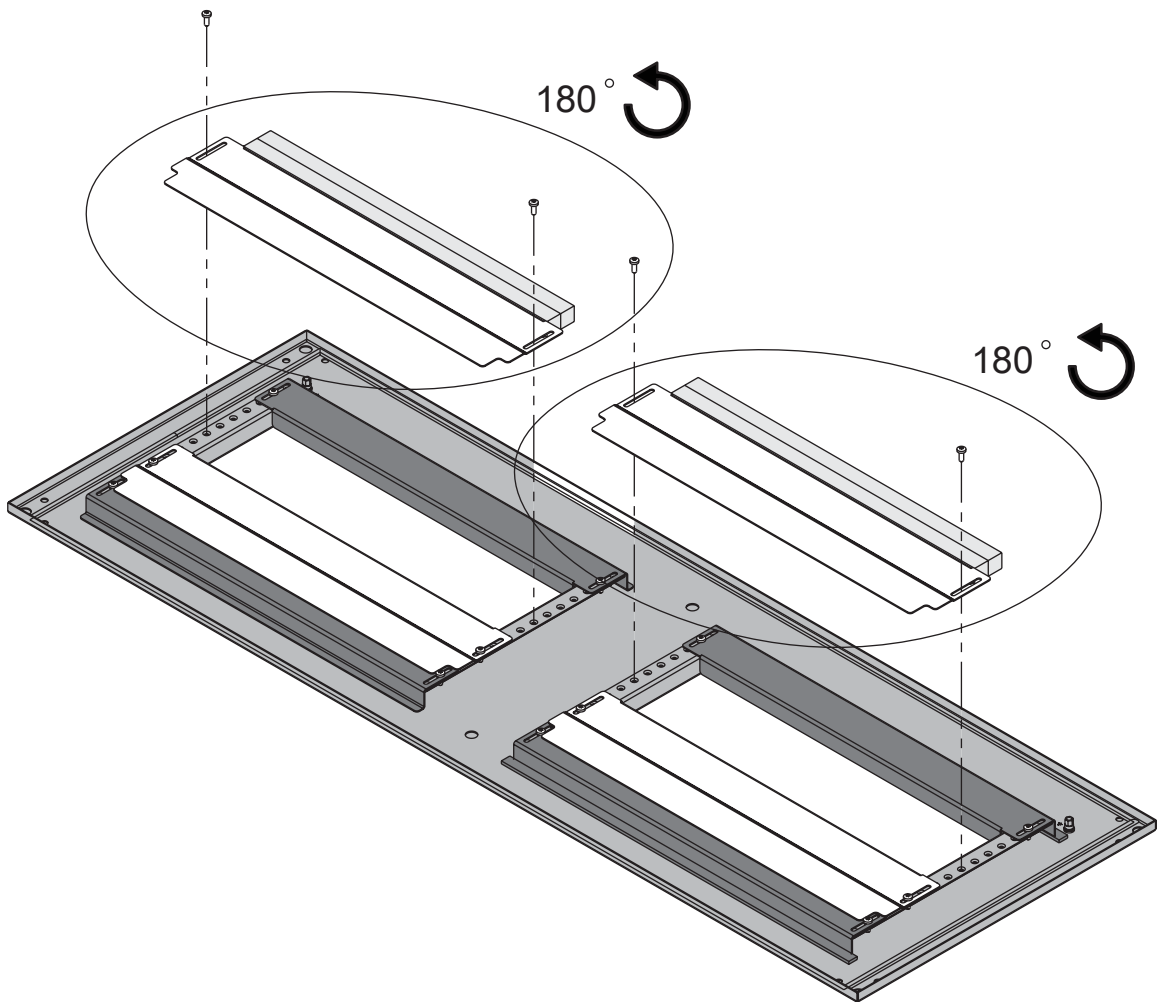

2

