

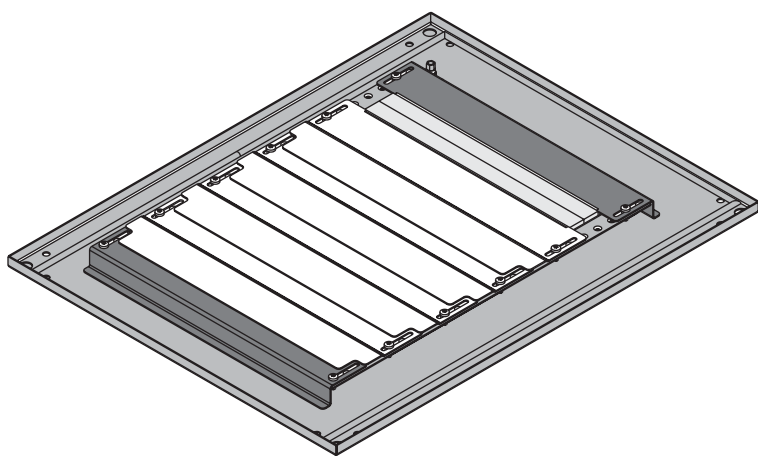
 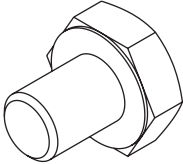
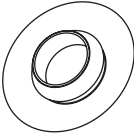

 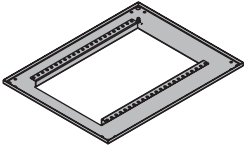
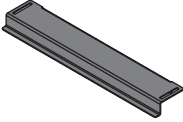



PROLINE G2





<1200 mm


1 M12X16  (4x)	2  (4x)	3 M6X16  C (mm) 400.....(4x) 500.....(6x) 600.....(8x) 800.....(12x) 1000.....(16x)
4  (1x)	5  (2x)	6  C (mm) 400.....(0x) 500.....(1x) 600.....(2x) 800.....(4x) 1000.....(6x)

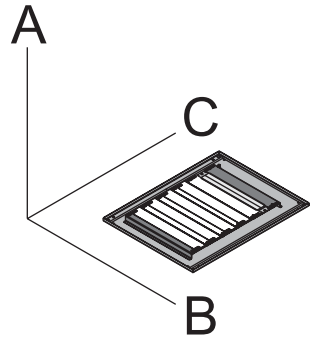

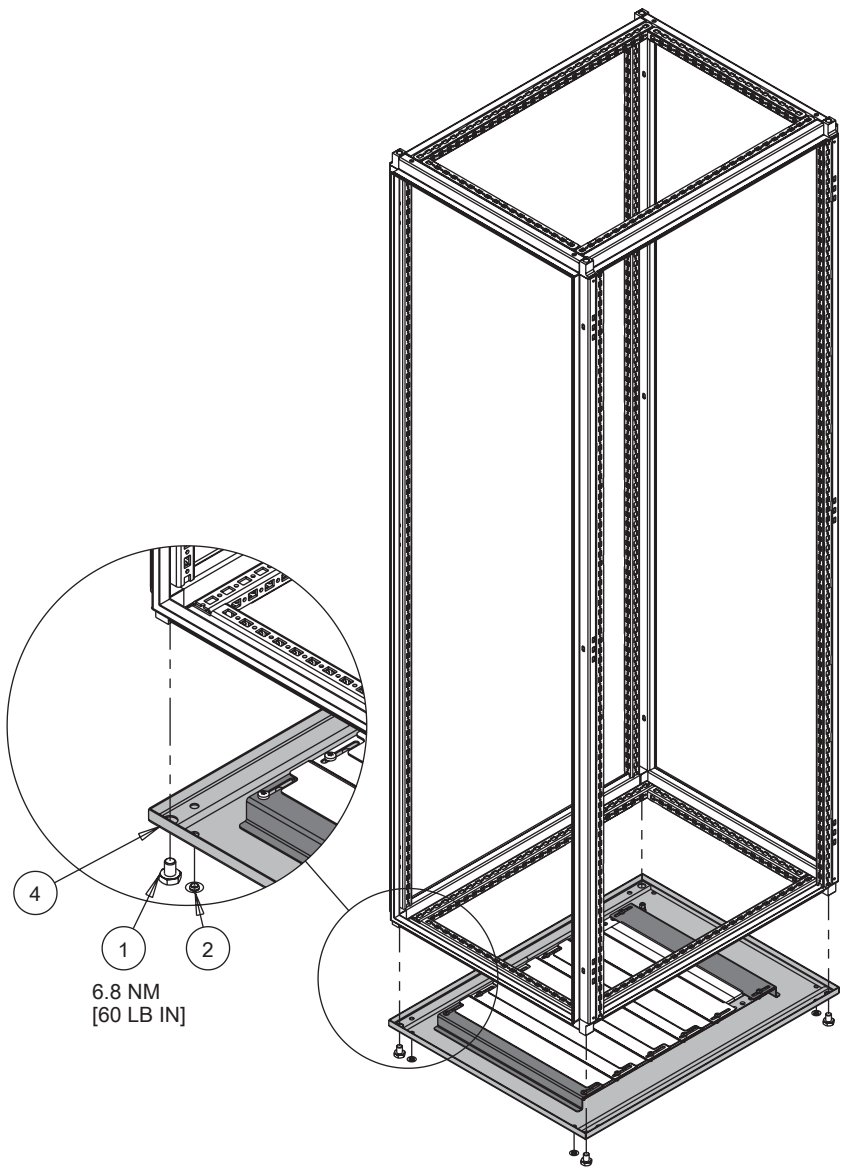


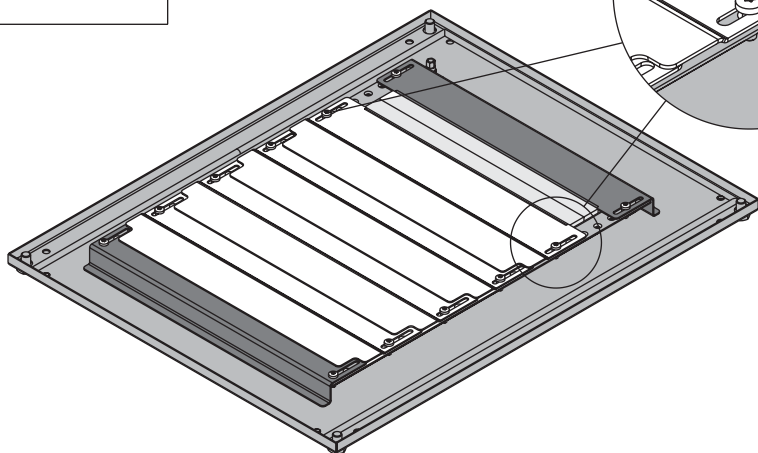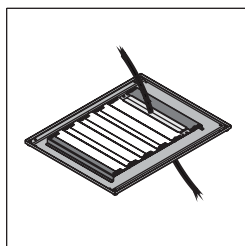


1

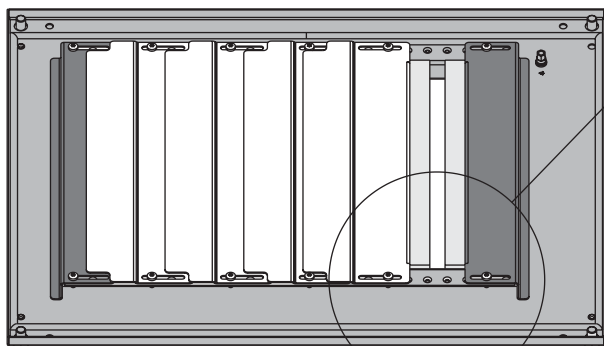


2

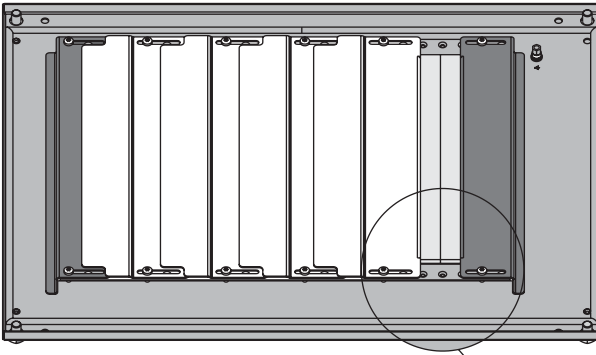



4.0 NM
[35 LB IN]

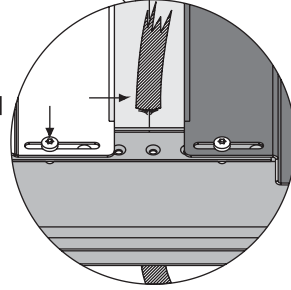


3

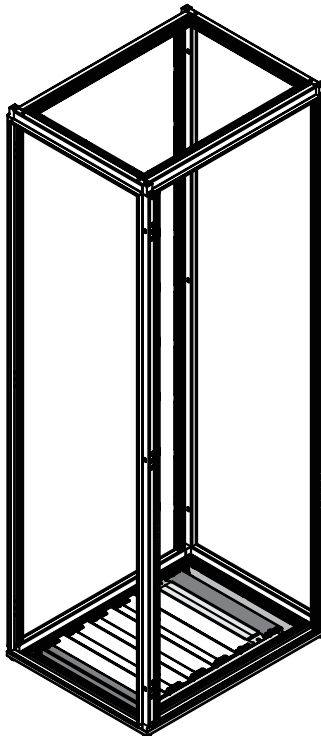


4

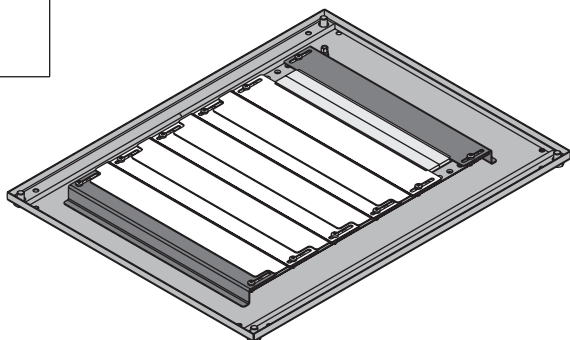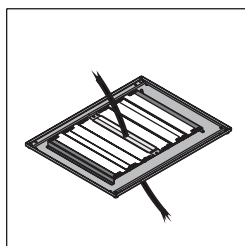



1

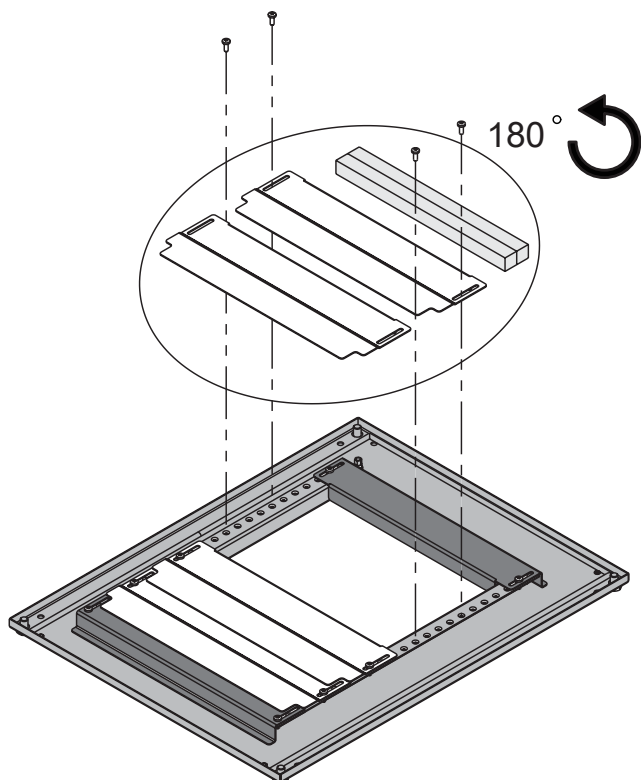

2

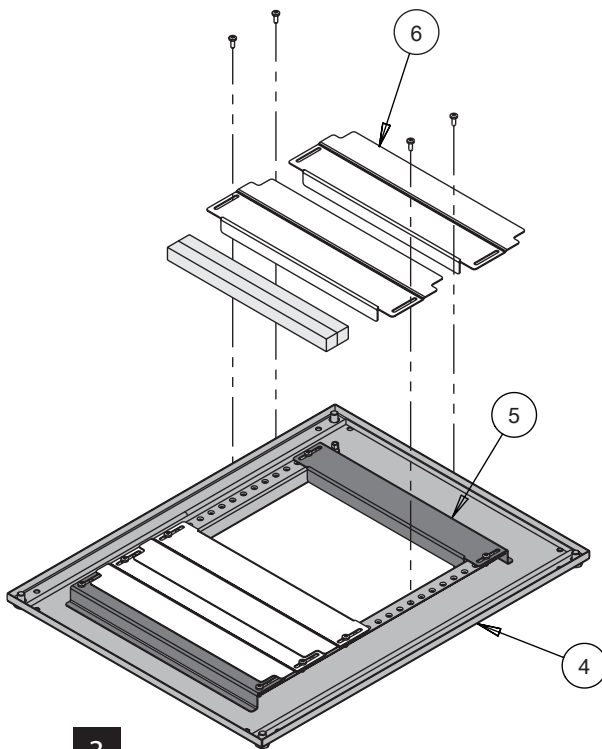

3

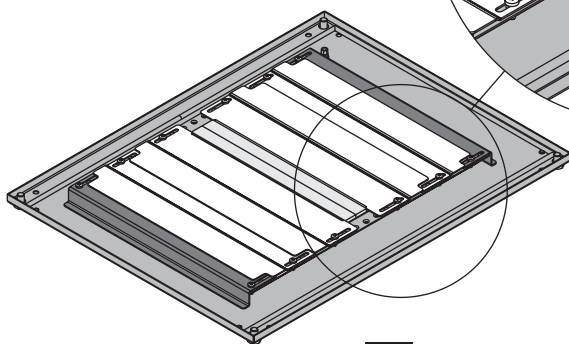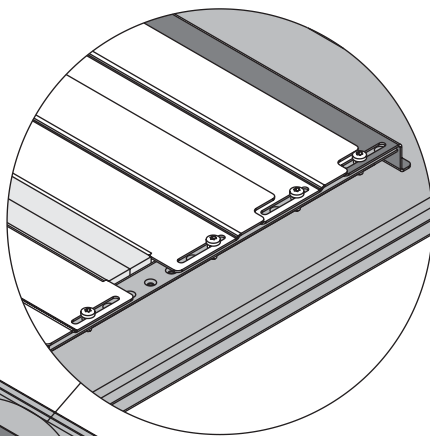

4



HOFFMAN