

# SLMT6-13W

6" SLIMLED MULTI, up to 1070 Lumens, 13 Watt,  
Color Selectable  
Recessed Downlighting

Job Information		
Project Name		Type
Location		
Quantity		Date
Contact/Phone		
Notes		

## Features

### Body

Durable airtight aluminum body with twist-and-lock trim that allows for ease and versatility. White trim included, black and brushed nickel trims sold separately.

### LED Characteristics

This general application light fixture features a 13 watt LED module that maintains uniform intensity producing up to 1070 lumens; with a typical CRI of 90. CCT select switch 2700 K - 5000 K color temperature.

### Dimming

100%-10% dimming capability. This fixture is compatible with industry standard forward/reverse phase dimmers, TRIAC/ELV dimmers. For compatible dimmers, visit [www.liteline.com/SlimLEDMulti](http://www.liteline.com/SlimLEDMulti)

### Beam Spread

The fixture lens provides 110° beam spread.

### Mounting

Can be mounted to an industry standard

3.5"/4" octagon box (JBox / standard slab box) with minimum depth of 1.5" (40mm) via mounting holes or a compatible 6" recessed housing (retrofit kit sold separately - P-SLMT6-6CAN).

### Compatible Recessed Housings

- RF601CAT series
- RF602ICAT series

### LED Driver

Built-in on board driver with 120V AC input.

### Quick Connect push-in terminals

"Quick connect" push-in terminals for fast and easy wiring.

### Operating Temperature

-30°C~45°C (-22°F~113°F)

### Environment

- Suitable for wet locations.
- Fire-rated when used in a fire-rated octagon box.
- Indoor/Outdoor rated.

 

SPECIFICATION	
Application	Recessed / Surface-mount Downlight
Approved Location	Wet
Beam Angle	110°
CCT	2700 K / 3000 K / 3500 K / 4000 K / 5000 K
Certification	cETLus
Color	WH (BK/BN trims sold separately)
CRI	90+
Dimming	Yes
Dimming Tech	Forward/Reverse phase / TRIAC/ELV
Energy Star	Yes
Input	120V, 60Hz
LM79	Yes
LM80	Yes
Lumens	Up to 1070
Lumens per Watt	Up to 83
Power Factor	0.9
Projected Life	70% @ 50,000 hrs
Title 24	Yes
Warranty	5-Year
Wattage	13W

CCT	Lumens
2700 K	960
3000 K	996
3500 K	1040
4000 K	1060
5000 K	1070




## Description


The SLMT6-13W is a 13 watt 6" round downlight for retrofit application onto existing 6" recessed housings or 3.5"/4" octagon box. It is a high-performance, easy to install residential grade downlight solution that offers good light output, energy-efficiency and streamlined design. Suitable for wet locations.

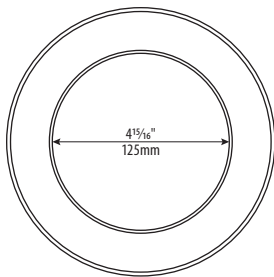

## Mounting Options

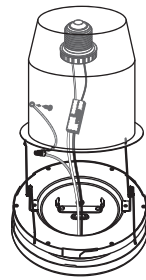

6" CAN\*

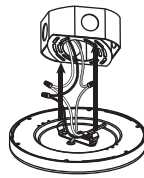

J-BOX

\* Retrofit Kit sold separately (P-SLMT6-6CAN).



**JA8**  
TITLE 24

WET LOCATION  
ENDROITS  
MOUILLÉS

**AIR  
TIGHT**

**Notes:** Accessories are sold separately. For additional options please consult your Liteline representative.  
Due to our continued efforts to improve our products, product specifications are subject to change without notice.

## Ordering Guide



### SLMT6-13W

6" SLIMLED MULTI color selectable round downlight, 13W, with white trim.

## Accessories

---



### **P-SLMT6-6CAN**

6" Housing accessories (Retrofit kit)  
E26 lampholder + wire + connectors +  
spring clips



### **SLMT6-RT-BK**

Optional trim for 6" SlimLED Multi, Black.

### **SLMT6-RT-BN**

Optional trim for 6" SlimLED Multi,  
Brushed Nickel.



### **LC-CRTL-3WAY-1**

OnCloud Smart Wi-Fi 3-way switch.  
Suitable for 3-way or 4-way switch  
applications.



### **LC-CRTL-DIM-1**

OnCloud Smart Wi-Fi dimmer. Features  
an ON/OFF press and a 7 level  
touch slider.