

120V SELECTABLE MINI TASK

Round and Square and Trimless Adjustable 2" LED Downlights

GM Lighting®

Project Name	Type
--------------	------

Catalog #	Date
-----------	------

PRODUCT OVERVIEW

GM Lighting's trimless MiniTask selectable 5CCT downlight with 90+ CRI light source is available in 2" round or square in white. The fixture is fully dimmable. Mud-in and paint include flange to minimize luminaire footprint on ceiling. Power supply integrated into included wiring box. No separate power supply required.

FEATURES

- 120V
- 5CCT selectable switch (2700K / 3000K / 3500K / 4000K / 5000K)
- Dimmable ELV
- 38° beam angle
- 90+ CRI
- 2" module up to 1030lm
- Mud-In Trimless 2" fixed square or round versions
- Mud-In Trimless 2" adjustable round versions
- White finish
- Wet location, indoor covered ceiling
- IC Rated for insulated ceiling spaces

SPECIFICATIONS

ELECTRICAL

- 15W (2" fixed)
- 8W (2" adjustable)
- 120V (includes wiring box)

OPTICS

- Selectable Switch 2700K, 3000K, 3500K, 4000K and 5000K
- 90+ CRI

CERTIFICATION

- ETL listed (for US & Canada)
- Energy Star
- Title24/J8
- IC rated

OPERATING TEMP

- -4°F to 104°F

WARRANTY

- 5-year warranty



ORDERING INFORMATION

Ordering Example: MTRT2-5CCT-W

Model	Format	Size	Color Temp	Finish
MT (MiniTask)	RT (Round Trimless)	2"	5CCT (Selectable Switch)	W (White)
	ST (Square Trimless)			
MT (MiniTask)	RAT (Round Adjustable Trimless)	2"	5CCT (Selectable Switch)	W (White)

ACCESSORIES

Model	Description
CHDL-UNV-NCP	Universal new construction mounting plate
RSD-5FT-EXT	5' extension cord for RSD Series Downlights
RSD-10FT-EXT	10' extension cord for RSD Series Downlights
RSD-20FT-EXT	20' extension cord for RSD Series Downlights

LUMEN TABLE

Model	2700K	3000K	3500K	4000K	5000K
MTRT2-5CCT-W MTST2-5CCT-W	840lm	880lm	980lm	1030lm	1000lm
Lumen Factor	0.95	1.00	1.11	1.17	1.14
MTRAT2-5CCT-W	530lm	545lm	595lm	610lm	600lm
Lumen Factor	0.97	1.00	1.08	1.12	1.09

NOTE: IES files available in 3000K. Download from product page on website. If needed, use lumen factors to scale output to other color temperatures.

120V SELECTABLE MINI TASK

Round and Square and Trimless Adjustable 2" LED Downlights



DIMENSIONS




2" Downlight Round / Square Trimless

MTRT2-5CCT-W / MTST2-5CCT-W

Ceiling Cutout Size For Hole

2" Round Fixed Downlight: $\varnothing 2\text{-}5/8"$ (67mm) round

2" Square Fixed Downlight: $2\text{-}13/16" \times 2\text{-}13/16"$ (72 x 72mm) square

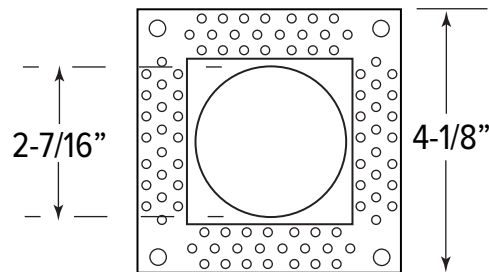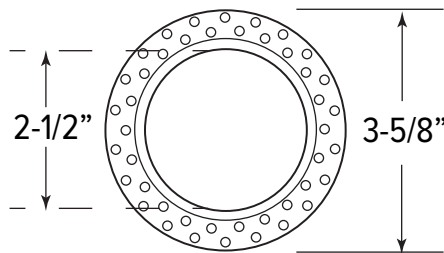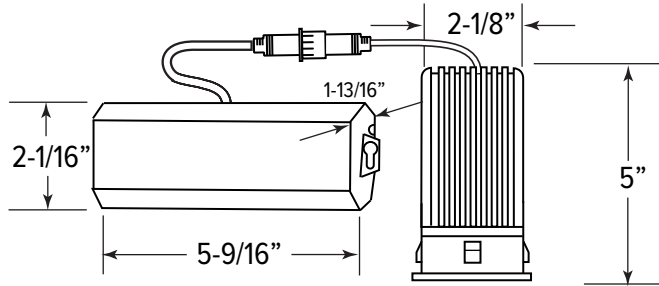

2" Round Adjustable Trimless

MTRAT2-5CCT-W

Ceiling Cutout Size For Hole

2" Round Adjustable Downlight: $\varnothing 3\text{-}1/8"$ (80mm) round

