
 
 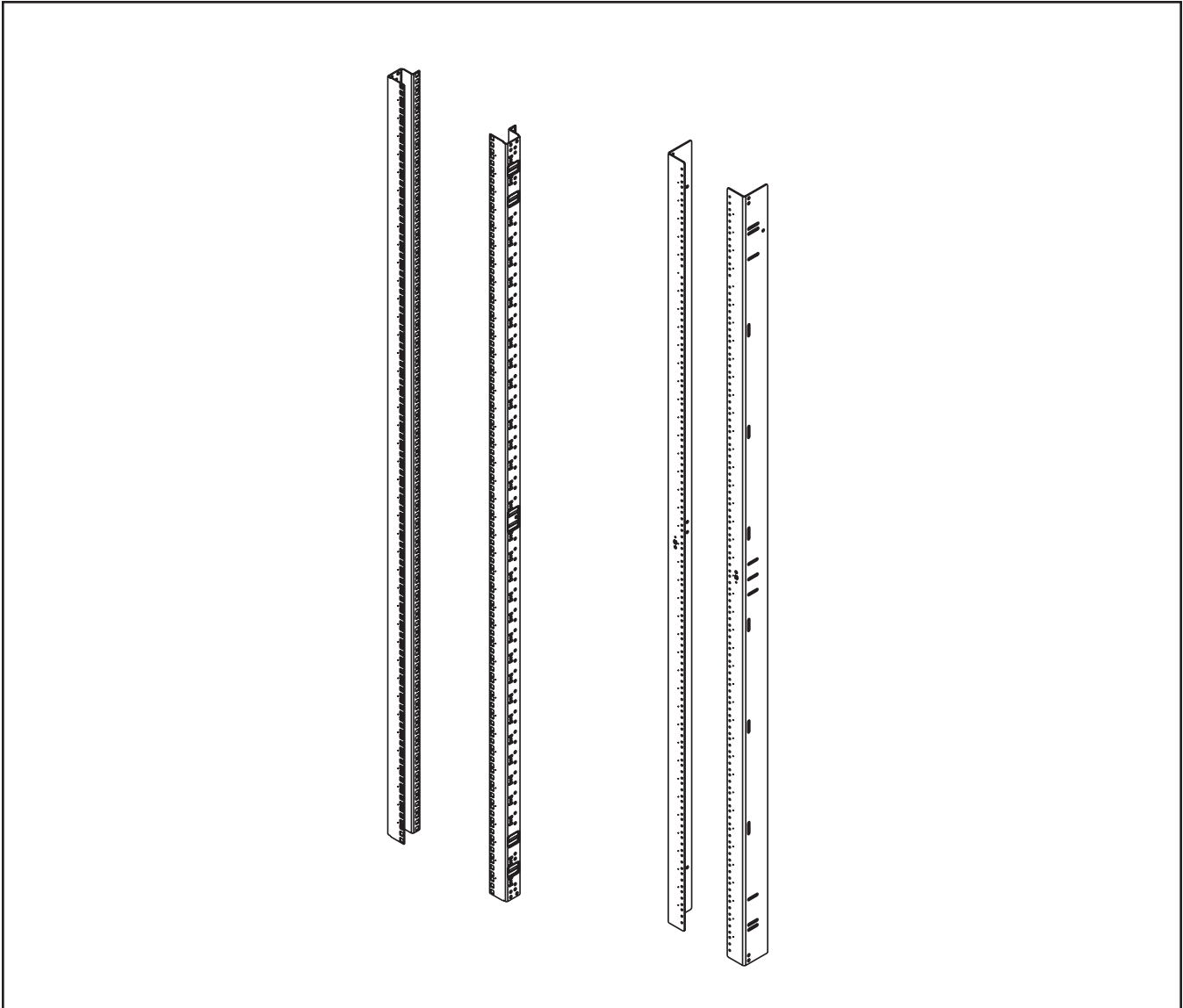



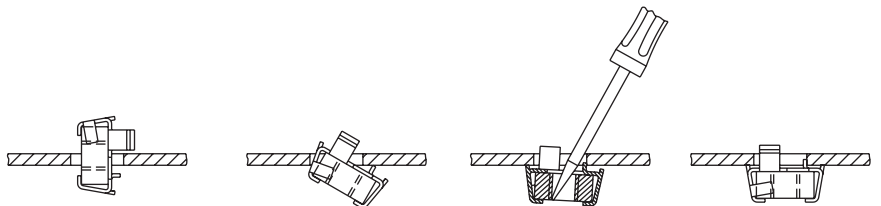
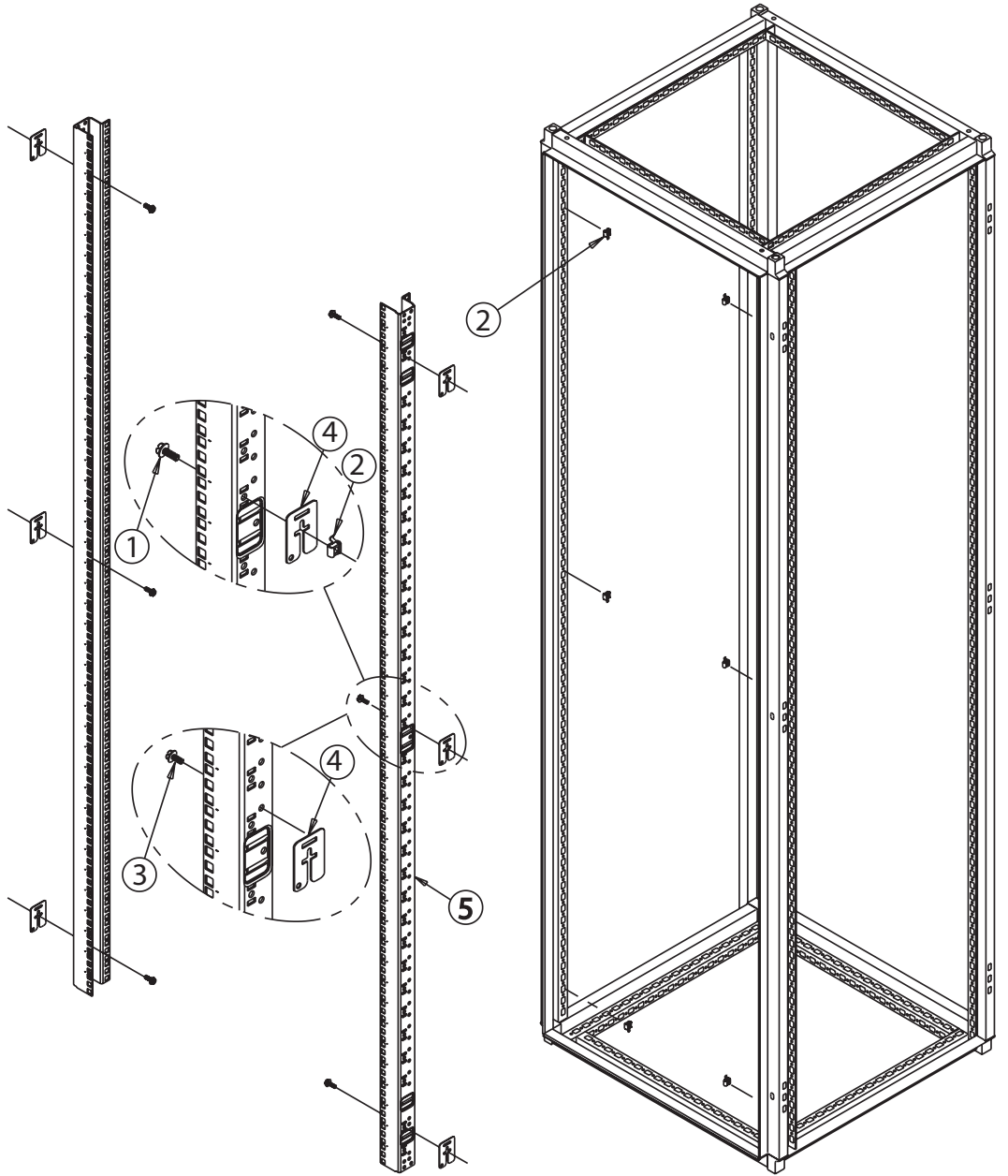
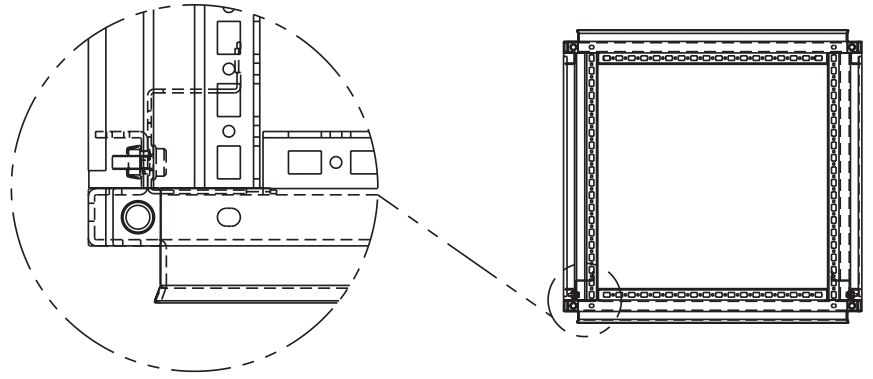
 
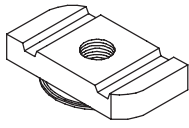





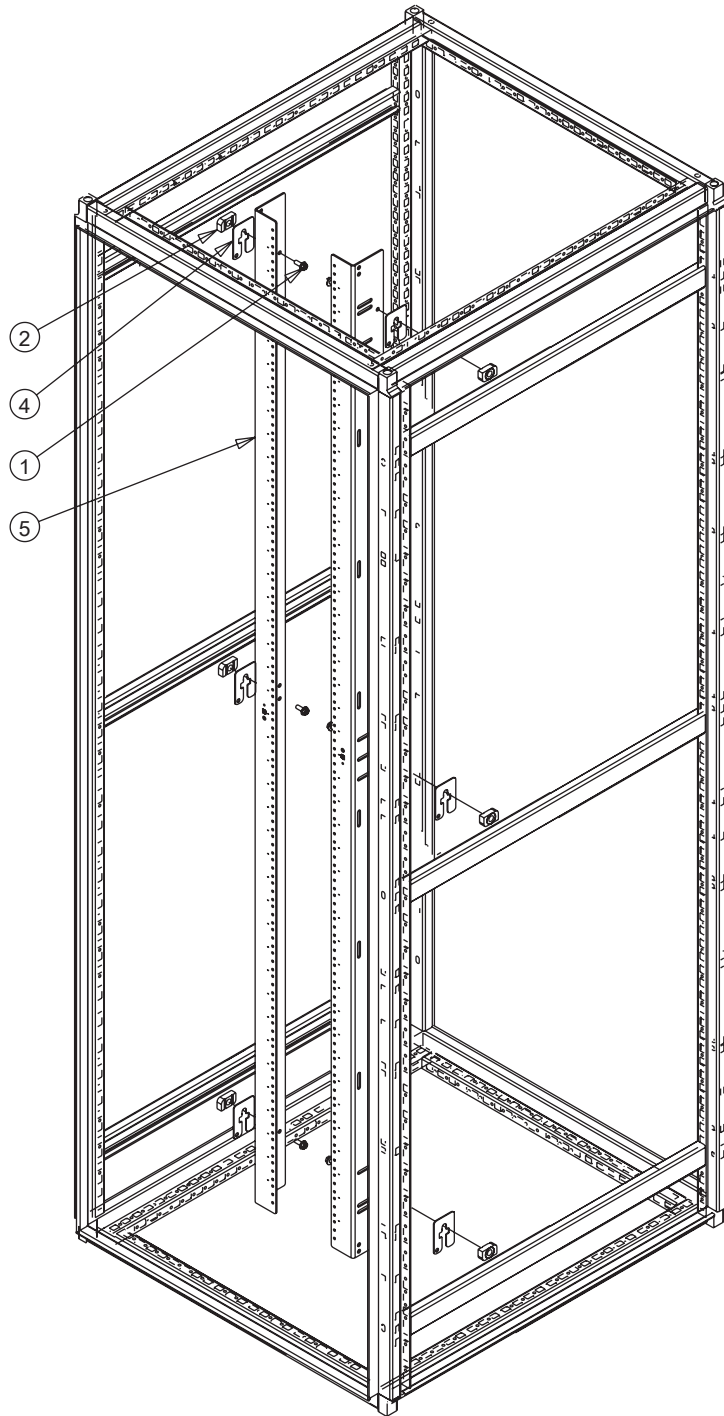
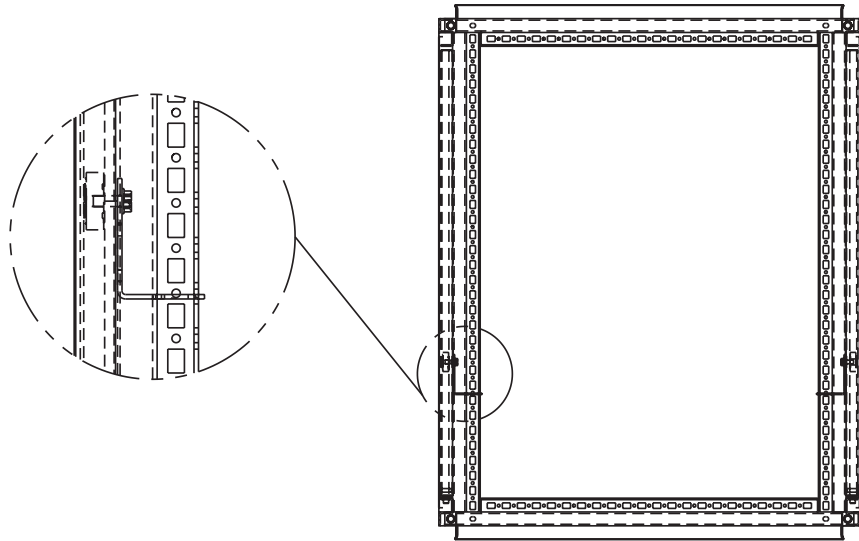
PROLINE™






| | |
|---|---|
| 1 | M6x20  (6x) |
| 2 | M6-1  (6x) |
| 3 | M5x10  (6x) |
| 4 |  (6x) |
| 5 | PRAxxxxTH PRAxxxxTP  (2x) |




| | | | |
|---|----------------------------|---|------|
| 1 | M6x20 |  | (6x) |
| 2 | |  | (6x) |
| 3 | M5x10 |  | (6x) |
| 4 | |  | (6x) |
| 5 | PRAxxxxTHL1 PRAxxxxTPL1 |  | (2x) |



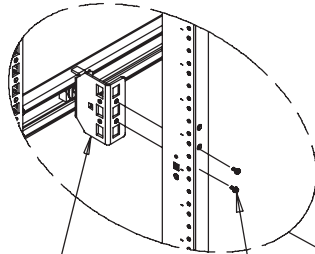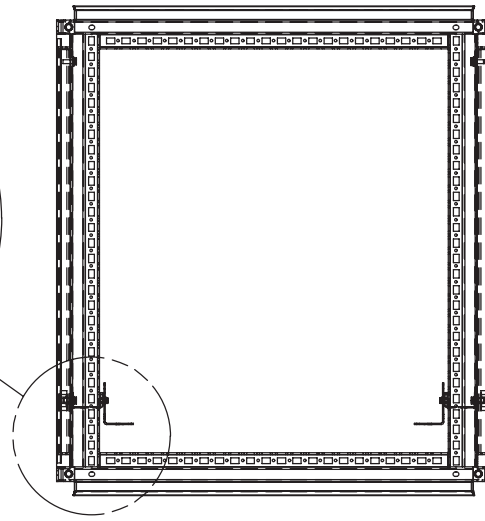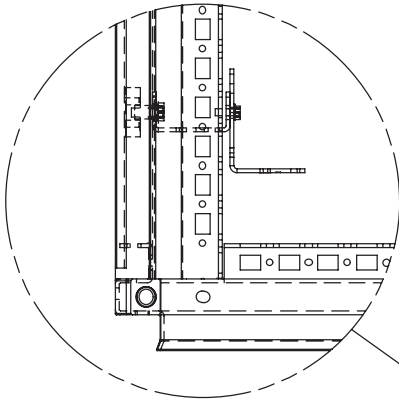


PRB50
PRB100
PRB200

3

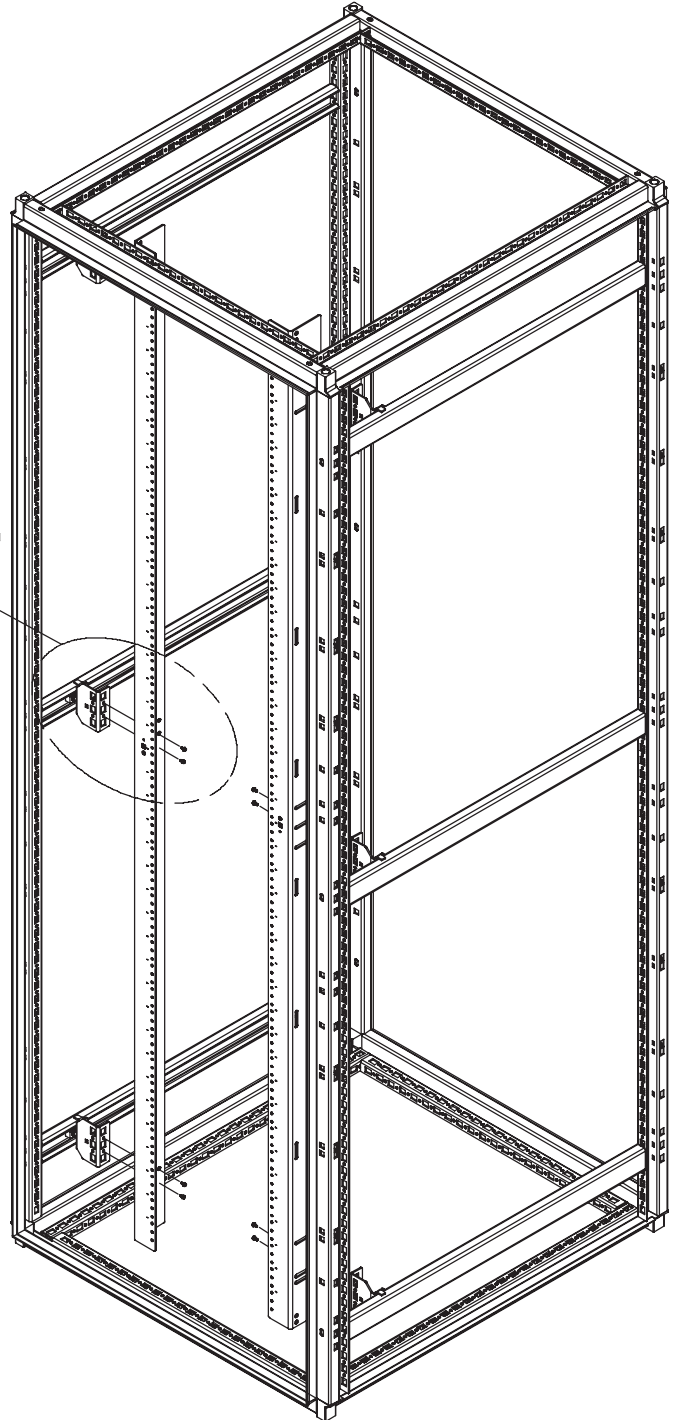


PRB50
PRB100
PRB200

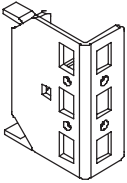

PM6CN

 M6-1



AS1032

10-32

