
 
 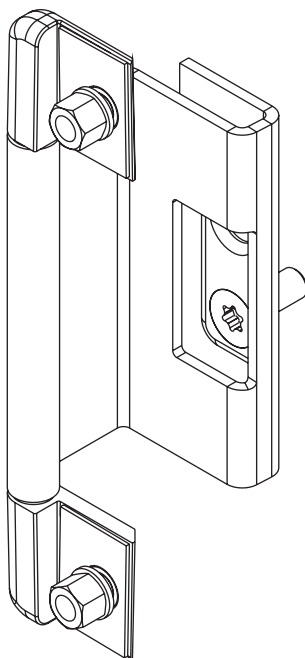
 

 
 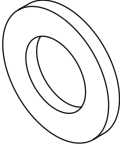







HOFFMAN

PROLINE G2




1  (3x)	2  (3x)	3  (3x)
4  (6x)	5 M6X16  (3x)	6  (6x)
7  (6x)	8  (3x)	9  (6x)

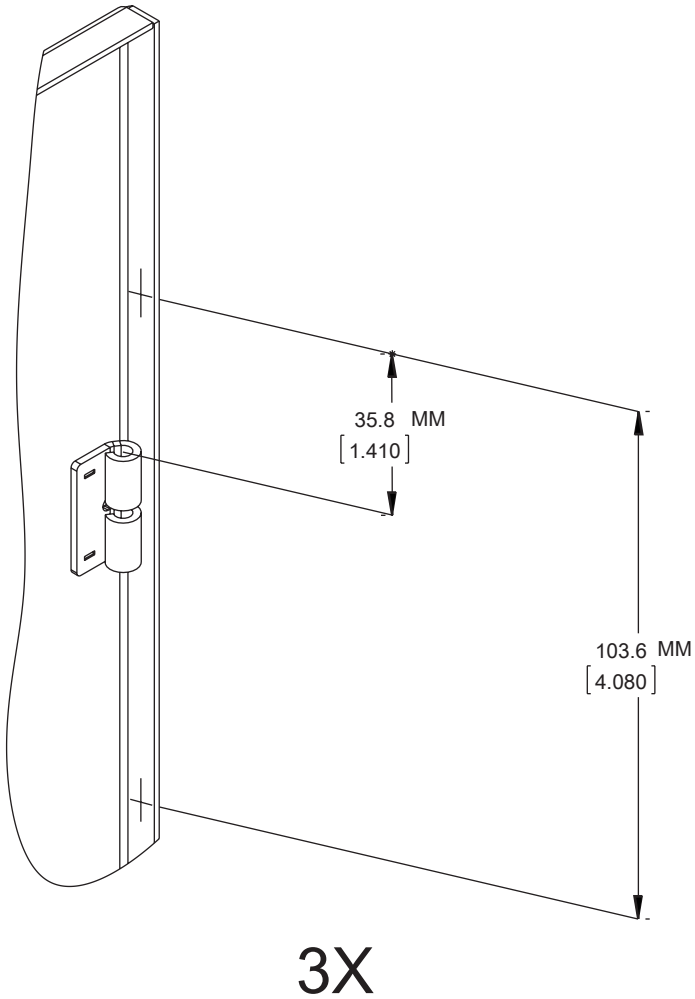


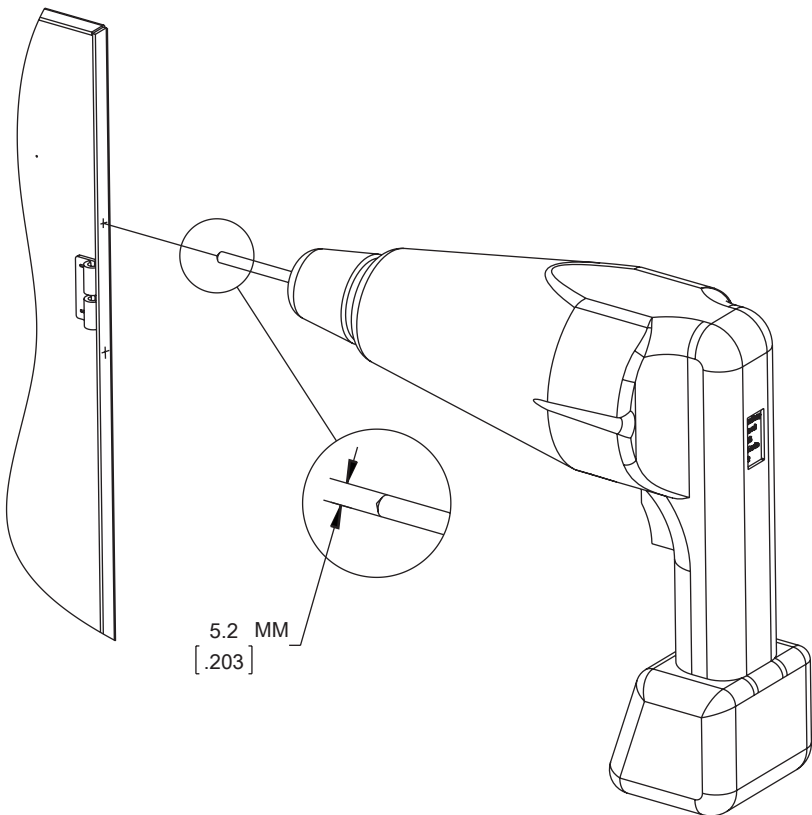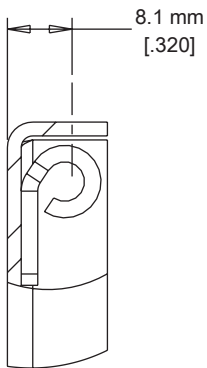


$6.2 \pm 0.6 \text{ N} \cdot \text{M}$
 $[55 \pm 5.5 \text{ LBF} \cdot \text{IN}]$

3X

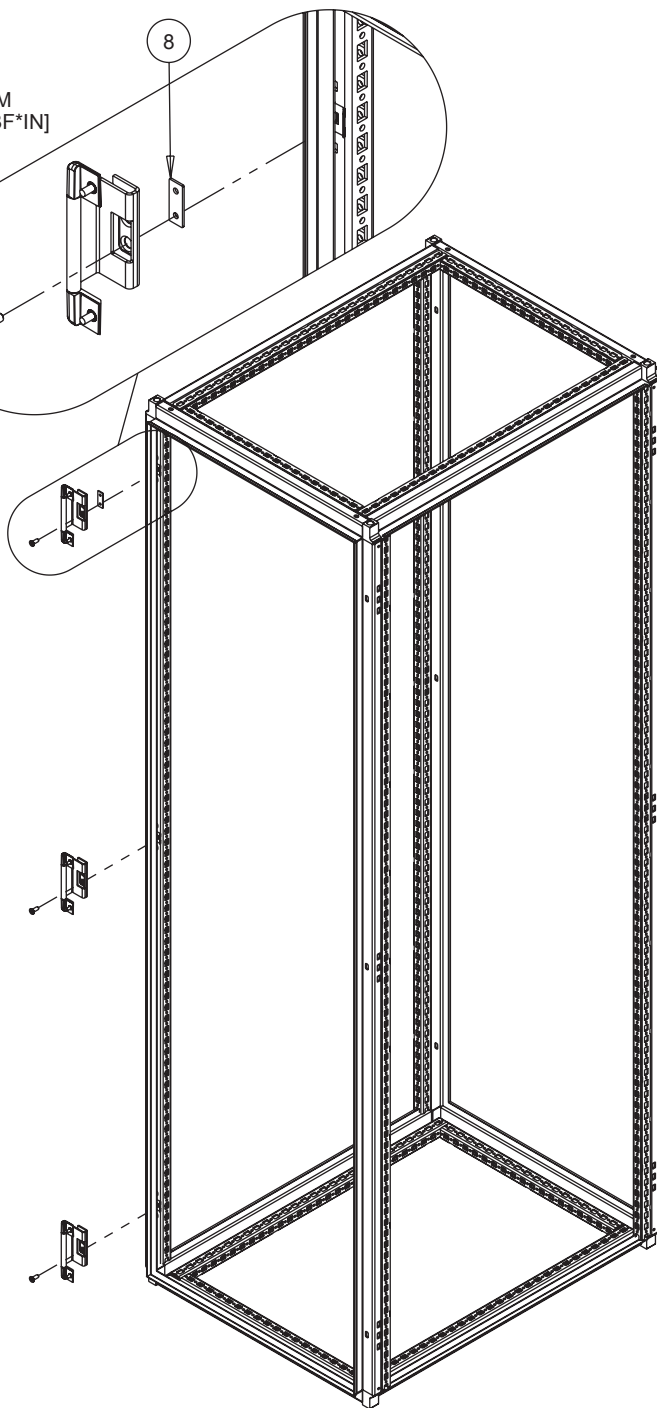

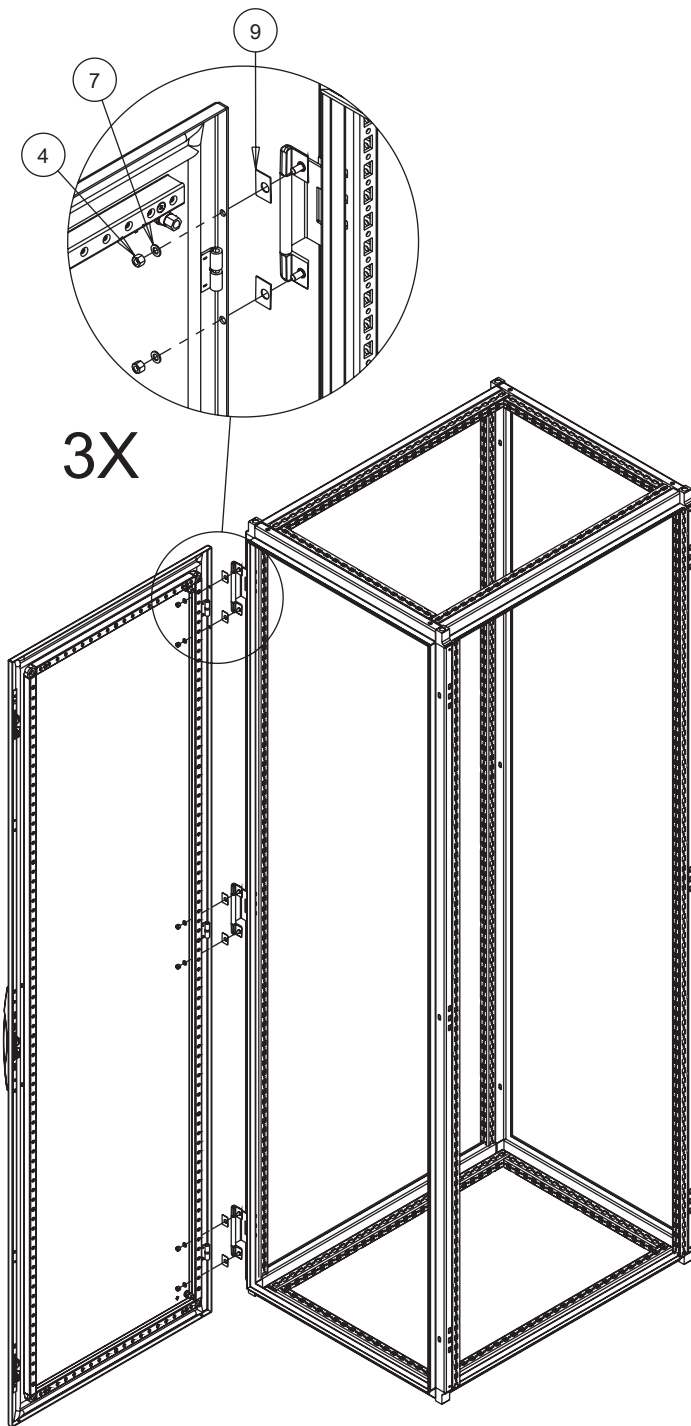

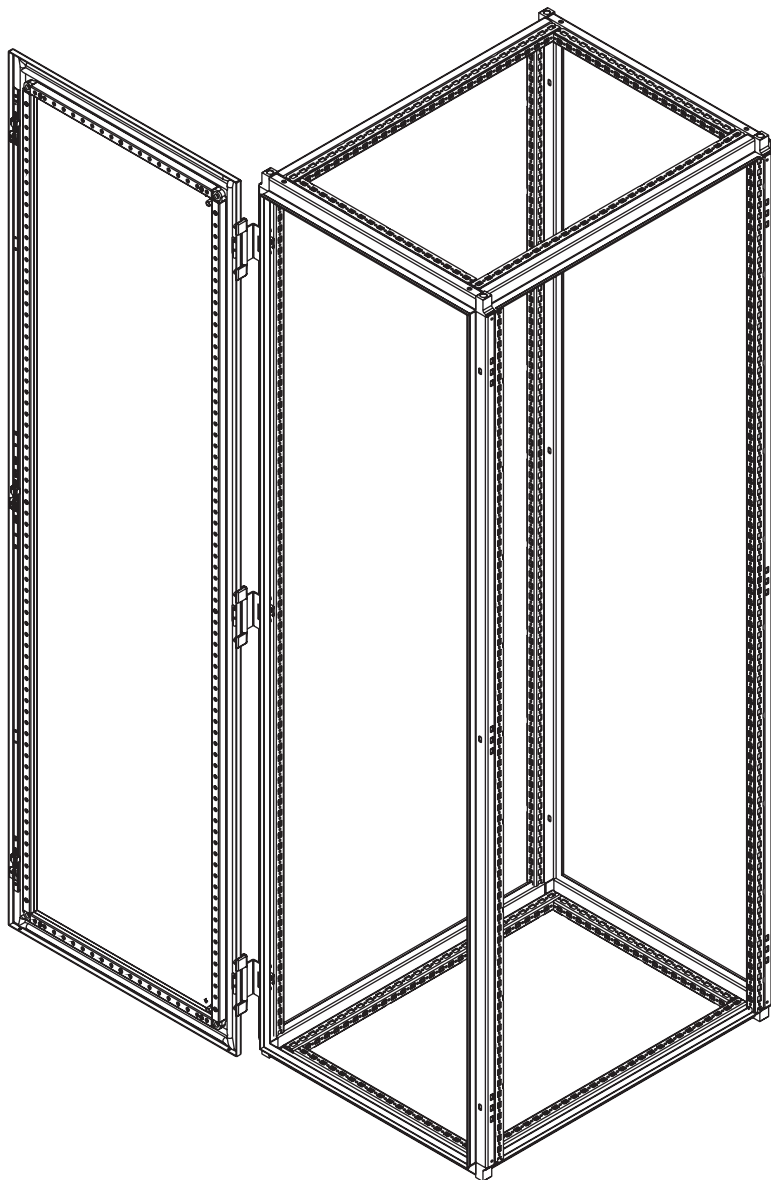



HOFFMAN