

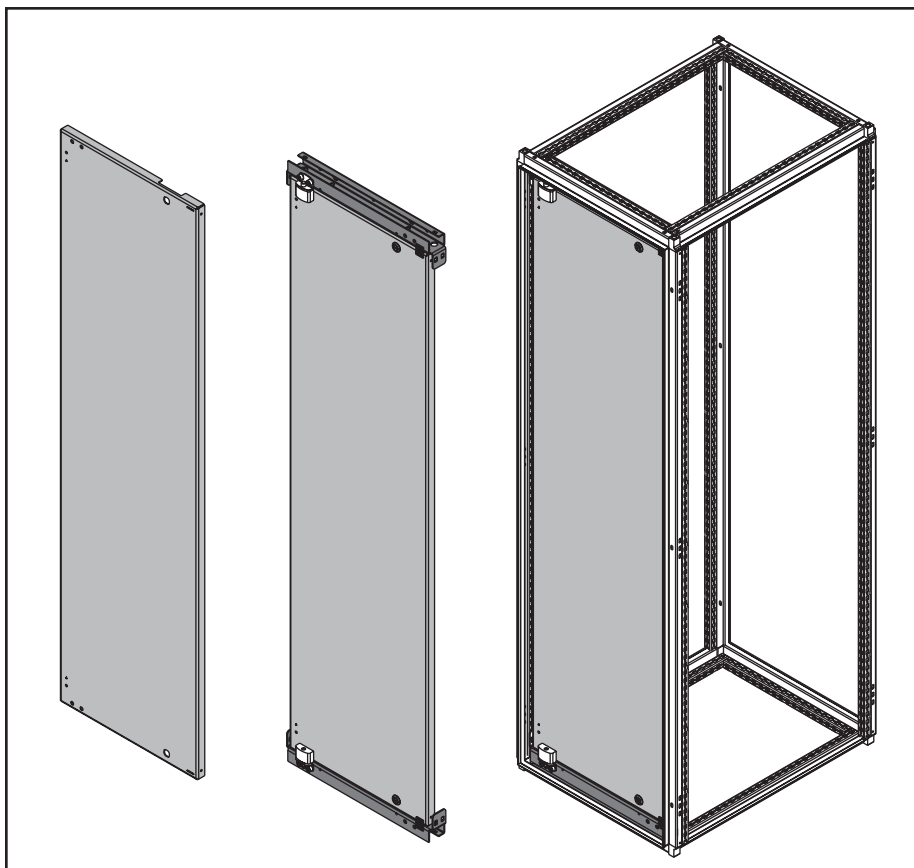
 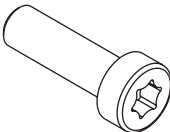
 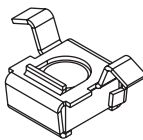
 


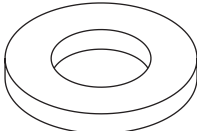
 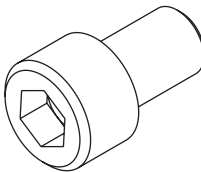
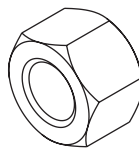

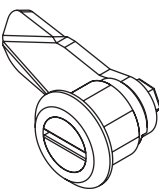




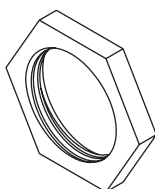




HOFFMAN



PROLINE G2

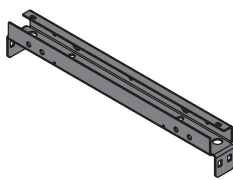


1 M6X20  (6x)	2 M6  (6x)	3 M6  (4x)
4 M6  (2x)	5  (1x)	6  (1x)
7 M10X1.5X16  (8x)	8 M10  (5x)	9 M10  (9x)
10  (2x)	11 M22  (2x)	12  (2x)

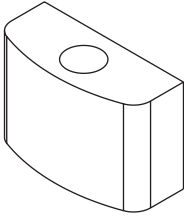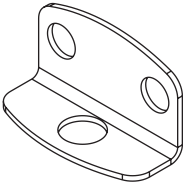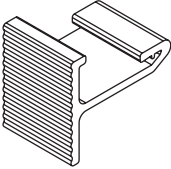
13  (2x)	14  (1x)	15  (1x)
16  (1x)	17  (1x)	18  (2x)
19  (2x)	20  (1x)	

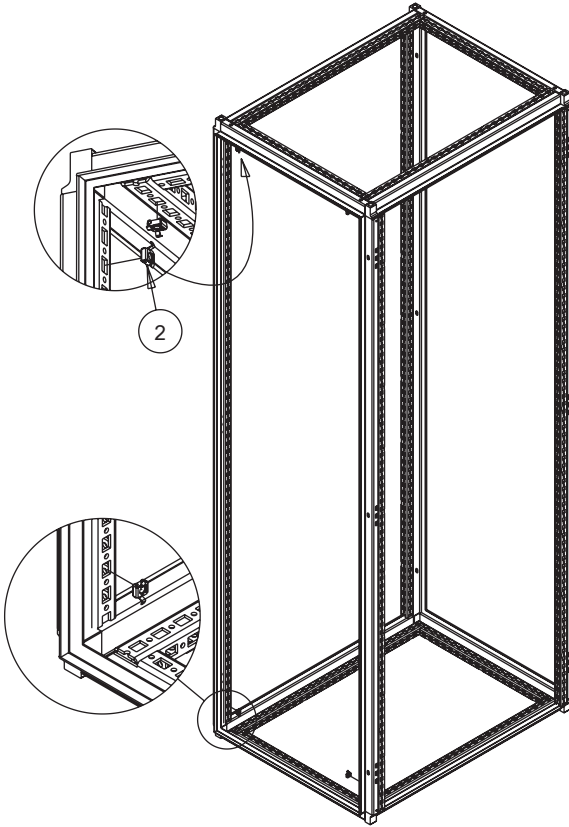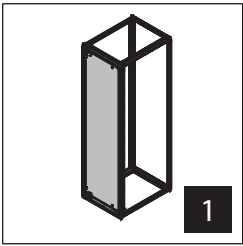

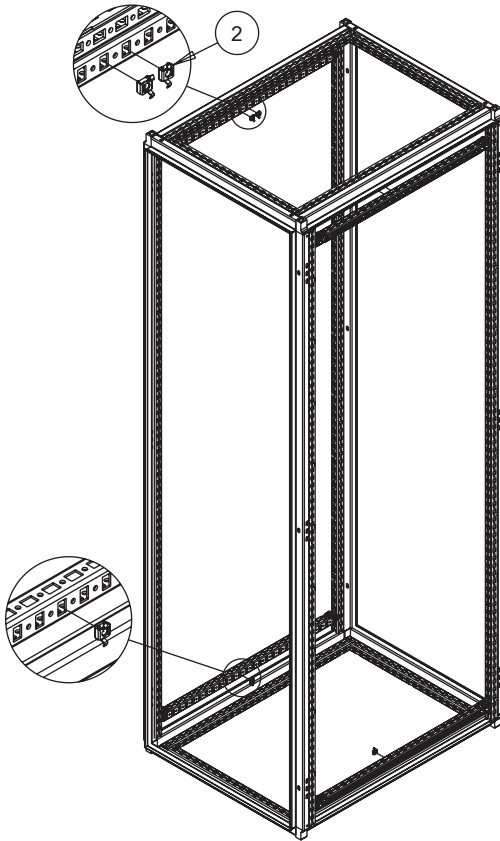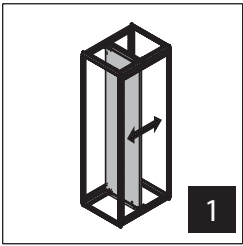


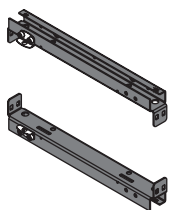




(L)

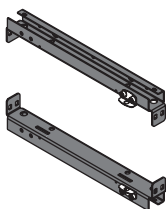


(R)

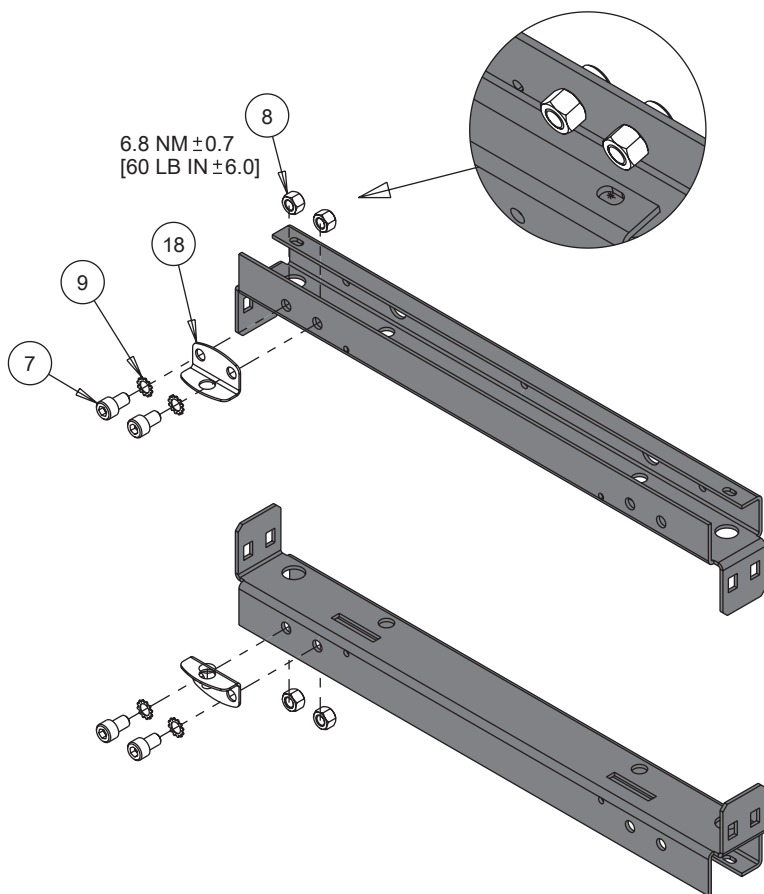


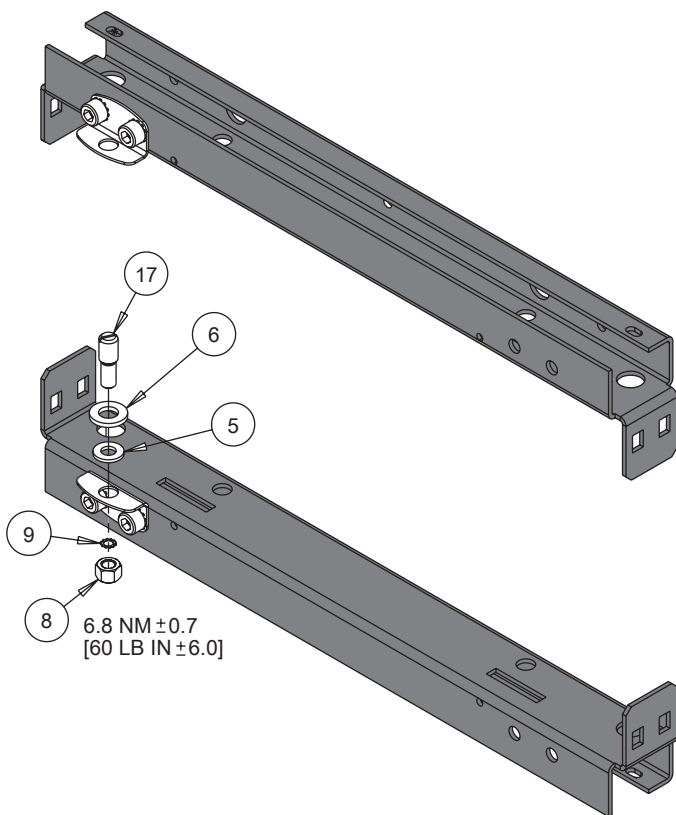


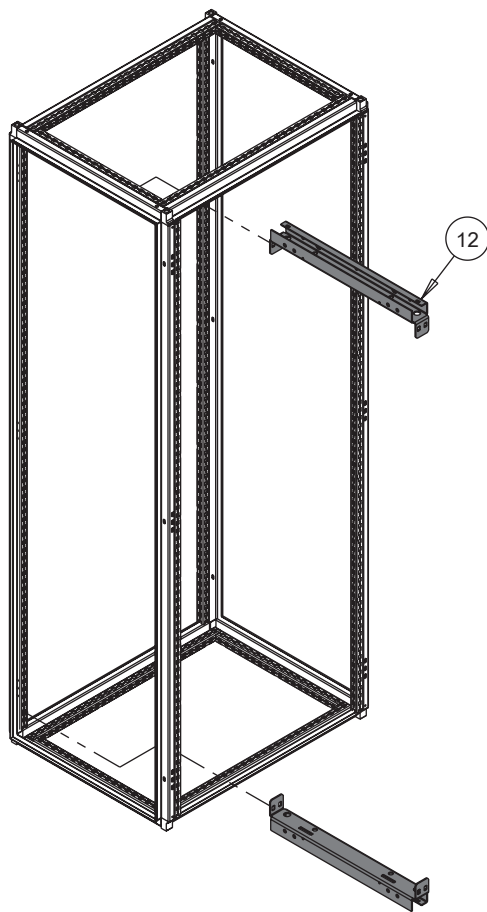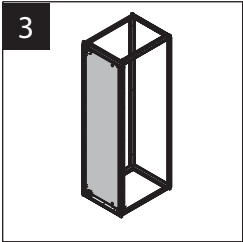


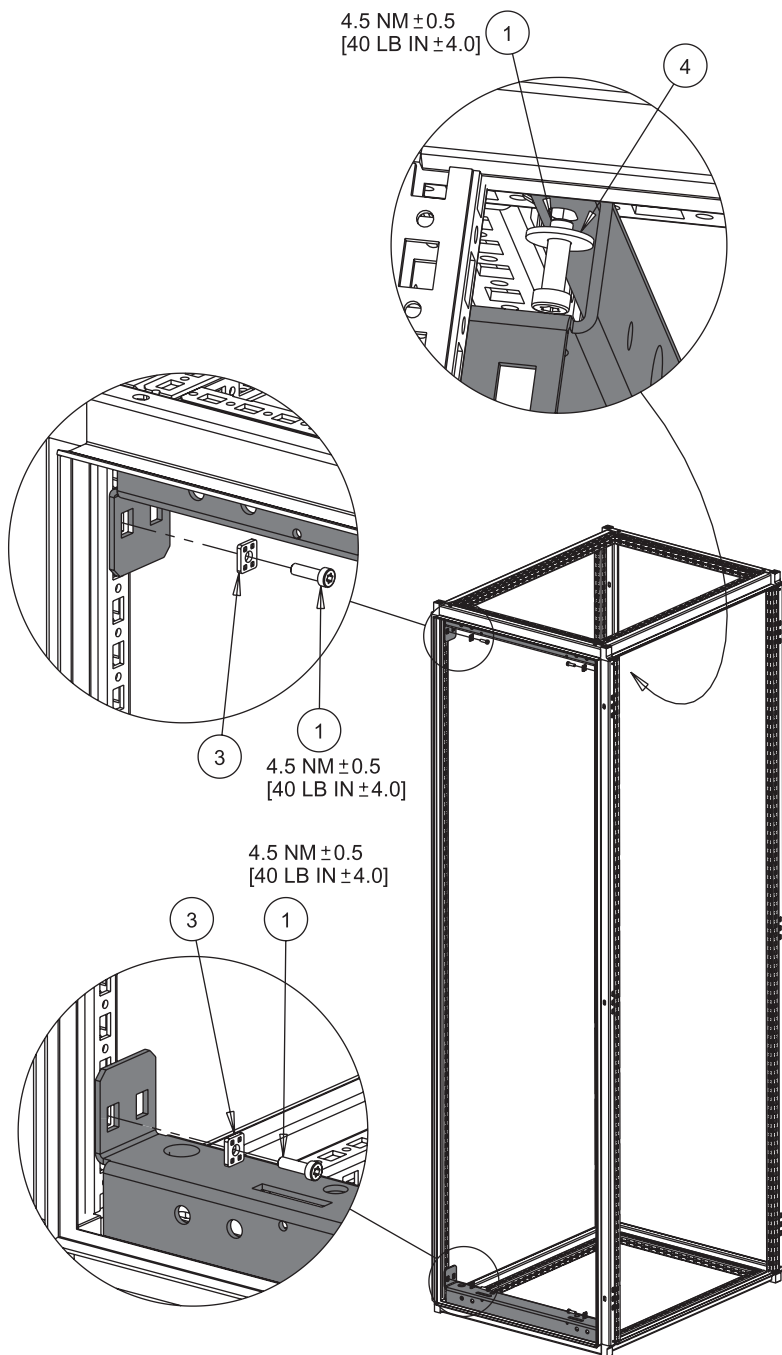




3

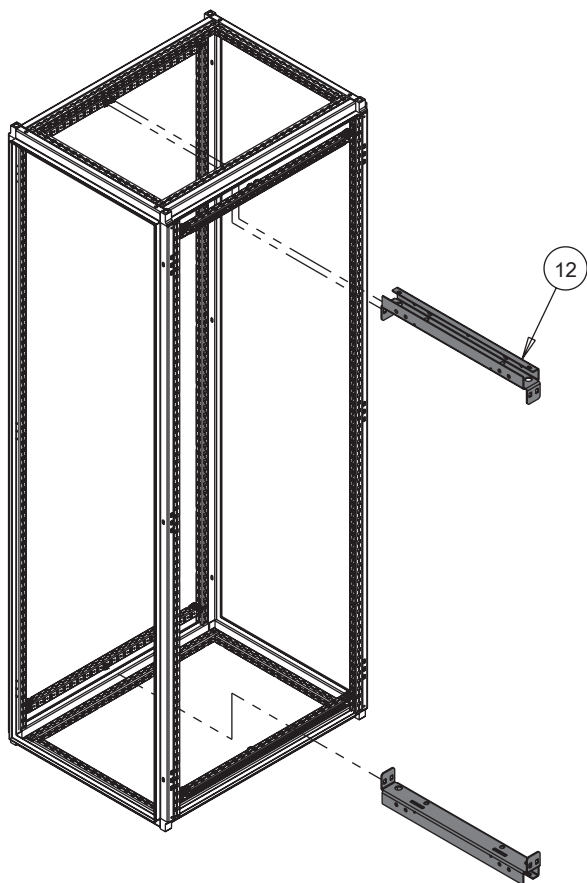


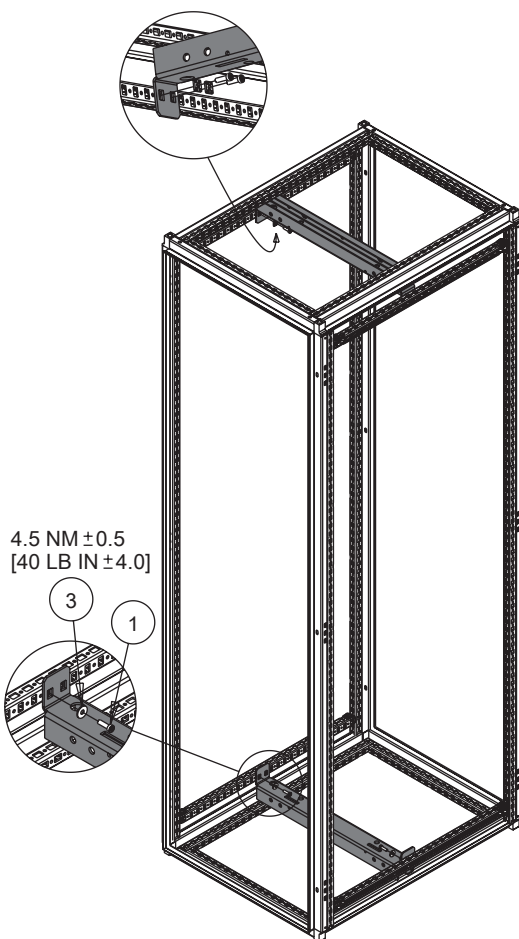

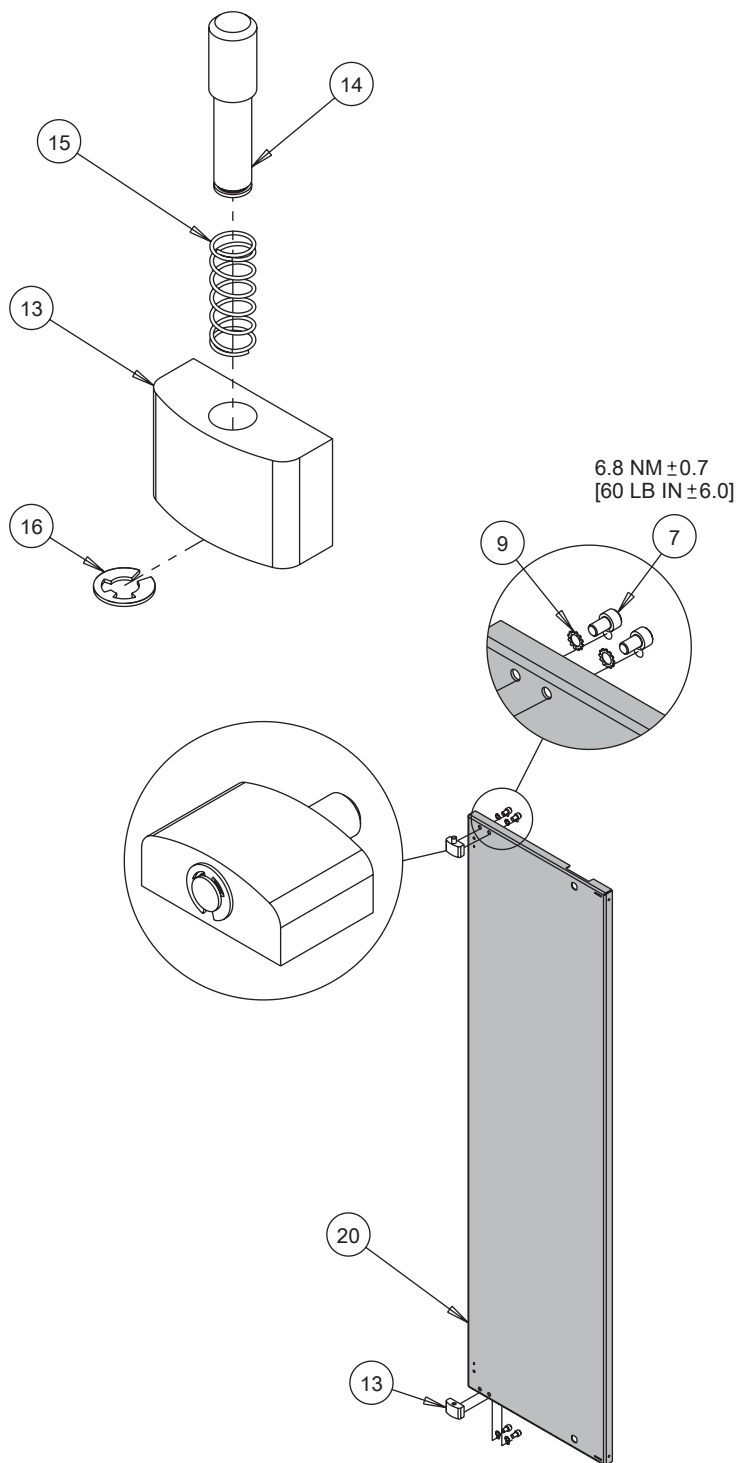

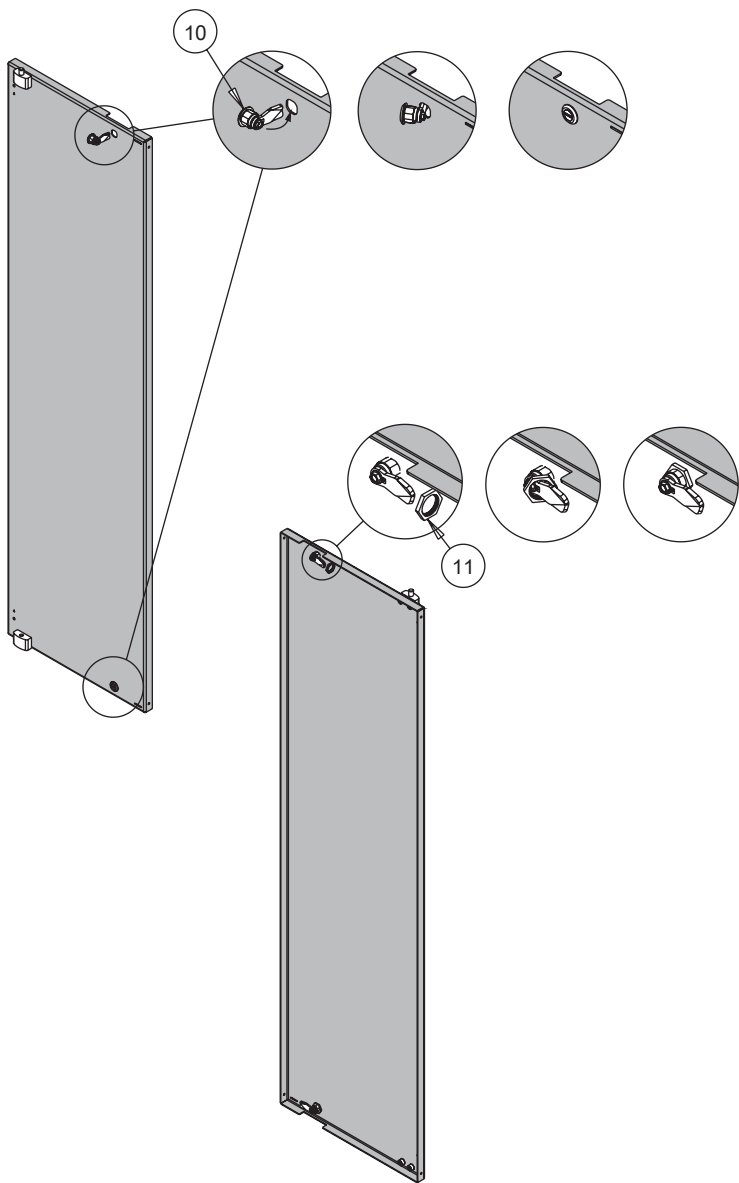

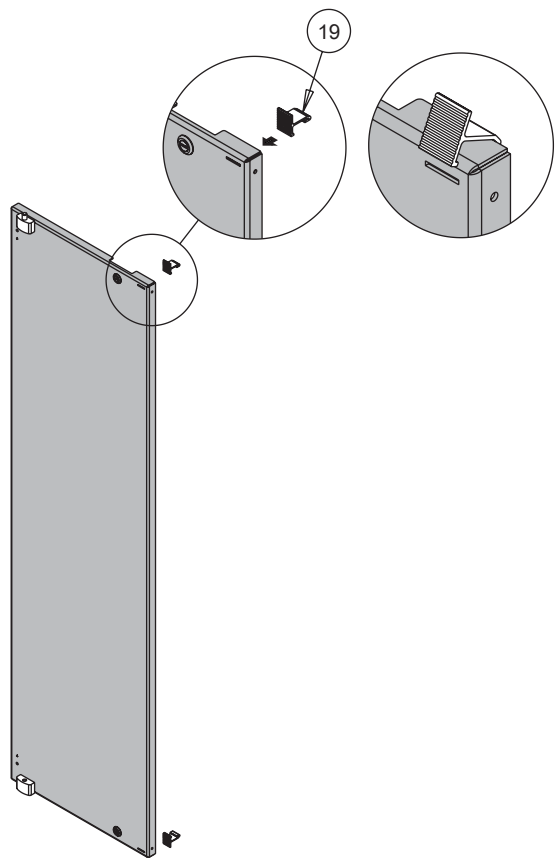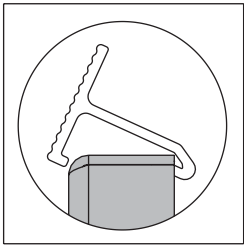

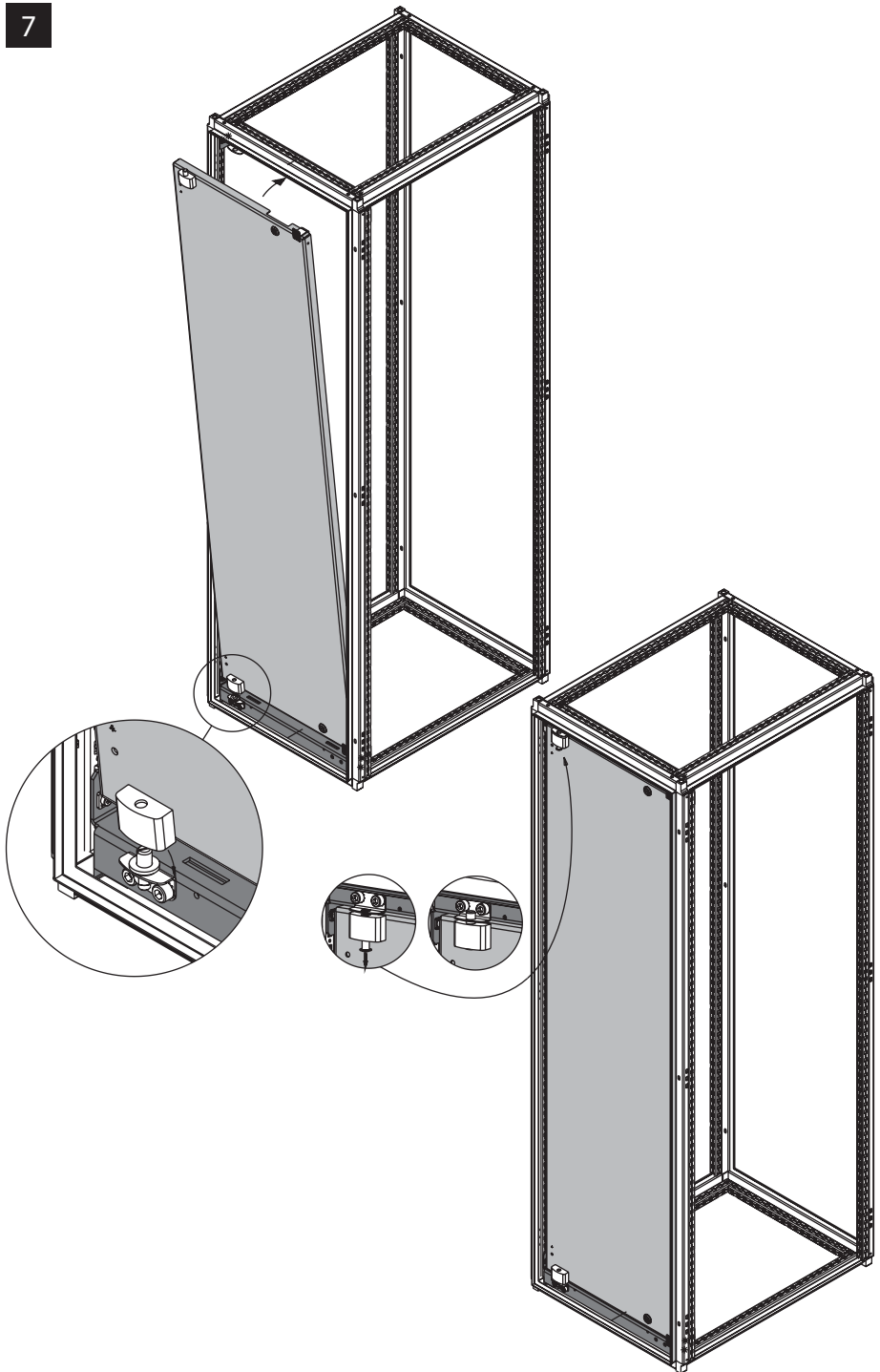



HOFFMAN