

 
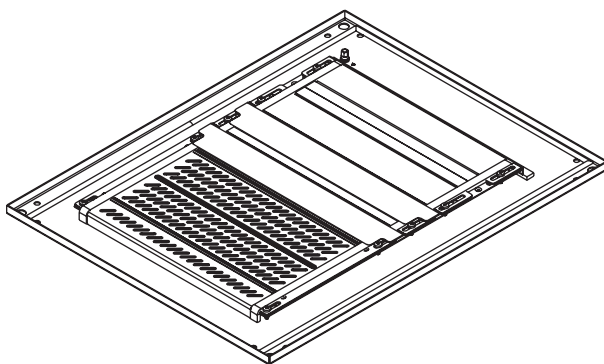
 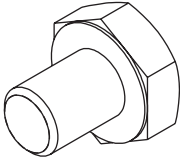
 
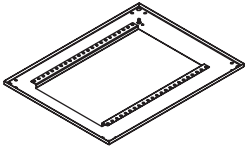


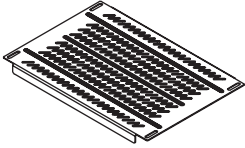
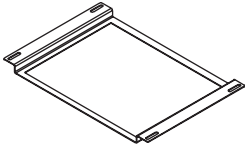



ProLine G2

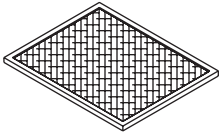


1 M12X16  (4x)	2  (4x)	3 M6X16  C (mm) 500.....(6x) 600.....(8x) 800.....(10x)
4  (1x)	5  (1x)	6  C (mm) 500.....(0x) 600.....(1x) 800.....(2x)
7  (1x)	8  (1x)	9  (1x)


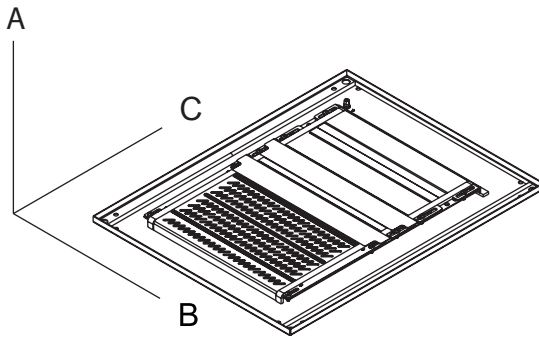


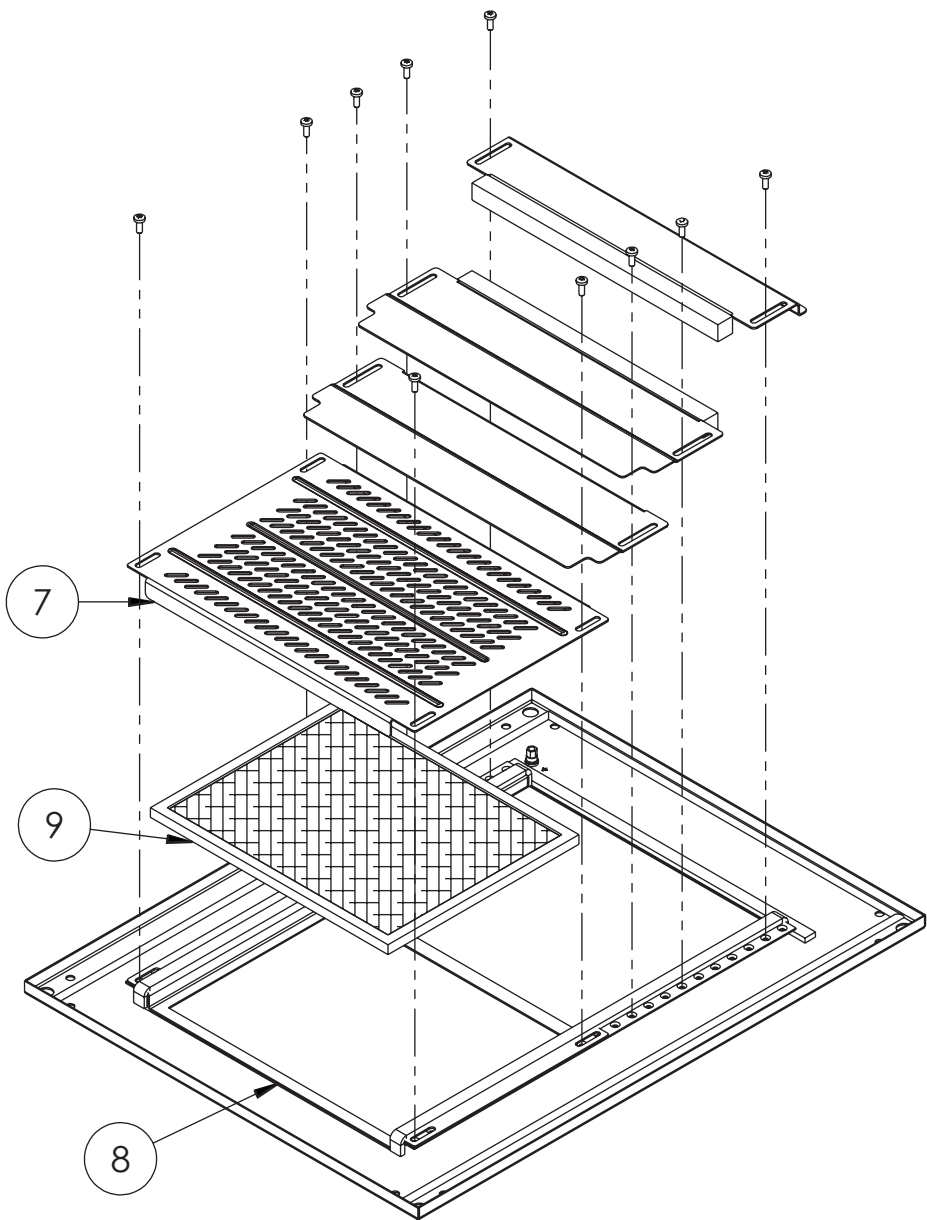

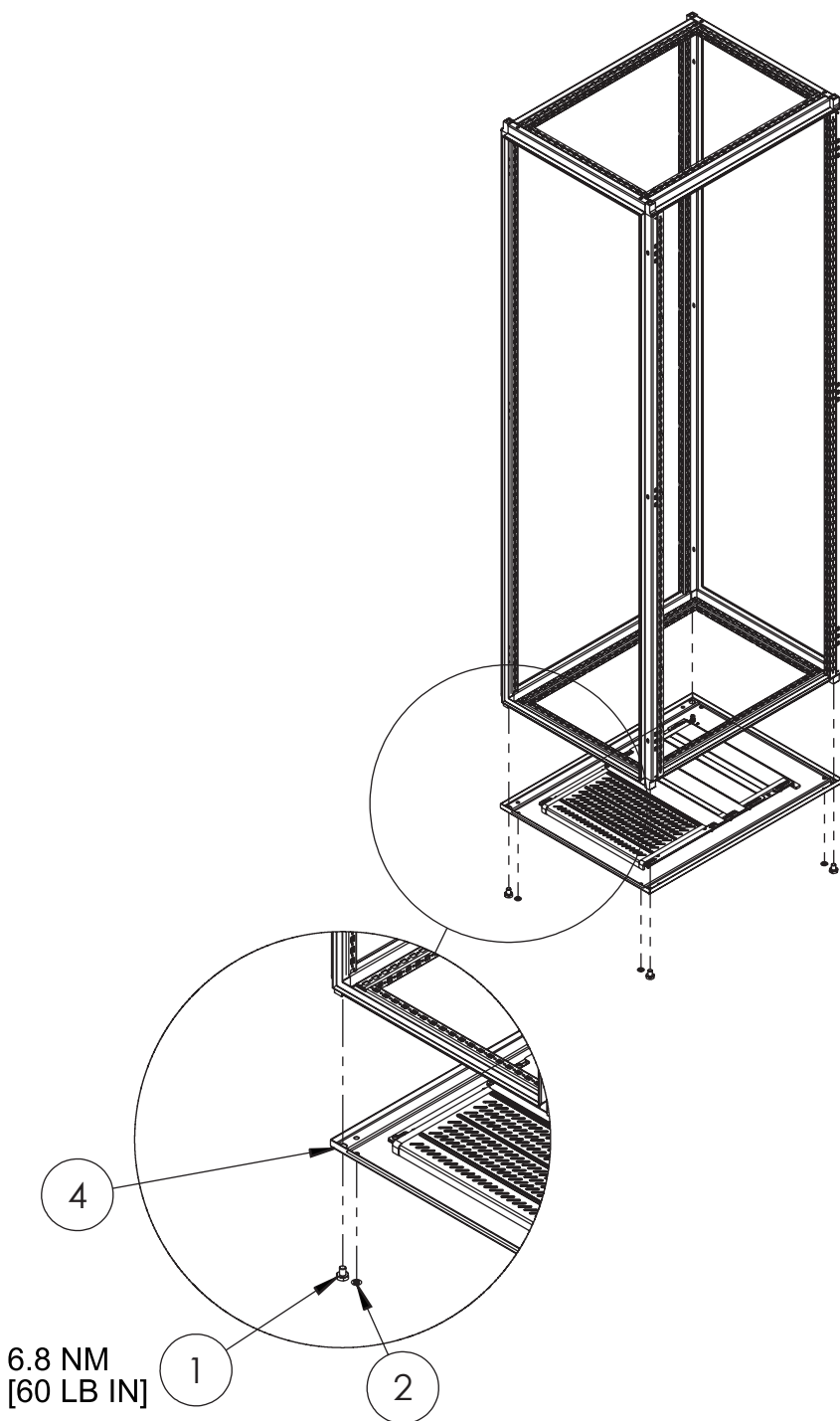

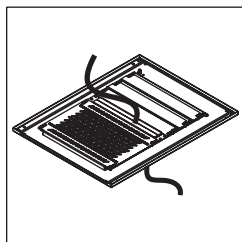



A1

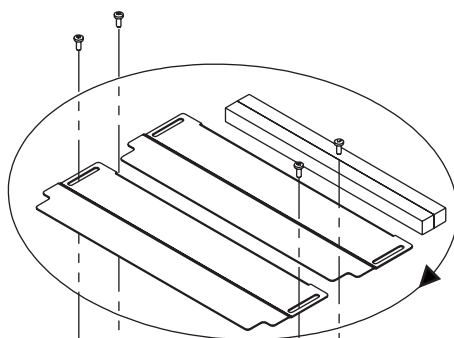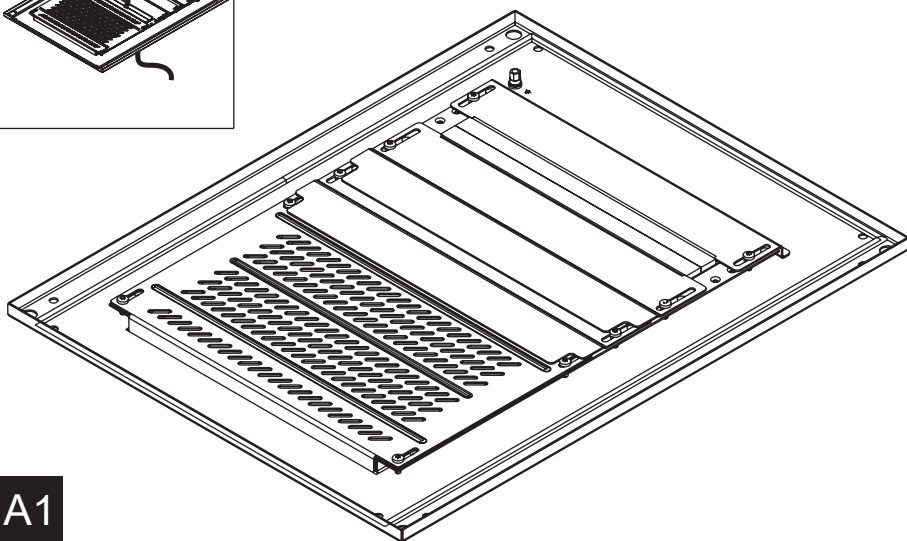





180°

A2

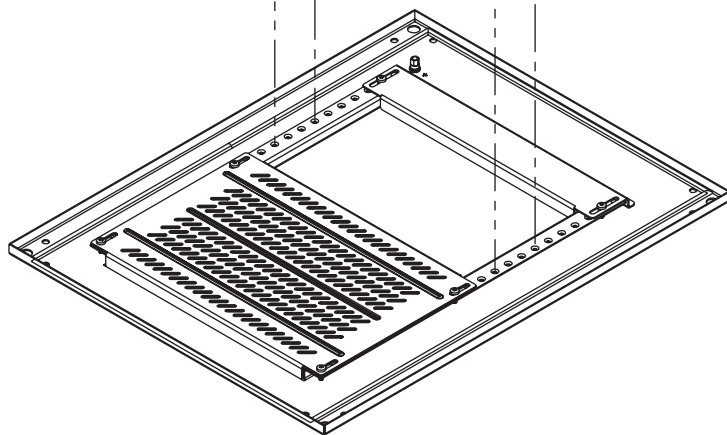


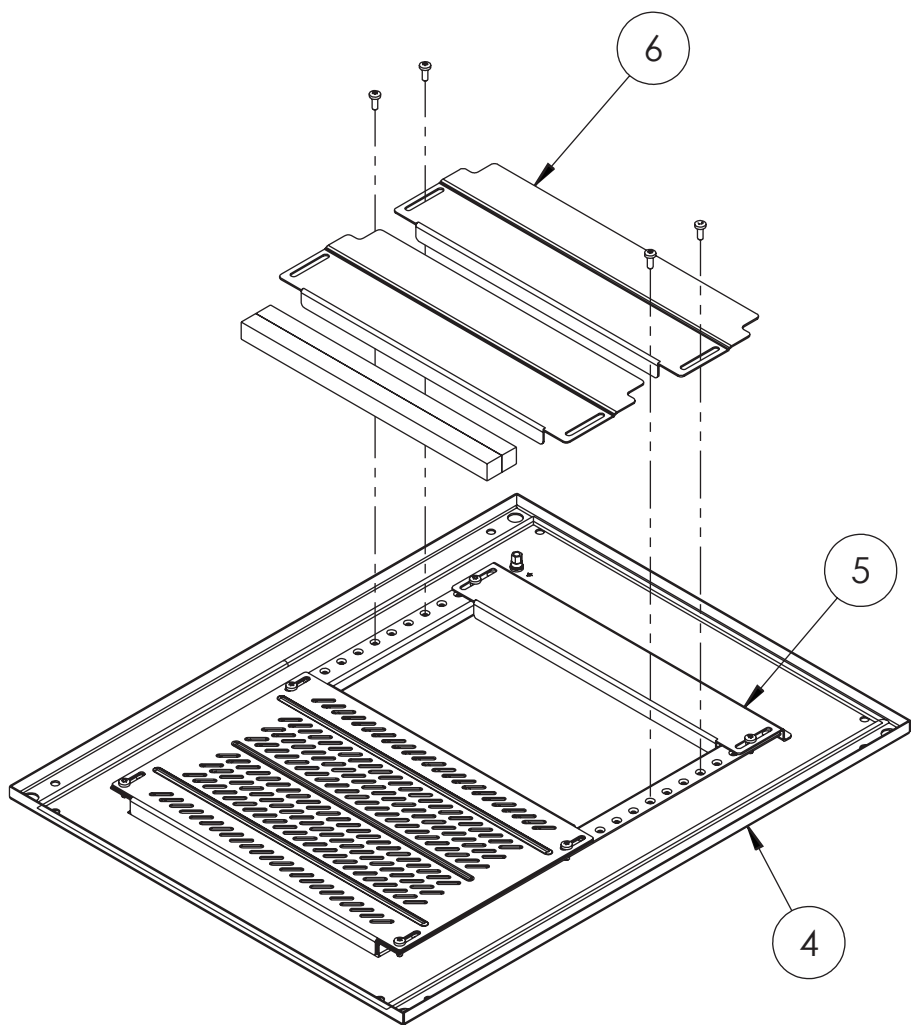


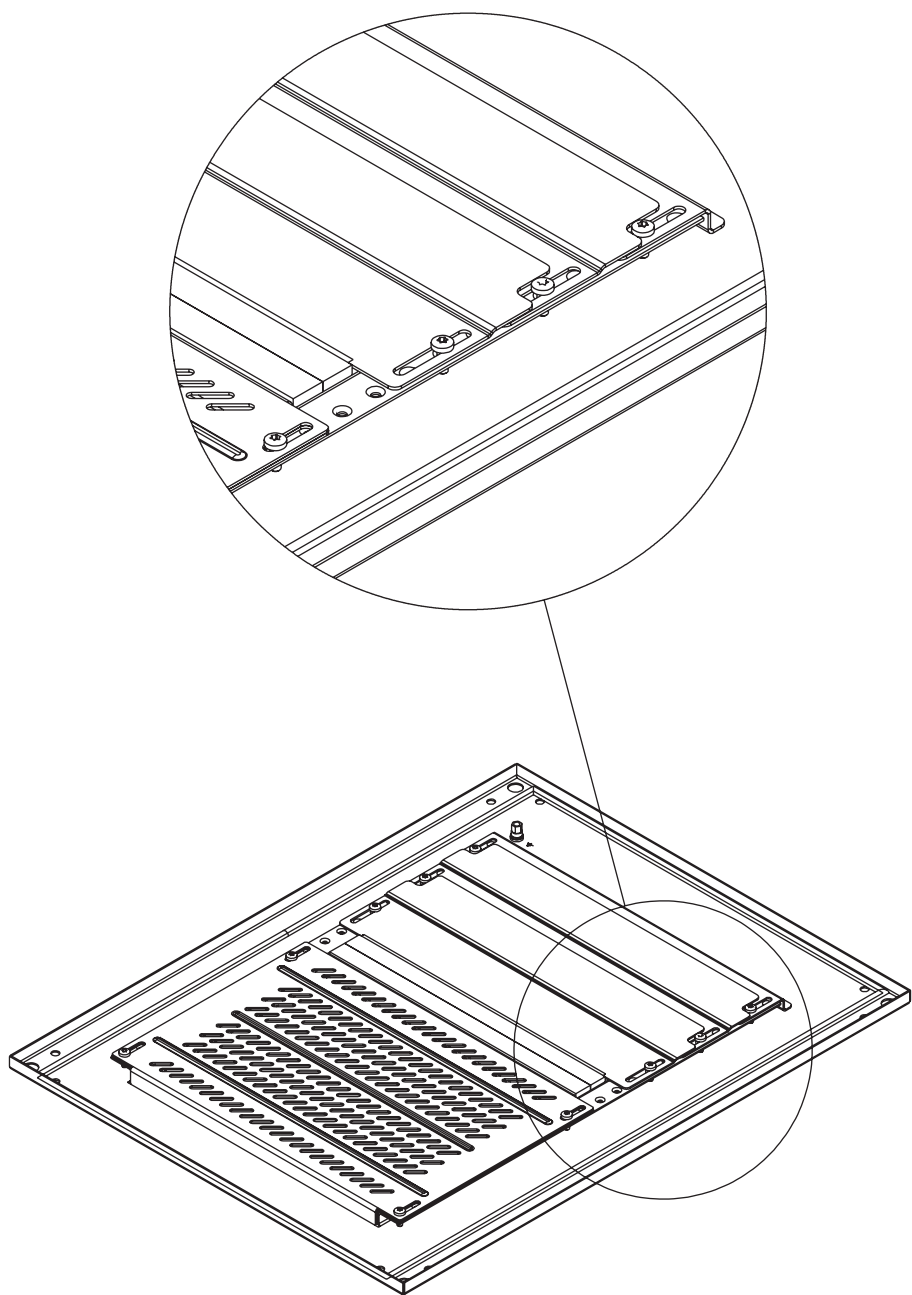

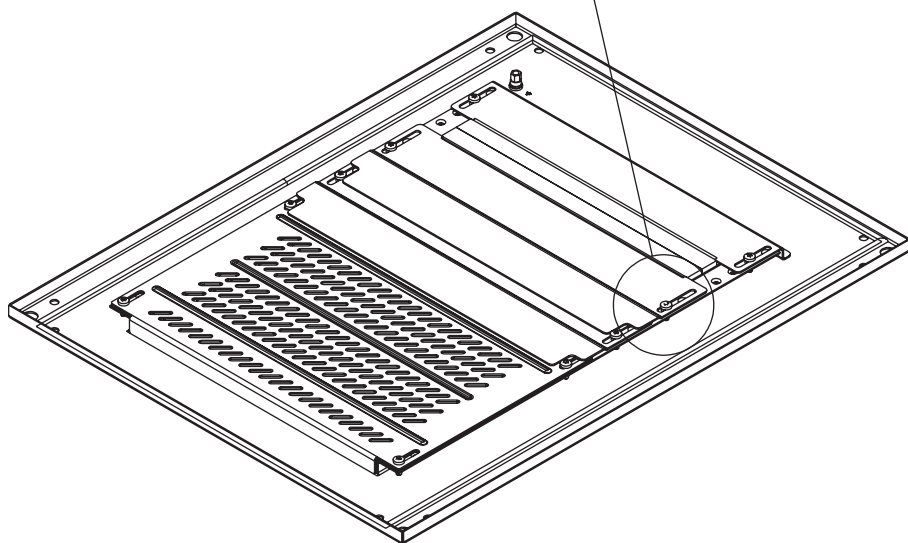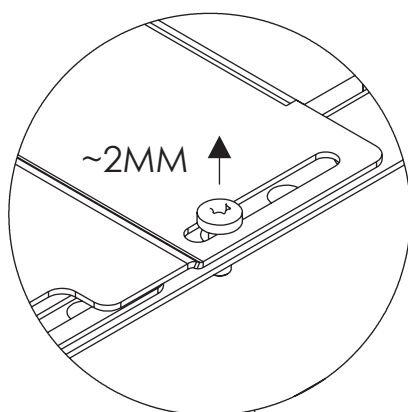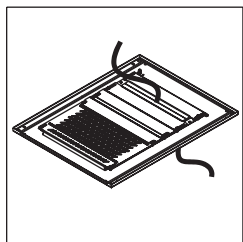



B1

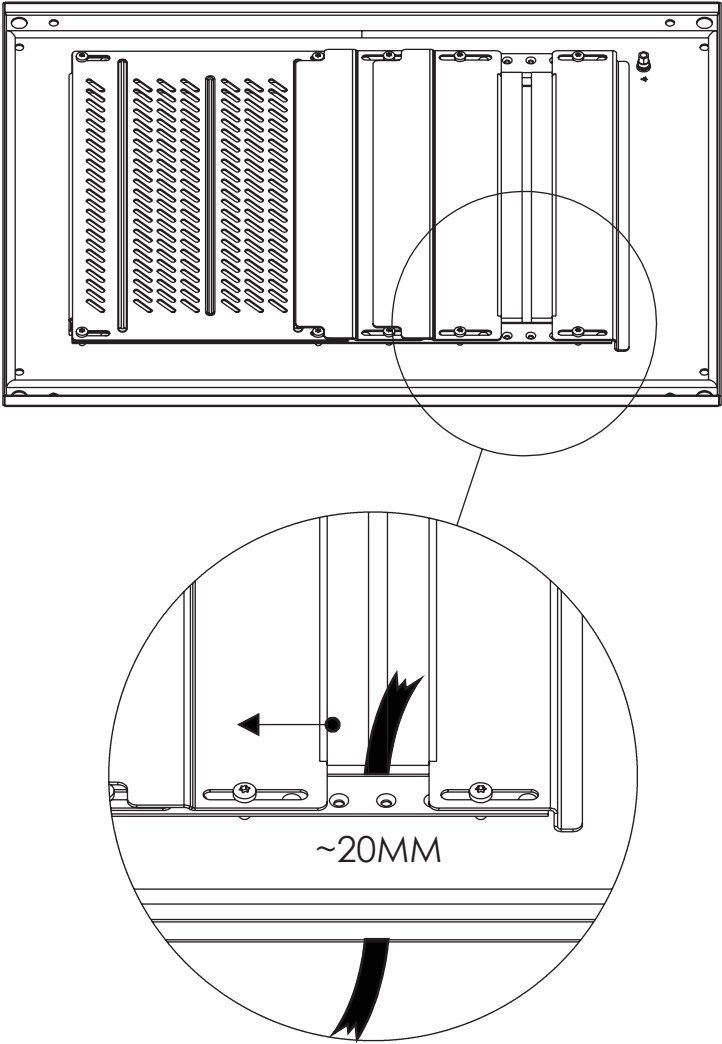

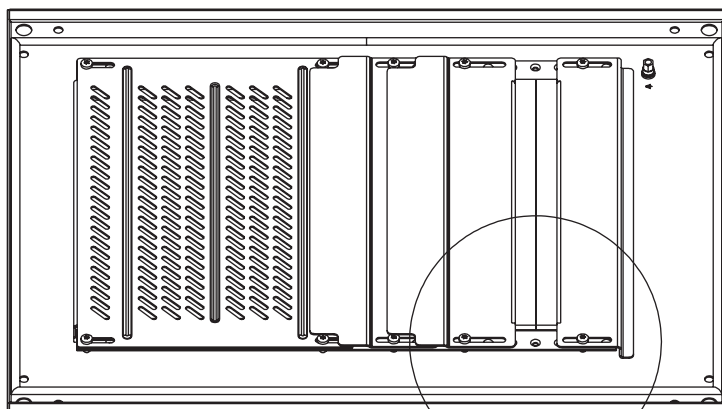

4.0 NM
[35 LB IN]

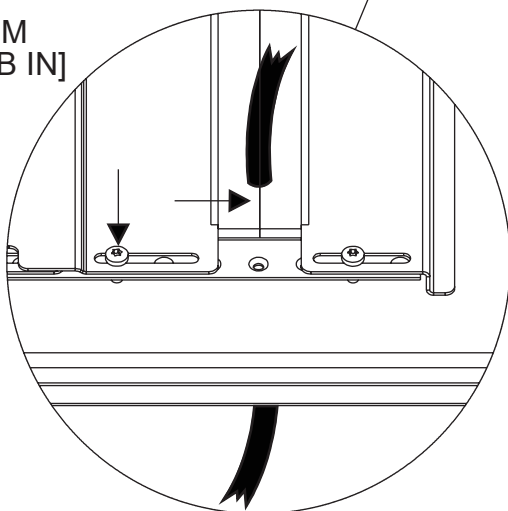

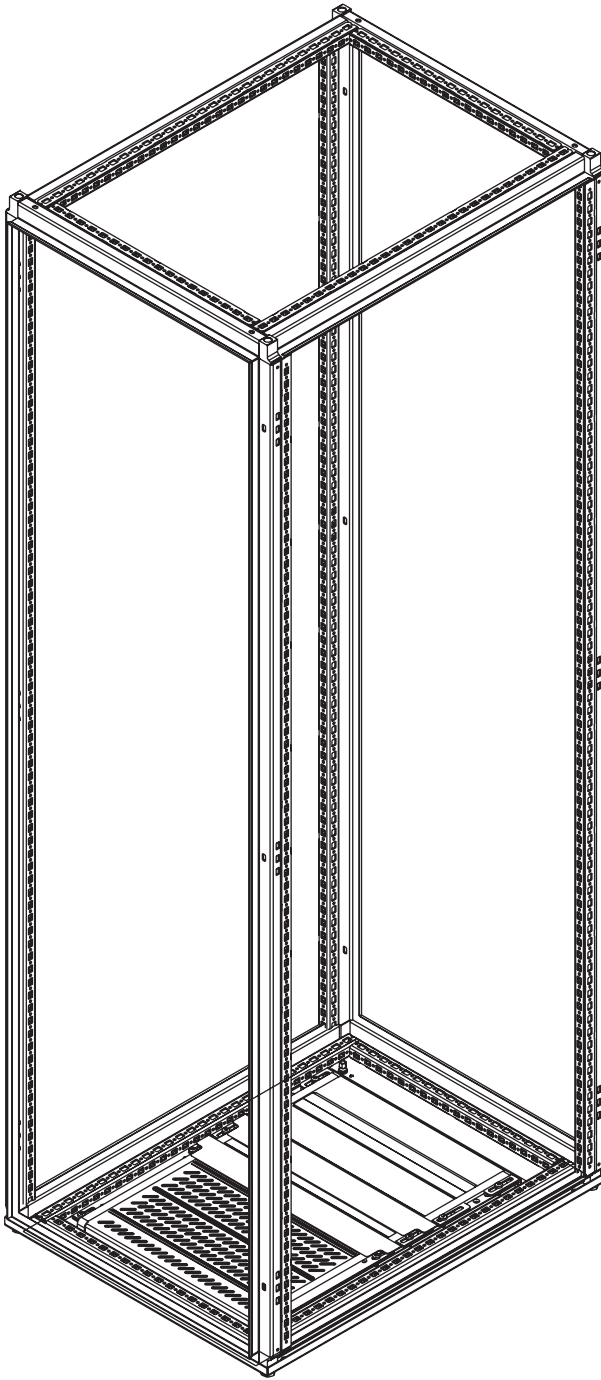

B4

