

## FEATURES & SPECIFICATIONS

### INTENDED USE

Low voltage reflector for use with Non-IC housings LV3, LP3V, LV3R and IC housing LIV3.

### CONSTRUCTION

30 degree vertical tilt standard.

350 degree horizontal rotation.

White integral flange.

### INSTALLATION

Retaining clips attached to trim ring to hold trim inside housing.

### LISTINGS

UL Listed to US and Canadian safety standards.

Damp location listed.

### WARRANTY

1-year limited warranty. Complete warranty terms located at [www.acuitybrands.com/CustomerResources/Terms\\_and\\_conditions.aspx](http://www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx)

Actual performance may differ as a result of end-user environment and application.

Note: Specifications subject to change without notice.

Catalog Number
Notes
Type

4" Finishing Trim

# 3VE1

**STANDARD EYEBALL**

Low Voltage

Narrow Flange




### Specifications

Height: 2 (5.1)

Lamp opening: 2 (5.1)

Diameter: 5 (12.7)

All dimensions are inches (centimeters) unless otherwise indicated.

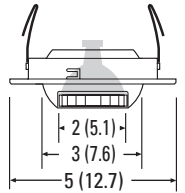

### ORDERING INFORMATION

Lead times will vary depending on options selected. Consult with your sales representative.

**Example: 3VE1**

3VE1	
Series	Finish
3VE1	(blank) White

### Housing Compatibility: Housing and trim ordered separately.

Application	Source	Maximum wattage	Housing
IC	Low Voltage/12V	50 MR16	LIV3
Non-IC	Low Voltage/12V	50 MR16	LV3, LV3R
	Low Voltage/12V	75 MR16	LP3V

# 3VE1 4" Standard Eyeball Low Voltage Trim

---