

# Lighting Controls

DATE: \_\_\_\_\_ LOCATION: \_\_\_\_\_

TYPE: \_\_\_\_\_ PROJECT: \_\_\_\_\_

CATALOG #: \_\_\_\_\_

## OUTDOOR LUX METER SENSOR

DLC SERIES

**wiSCAPE™**

### FEATURES

- Continuous dim operation with 0-10V output
- Foot-candle range: 0-260FC
- Mounts horizontally
- UL and cUL list
- California Title 24 Compliant
- Low voltage device: 24 VDC
- 5 year limited warranty



### SPECIFICATIONS

#### CONSTRUCTION

- White

#### ELECTRICAL

- Input Voltage: 24VDC
- Output Voltage: 10v full output
- Output Offset: 0VDC or 1VDC - total darkness
- Three conductors 18-gauge standard cable
  - Red: Pos. DC input
  - Black: DC common
  - Yellow: Output to EMS

#### OPERATION

- Sensor Type: Blue-enhanced photo diode
- Sensor Range: 0-250FC

#### OPERATING ENVIRONMENT

- 13° to 140°F (-11° to 60°C)

#### CERTIFICATIONS

- ETL/UL 916 listed
- Title 24 listed
- RoHS compliant

#### WARRANTY

- 5 year limited

### ORDERING GUIDE

Example: DLPCO

CATALOG #


DLC	PC	O
Model	Type	Rating/Range
DLC Daylighting Controls	PC Photocell Sensor	O Outdoor, 0-250FC

# Lighting Controls


## OUTDOOR LUX METER SENSOR

DLC SERIES

### DIMENSIONS

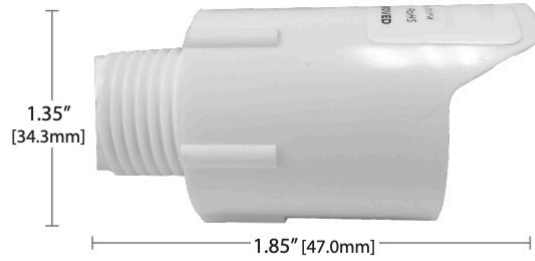

### WIRING DIAGRAMS

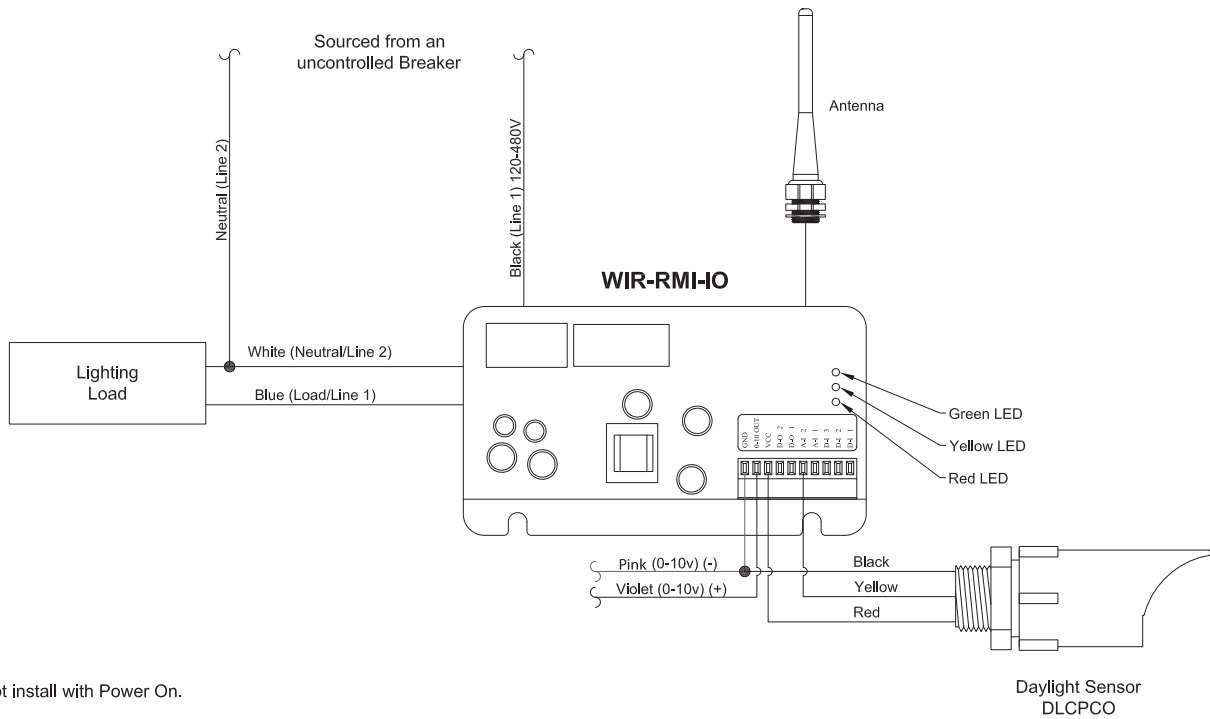

**Note:**

Do not install with Power On.

Pink wire replaces previous gray wire. Units with a gray instead of pink wire should be wired as the pink wire shown in the diagram.