



Type IC, Wet Location & Air-Tight


DESCRIPTION

4" Round Recessed Gimbal LED fixture
 Regressed optics with low glare
 Adjustable 20° each direction and with 360° rotation

FEATURES & BENEFITS

3 light options - 3000K, 5CCT selectable, Dim to Warm 3000K-1800K
CRI 90+ for true color rendering
2 1/4" Deep - fits in limited ceiling space
Type IC Rated - no housing required
Fast & Easy to install - save on labor
Driver Inside Connection Box - no junction box needed

DIMENSIONS ID 4" OD 5" Cut Out 4 1/4" to 4 1/2"

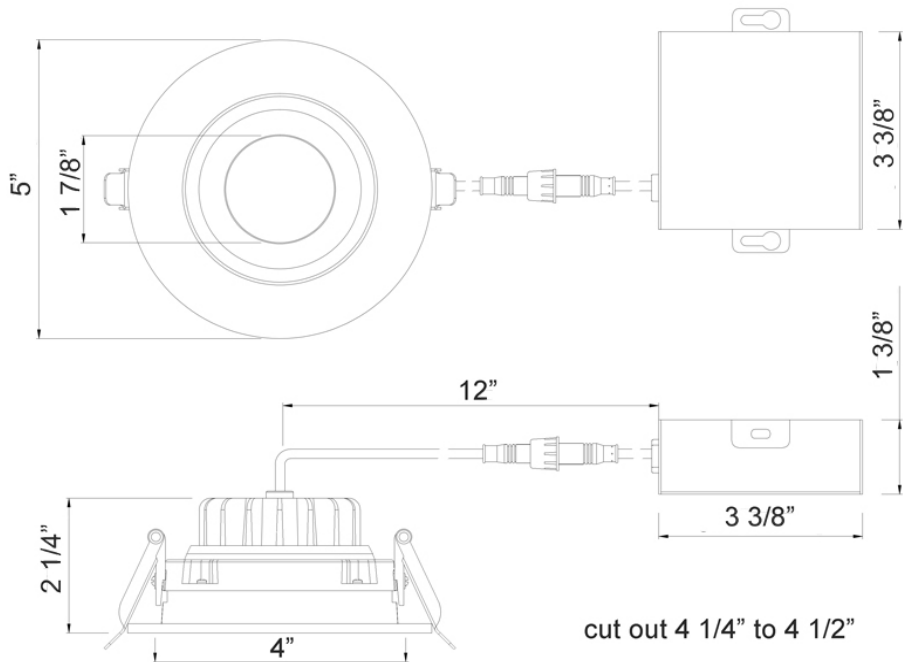

ORDERING GUIDE

model	light color	trim color
AD-LED-4-S12W-3K-WH-LREY	3000K	White
AD-LED-4-S12W-5CCT-WH-LREY	5CCT selectable	White
AD-LED-4-S12W-5CCT-BK-LREY	5CCT selectable	Black
AD-LED-4-S12W-DTW-WH-LREY	Dim to Warm 3018K	White
AD-LED-4-S12W-DTW-BK-LREY	Dim to Warm 3018K	Black

Single light color in stock 3000K round white trim
 Other options available by custom order MOQ 500 pcs

AD-LED-4-S12W-xx-xx-LREY

4" Round Venus Adjustable Recessed LED 12W

Project: _____
 Location: _____
 Model: _____ Qty: _____
 Notes: _____

SPECIFICATION	
Applications	Commercial & Residential Recessed
Power	12 W
Color Temperature (K)	3000 5CCT 27K-30K-35K-40K-50K Dim to Warm 30-18K
Light Output (lm)	880 780-820-890-920-910 700
Halogen Equivalent	90 W
Beam Angle	38° wide beam with 20° tilt and 360° rotation
CRI	90 +
Driver Input	120V AC 50/60 Hz
Junction Box Volume	9.69 cu in / max 5 No 12 AWG or 8 No 14 AWG
Dimming	TRIAC Dimmers 5% - 100%
Approved Location	Insulated Ceiling & Wet Locations
Air Tight	Yes
Ambient Temperature	-4°F (-20°C) to +104°F (+40°C)
Projected Life	70% Light Output at 50,000 Hours
Certification	cETLus, Energy Star, T24
Warranty	5 Year

Trim Options



White



Black

Other Trim Colors Available By Custom Order, MOQ 500 pcs

ACCESSORIES

Sold Separately



[26" Long Flat Rough-In Plate model # RIP4](#)



[13" Long Flat Rough-In Plate model # MP4-2](#)



[13" Long Flanged Rough-In Plate model # MP4](#)



[4 1/8" Hole Flanged with Hanger Bars model # FRP4](#)

 


[Jumper Cable 10 ft model # JC-10](#)



[White model # GR4 Black model # GR4-BK](#)

COMPLIANCE



**Type IC
Air-Tight**

Lotus LED Lights USA
 250 H Street # 301, Blaine WA 98230 tel 360-200-5500
 Hainesport NJ, Naples FL, Vancouver WA

www.LotusLEDLights.com

mailing addresses
 warehouses

Lotus LED Lights CANADA
 702 Chester Rd, Delta BC V3M 6J1 tel 604-538-3090
 Delta BC & Mississauga ON