



# A-Shape LED

## 11A19/LED/850/FR/P/ND 4/6FB

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.


### Product data

General information		Warm Up Time to 60% Light (Nom)	
Cap-Base	E26 [ Single Contact Medium Screw]		0.5 s
EU RoHS compliant	Yes	Power Factor (Nom)	0.5
Nominal Lifetime (Nom)	11000 h	Voltage (Nom)	120 V
Switching Cycle	50000	<b>Temperature</b>	
Technical Type	11-60W	T-Case Maximum (Nom)	80 °C
<b>Light technical</b>		<b>Controls and dimming</b>	
Color Code	850 [ CCT of 5000K]	Dimmable	No
Beam Angle (Nom)	150 °	<b>Mechanical and housing</b>	
Luminous Flux (Nom)	800 lm	Bulb Finish	Frosted
Color Designation	Daylight [ Daylight]	Bulb Shape	A19 (A19)
Correlated Color Temperature (Nom)	5000 K	<b>Approval and application</b>	
Luminous Efficacy (rated) (Nom)	72.00 lm/W	Energy Consumption kWh/1000 h	- kWh
Color Consistency	ANSI	<b>Product data</b>	
Color Rendering Index (Nom)	80	Order product name	11A19/LED/850/FR/P/ND 4/6FB
LLMF At End Of Nominal Lifetime (Nom)	70 %	EAN/UPC - Product	50046677455663
<b>Operating and electrical</b>		Order code	455667
Input Frequency	60 Hz	Numerator - Quantity Per Pack	1
Power (Rated) (Nom)	11 W	Numerator - Packs per outer box	4
Lamp Current (Nom)	150 mA	Material Nr. (12NC)	929001958075
Wattage Equivalent	60 W		
Starting Time (Nom)	0.5 s		

# A-Shape LED

Net Weight (Piece) 0.046 kg


## Dimensional drawing

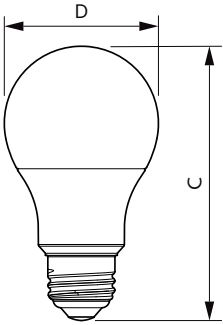


11A19/LED/850/FR/P/ND 4/6FB

Product	D	C
11A19/LED/850/FR/P/ND 4/6FB	60 mm	110 mm


## Photometric data

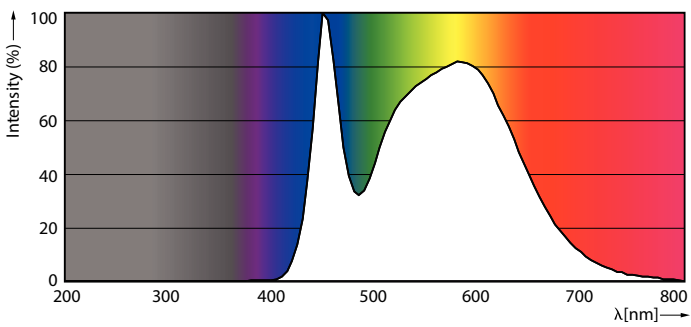

LedBulb A19 E26

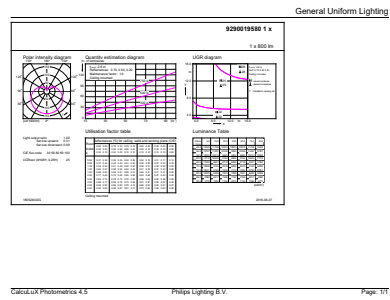



LedBulb A19 E26 11W 850

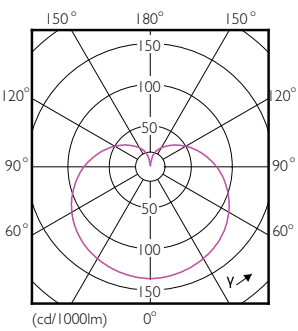

LedBulb A19 E26

# A-Shape LED

## Lifetime

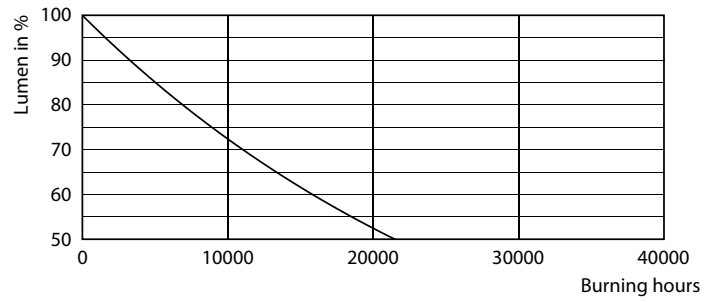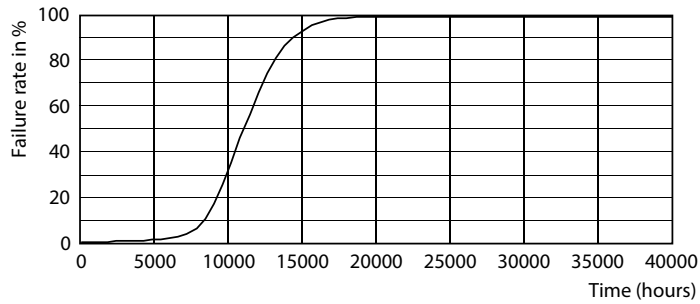

LedBulb A19 E26

LedBulb A19 E26

