



LED PAR30 S/L

8.5PAR30L/LED/927/F25/DIM/GULW/T20 6/1FB

Philips LED spots with a single optic beam, provide a clean beam that's free from shadows with beam angles from 15 and 40 degrees to suit every general lighting application.

Product data


General Information		Starting Time (Nom)	
Cap-Base	E26 [Single Contact Medium Screw]		0.5 s
Nominal lifetime	25,000 hour(s)	Warm-up time to 60% light	0.5 s
Switching Cycle	25,000	Power Factor (Fraction)	0.9
Lighting Technology	LED	Voltage (Nom)	120 V
Light Technical		Temperature	
Color Code	927 [CCT of 2700K]	T-Case Maximum (Nom)	158 °F
Beam Angle (Nom)	25 degree(s)	Controls and Dimming	
Luminous Flux	800 lumen	Dimmable	Only with specific dimmers
Luminous Intensity (Nom)	3,300 cd	Mechanical and Housing	
Color Designation	Warm White (WW)	Bulb Finish	Clear
Correlated Color Temperature (Nom)	2700 K	Bulb Material	Glass
Luminous Efficacy (rated) (Nom)	94.00 lm/W	Bulb Shape	PAR30L [PAR 3.75 inch/95mm Long]
Color Consistency	<4	Approval and Application	
Color rendering index (CRI)	90	Suitable For Accent Lighting	Yes
LLMF At End Of Nominal Lifetime (Nom)	70 %	Energy Certifications	Energy Star
		EU RoHS compliant	Yes
Operating and Electrical		Product Data	
Line Frequency	50 to 60 Hz	Order product name	8.5PAR30L/LED/927/F25/DIM/GULW/T20
Input Frequency	50 to 60 Hz		6/1FB
Power Consumption	8.5 W		
Lamp Current (Nom)	80 mA		
Wattage Equivalent	75 W		

LED PAR30 S/L

Order code	567941
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material number (12NC)	929003026904
Full product name	8.5PAR30L/LED/927/F25/DIM/GULW/T20 6/1FB



EAN/UPC - Case	50046677567946
----------------	----------------

Dimensional drawing

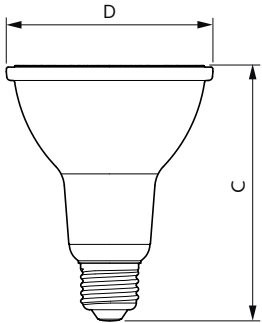

Product	D	C
8.5PAR30L/LED/927/F25/DIM/GULW/T20 6/1FB	94 mm	116 mm


Photometric data

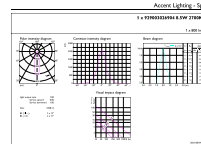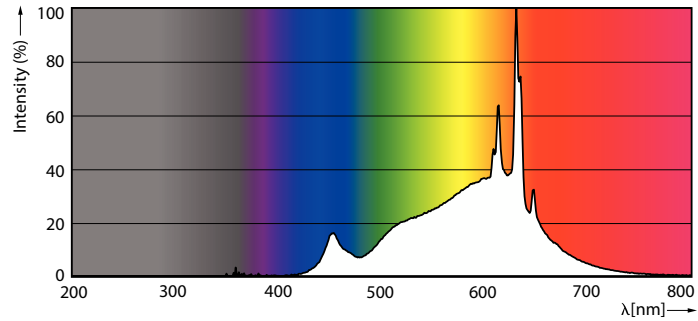

© 2023 Philips Lighting B.V. Philips Lighting B.V. Page 1/1

Spectral Power Distribution Colour - 8.5PAR30L/LED/927/F25/DIM/GULW/T20 6/1FB

Accent Lighting Spots - 8.5PAR30L/LED/927/F25/DIM/GULW/T20 6/1FB

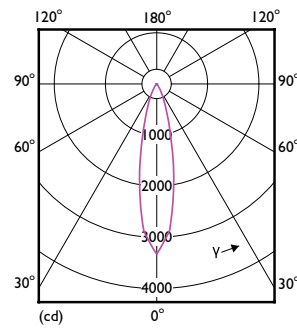

Light Distribution Diagram - 8.5PAR30L/LED/927/F25/DIM/GULW/T20 6/1FB

LED PAR30 S/L

Lifetime



Life Expectancy Diagram - 8.5PAR30L/LED/927/F25/DIM/GULW/T20 6/1FB

Lumen Maintenance Diagram - 8.5PAR30L/LED/927/F25/DIM/GULW/T20 6/1FB

