



Reflector Flood

65BR30/FL55 120V 12/1

Philips Family of Specialty Incandescents provide the perfect light for dramatic accents and display lighting as well as general lighting in a variety of applications. These flood lamps produce homogeneous beams of high intensity for general illumination.


Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Operating Position	UNIVERSAL [Any or Universal (U)]
Nominal lifetime	2,000 hour(s)
Rated Lifetime (Hours)	2,000 hour(s)
Lighting Technology	Incandescent
Light Technical	
Beam Angle (Nom)	55 degree(s)
Luminous Flux	620 lumen
Color rendering index (CRI)	100
Operating and Electrical	
Power Consumption	65 W
Warm-up time to 60% light	instant full light s
Voltage (Nom)	120 V

Voltage (Nom)	120 V
Mechanical and Housing	
Bulb Finish	Frosted
Bulb Shape	BR30
Product Data	
Order product name	65BR30/FL55 120V 12/1
Order code	920681036369
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material number (12NC)	920681036369
Full product name	65BR30/FL55 120V 12/1
EAN/UPC - Case	50046677225198

Reflector Flood

Dimensional drawing

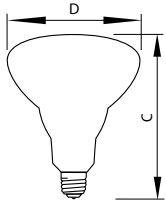

Product

65BR30/FL55 120V 12/1

