



Reflector Flood

65BR30/FL55 CDA 130V

Philips Family of Specialty Incandescents provide the perfect light for dramatic accents and display lighting as well as general lighting in a variety of applications. These flood lamps produce homogeneous beams of high intensity for general illumination.

Product data


General information	
Cap-Base	E26 [Single Contact Medium Screw]
Operating Position	UNIVERSAL [Any or Universal (U)]
Main Application	Indoor Reflector
Gas Filling	Gas
Life with 3 Hour Per Day Use	1.8 a
Footnote Incandescent 1	Consider the compact fluorescent lamps for energy savings.
Footnote Incandescent 2	Do not allow hot bulb to come in contact with liquid or metal parts of the fixture, as glass may shatter. Do not use outdoors. Do not operate in close proximity to flammable materials or those adversely affected by heat or drying. Operate only in heat resistant sockets. (87)
Rated Lifetime (Hours)	2000 h
Light technical	
Beam Angle (Nom)	55 °
Luminous Flux (Nom)	605 lm
Beam Description	Flood
Luminous Flux Lamp @ 120V	450 lm

Operating and electrical	
Power (Nom)	65 W
Lamp Wattage Rated@120V	55 W
Voltage (Nom)	130 V
Mechanical and housing	
Bulb Finish	Frosted
Cap-Base Information	Aluminium Cap
Filament Shape	CC6 [Straight]
Bulb Shape	BR30
Approval and application	
Estimated Energy Cost Per Year at 120V	6.67 \$
Estimated Energy Cost Per Year	7.83 \$

Product data	
Order product name	65BR30/FL55 CDA 130V
EAN/UPC - Product	046677225209
Order code	920681036112
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	920681036112
Net Weight (Piece)	0.001 kg

Reflector Flood

Dimensional drawing

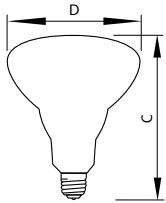

Product

65BR30/FL55 CDA 130V

65BR30/FL55 CDA 130V

