



T5 High Output Energy Advantage

F54T5 850 HO EA ALTO 49W

Philips Energy Advantage T5 HO 49W lamps are environmentally-responsible, ultra-slim and have extraordinary light output with increased energy savings.

Product data

 

General Information		Mechanical and Housing	
Cap-Base	G5 [G5]	Bulb Shape	T5 [16 mm (T5)]
Features	HO EA [High Output Energy Advantage]		
Light Technical		Approval and Application	
Color Code	850 [CCT of 5000K]	Mercury (Hg) Content (Nom)	1.4 mg
Luminous Flux	4,800 lumen		
Color Designation	Daylight	Product Data	
Correlated Color Temperature (Nom)	5000 K	Order product name	F54T5 850 HO EA ALTO 49W
Luminous Efficacy (rated) (Nom)	89 lm/W	Order code	927991985031
Color rendering index (CRI)	82	Numerator - Quantity Per Pack	1
		Numerator - Packs per outer box	40
Operating and Electrical		Material number (12NC)	927991985031
Power Consumption	48.0 W	Full product name	F54T5 850 HO EA ALTO 49W
Lamp Current (Nom)	0.460 A	EAN/UPC - Case	50046677406498
Controls and Dimming			
Dimmable	Yes		

T5 High Output Energy Advantage

Dimensional drawing


Product	D (max)	A (max)	B (max)	B (min)	C (max)
F54T5 850 HO EA ALTO 49W	17 mm	1,149.0 mm	1,156.1 mm	1,153.7 mm	1,163.2 mm

Lifetime

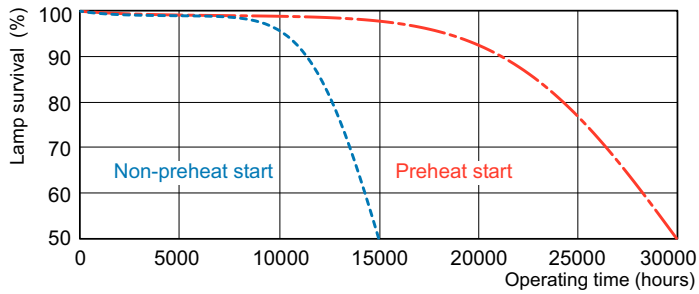

Life Expectancy Diagram - F54T5 850 HO EA ALTO 49W

Life Expectancy Diagram - F54T5 850 HO EA ALTO 49W

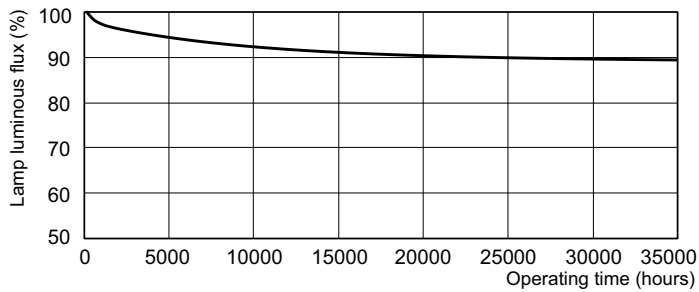

Lumen Maintenance Diagram - F54T5 850 HO EA ALTO 49W

T5 High Output Energy Advantage

