



T5 Standard

F21T5/841/ALTO 40PK

Philips T5 Fluorescent Lamps featuring ALTO® Lamp Technology offer increased energy savings and low toxicity in a slim profile.

Warnings and Safety

- Lamp contains mercury.
- Manage in Accord with Disposal Laws.
- See: www.lamprecycle.org or 1-800-555-0050

Product data

General Information		Mechanical and Housing	
Features	HE Alto® [High Efficiency Alto]	Bulb Shape	T5 [16 mm (T5)]
Cap-Base	G5 [G5]		
Light Technical		Approval and Application	
Color Code	841 [CCT of 4100K]	Mercury (Hg) Content (Nom)	1.4 mg
Luminous Flux	2,100 lumen		
Color Designation	Cool White (CW)	Product Data	
Correlated Color Temperature (Nom)	4100 K	Order product name	F21T5/841/ALTO 40PK
Luminous Efficacy (rated) (Nom)	90 lm/W	Order code	230839
Color rendering index (CRI)	82	Numerator - Quantity Per Pack	1
		Numerator - Packs per outer box	40
Operating and Electrical		Material number (12NC)	927990884022
Power Consumption	20.6 W	Full product name	F21T5/841/ALTO 40PK
Lamp Current (Nom)	0.165 A	EAN/UPC - Case	50046677230833
Controls and Dimming			
Dimmable	Yes		

 
T5 Standard

Dimensional drawing




Product	D (max)	A (max)	B (max)	B (min)	C (max)
F21T5/841/ALTO 40PK	17 mm	849.0 mm	856.1 mm	853.7 mm	863.2 mm

Photometric data




Spectral Power Distribution Colour - F21T5/841/ALTO 40PK

Lifetime

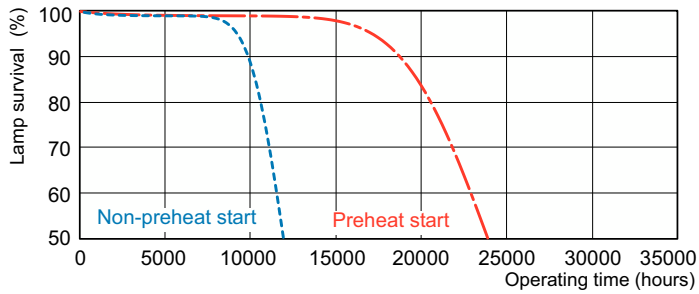

Life Expectancy Diagram - F21T5/841/ALTO 40PK

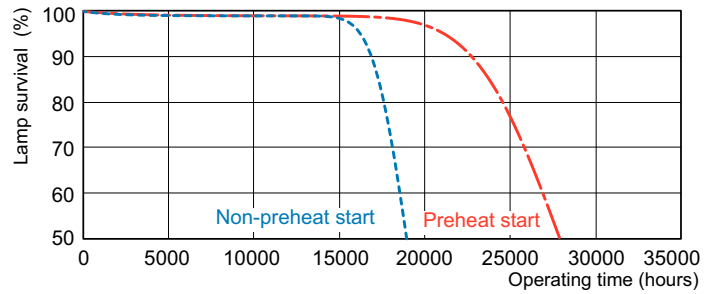

Life Expectancy Diagram - F21T5/841/ALTO 40PK

T5 Standard

Lifetime



Lumen Maintenance Diagram - F21T5/841/ALTO 40PK

