


## Liquidtight Flexible Metallic Conduit Fittings: Zinc Die Cast


### Straight Connectors — Die-Cast Zinc

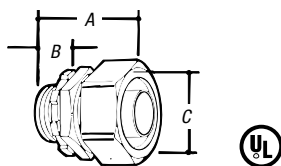

CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)			STD. CTN.
		A	B	C	
LT-200	3/8	1.81	.50	1.06	100
LT-201	1/2	1.88	.61	1.19	100
LT-202	3/4	2.03	.56	1.44	100
LT-203	1	2.28	.63	1.75	50
LT-204	1 1/4	2.59	.69	2.44	40
LT-205	1 1/2	2.78	.78	2.75	20
LT-206	2	3.22	.78	3.53	20
LT-207	2 1/2	3.53	.84	4.28	1
LT-208	3	3.91	.88	4.72	1
LT-209	3 1/2	4.04	.91	5.42	1
LT-210	4	4.16	.94	5.91	1

UL File No. E-23018.


### Straight Connectors — Die-Cast Zinc with Insulated Throat

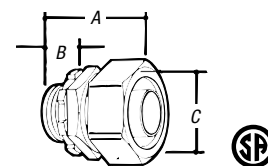

CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)			STD. CTN.
		A	B	C	
LT-800	3/8	1.81	.50	1.06	100
LT-801	1/2	1.88	.61	1.19	100
LT-802	3/4	2.03	.56	1.44	100
LT-803	1	2.28	.63	1.75	50
LT-804	1 1/4	2.59	.69	2.44	40
LT-805	1 1/2	2.78	.78	2.75	20
LT-806	2	3.22	.78	3.53	20
LT-807	2 1/2	3.53	.84	4.28	1
LT-808	3	3.91	.88	4.72	1
LT-809	3 1/2	4.04	.91	5.42	1
LT-810	4	4.16	.94	5.91	1

CSA File No. LR-12798.


### 90° Connectors — Die-Cast Zinc

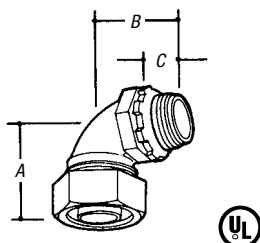

CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)			STD. CTN.
		A	B	C	
LT-290	3/8	1.88	1.38	.50	100
LT-291	1/2	2.00	1.41	.50	100
LT-292	3/4	2.19	1.66	.56	100
LT-293	1	2.56	1.88	.63	50
LT-294	1 1/4	3.00	2.00	.69	40
LT-295	1 1/2	3.38	2.56	.78	20
LT-296	2	4.06	3.00	.78	10
LT-297	2 1/2	5.03	3.72	.84	1
LT-298	3	5.63	4.66	.88	1
LT-299	3 1/2	6.10	4.82	.91	1
LT-2910	4	6.56	4.97	.94	1

UL File No. E-23018.

### 90° Connectors — Die-Cast Zinc with Insulated Throat

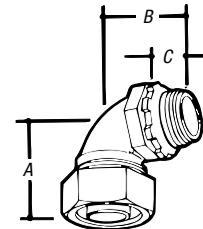

CAT. NO.	CONDUIT SIZE (IN.)	DIMENSIONS (IN.)			STD. CTN.
		A	B	C	
LT-890	3/8	1.88	1.38	.50	100
LT-891	1/2	2.00	1.41	.50	100
LT-892	3/4	2.19	1.66	.56	100
LT-893	1	2.56	1.88	.63	50
LT-894	1 1/4	3.00	2.00	.69	20
LT-896	2	4.06	3.00	.78	10
LT-897	2 1/2	5.03	3.72	.84	1

UL File No. E-23018.

### Sealing O-Rings



CAT. NO.	CONDUIT SIZE (IN.)	STD. CTN.
SR 101	1/2	500
SR-102	3/4	500
SR-103	1	500
SR-104	1 1/4	250
SR-105	1 1/2	250
SR-106	2	250

Material: Neoprene