


INSTRUCTION SHEET for Ground Grid Connectors

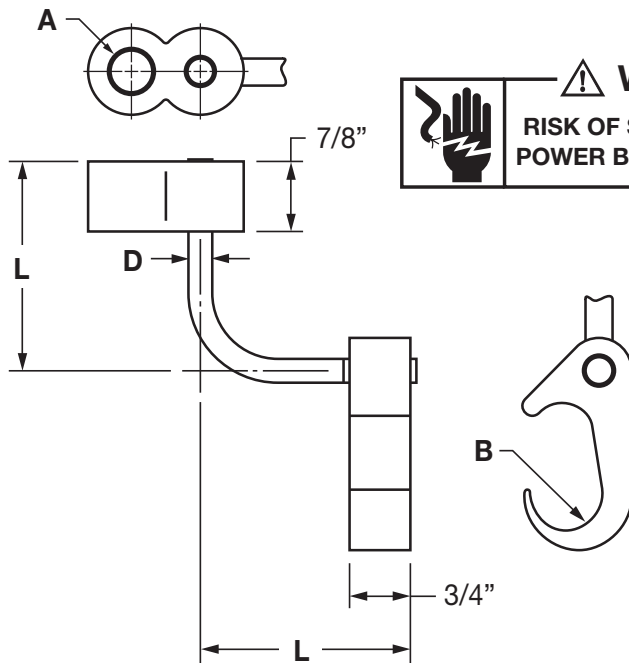

INSTRUCTIONS:

NOTE: Install these connectors on ground rods after the rods have been driven to their final depth.

1. Clean cable of all visible dirt with rough cloth or brush and provide a bright copper finish by wire brushing or similar process.
2. Cable end(s) should protrude at least 3/4" beyond connector.
3. **OPTIONAL:** Use knurling tool 240-31565-94 on smooth ground rods.
4. Use hydraulic tool 13100A, TBM14CR-LI, TBM14M, TBM15CR-LI, TBM15, or TBM15I with die marked on part.

Thomas & Betts

A Member of the ABB Group

Cat. Nos.	A Ground Rod	B Cable Range	D	L	DIES FOR T&B TOOLS (see Step 4)	
					A	B
54920LR100	1"	250 MCM-500 MCM	1/2"	2-5/8"	15G121R*	15G126R
54910LR100	1"	2 AWG-250 MCM	1/2"	2-5/8"	15G121R*	15G86R
54900LR34	3/4"	250 MCM-500 MCM	1/2"	2-5/8"	15G121R*	15G126R
54875LR34	3/4"	2 AWG-250 MCM	1/2"	2-5/8"	15G121R*	15G86R
54895LR58	5/8"	250 MCM-500 MCM	5/16"	2-1/2"	15G121R*	15G126R
54865LR58	5/8"	2 AWG-250 MCM	5/16"	2-1/2"	15G121R*	15G86R
54885LR12	1/2"	250 MCM-500 MCM	5/16"	2-1/2"	15G121R*	15G126R
54855LR12	1/2"	2 AWG-250 MCM	5/16"	2-1/2"	15G121R*	15G86R

*Requires 2 crimps

Cat. Nos.	Burndy Tools (Crimps)					
	Y750		Y45		Y46	
	A	B	A	B	A	B
54920LR100	U1011 (2) or PU998 (1)	U1011 (2) or PU998 (1)	S1011 (2) or PU998 (1)	U1011 (2) or PU998 (1)	P1011 (2) or PU998 (1)	U1011 (2) or PU998 (1)
54910LR100	U1011 (2) or PU998 (1)	U997 (1)	S1011 (2) or PU998 (1)	U997 (1)	P1011 (2) or PU998 (1)	U997 (1)
54900LR34	U1011 (2) or PU998 (1)	U1011 (2) or PU998 (1)	S1011 (2) or PU998 (1)	U1011 (2) or PU998 (1)	P1011 (2) or PU998 (1)	U1011 (2) or PU998 (1)
54875LR34	U1011 (2) or PU998 (1)	U997 (1)	S1011 (2) or PU998 (1)	U997 (1)	P1011 (2) or PU998 (1)	U997 (1)
54895LR58	U1011 (2) or PU998 (1)	U1011 (2) or PU998 (1)	S1011 (2) or PU998 (1)	S998 (1) or PU998 (1)	P1011 (2) or PU998 (1)	P998 (1) or PU998 (1)
54865LR58	U1011 (2) or PU998 (1)	U997 (1)	S1011 (2) or PU998 (1)	U997 (1)	P1011 (2) or PU998 (1)	U997 (1)
54885LR12	U1011 (2) or PU998 (1)	U1011 (2) or PU998 (1)	S1011 (2) or PU998 (1)	S998 (1) or PU998 (1)	P1011 (2) or PU998 (1)	P998 (1) or PU998 (1)
54855LR12	U1011 (2) or PU998 (1)	U997 (1)	S1011 (2) or PU998 (1)	U997 (1)	P1011 (2) or PU998 (1)	U997 (1)

WARRANTY: Thomas & Betts sells this product with the understanding that the user will perform all necessary tests to determine the suitability of this product for the user's intended application. Thomas & Betts warrants that this product will be free from defects in materials or workmanship for a period of two (2) years following the date of purchase. Upon prompt notification of any warranted defect, Thomas & Betts will, at its option, repair or replace the defective product. Misuse, misapplication or modification of Thomas & Betts Products immediately voids all warranties.

Limitations and Exclusions: THE ABOVE WARRANTY IS THE SOLE WARRANTY CONCERNING THIS PRODUCT, AND IS IN LIEU OF ALL OTHER WARRANTIES EXPRESS OR IMPLIED, INCLUDING BUT NOT LIMITED TO ANY IMPLIED WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE, WHICH ARE SPECIFICALLY DISCLAIMED. LIABILITY FOR BREACH OF THE ABOVE WARRANTY IS LIMITED TO COST OF REPAIR OR REPLACEMENT OF THE PRODUCT, AND UNDER NO CIRCUMSTANCES WILL THOMAS & BETTS BE LIABLE FOR ANY INDIRECT, SPECIAL, INCIDENTAL OR CONSEQUENTIAL DAMAGES.