

Copper Mechanical Connectors

All the same features as the standard LOCKTITE® lug — with two or three barrels.

LOCKTITE® Double- and Triple-Barrel NEMA-Drilled Lugs for 600V Applications

- Screw tightening
- Serrated saddle
- Built-in lockwasher
- For use with code copper conductor (600V)

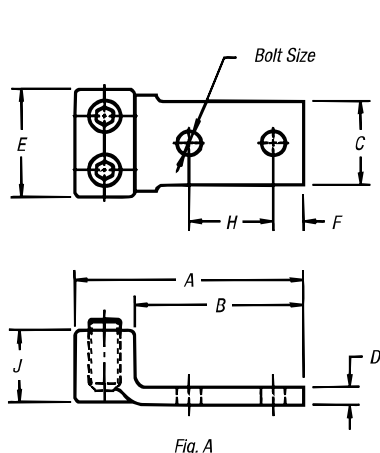


Fig. A

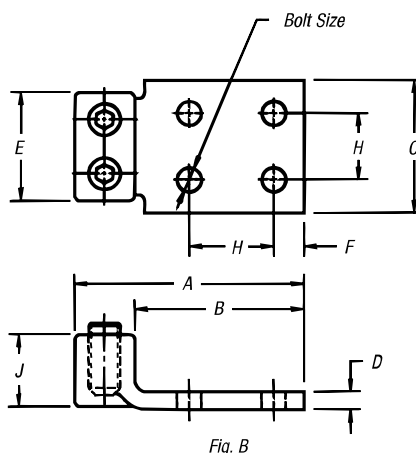


Fig. B

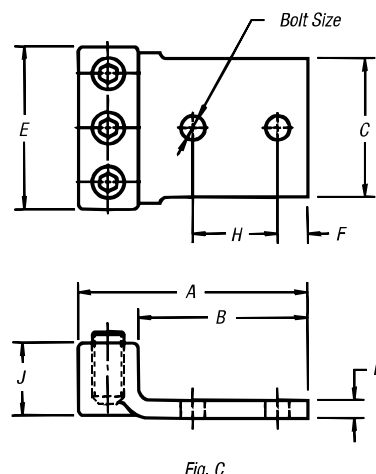


Fig. C

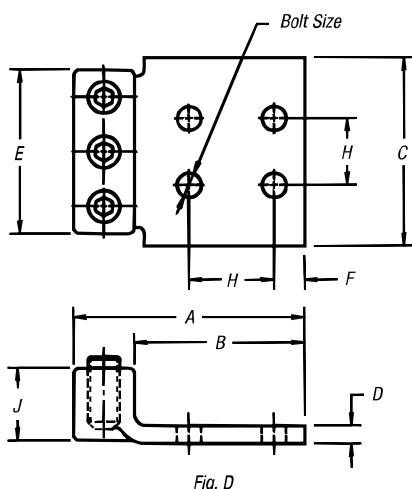


Fig. D



CAT. NO.	CABLE SIZE	FIG.	BOLT SIZE	DIMENSIONS (IN.)							
				A	B	C	D	E	F	H	J
32003BD ¹	14 to 8	A	1/4	2 3/16	1 3/4	5/8	1/8	1 1/16	9/32	5/8	1 3/32
32005BD ¹	8 to 4	A	1/4	2 1/2	2	1	1/8	1	9/32	5/8	1 1/32
32007BD	4 to 1	A	3/8	2 13/16	2	1 1/4	7/32	1 1/4	7/16	1	29/32
32009BD	1 to 2/0	A	1/2	4 7/16	3 1/2	1 1/2	1/4	1 9/16	5/8	1 3/4	1 13/32
32011BD	2/0 to 4/0	A	1/2	4 5/8	3 1/2	1 3/4	9/32	1 3/4	5/8	1 3/4	1 5/16
32013BD	4/0 to 300	A	1/2	4 3/4	3 1/2	2	5/16	2 1/8	5/8	1 3/4	1 9/16
32015BD	300 to 500	A	1/2	5 3/8	3 15/16	2 1/2	1 1/32	2 1/2	5/8	1 3/4	1 11/16
32017BD	500 to 700	B	1/2	5 19/32	4	4	1 3/32	2 9/16	5/8	1 3/4	2 1/8
32019BD	750 to 1000	B	1/2	5 27/32	4	4	1 5/32	3 1/4	5/8	1 3/4	2 1 1/32
32011TB	2/0 to 4/0	C	1/2	4 5/8	3 3/8	2 1/2	9/32	2 3/4	5/8	1 3/4	1 5/16
32013TB	4/0 to 300	C	1/2	4 3/4	3 1/2	3	5/16	3 1/4	5/8	1 3/4	1 11/32
32015TB	300 to 500	D	1/2	5 3/8	4	4	1 1/32	3 3/4	5/8	1 3/4	1 11/16
32017TB	500 to 750	D	1/2	5 19/32	4	4	1 3/32	4 3/8	5/8	1 3/4	2 1/8
32019TB	750 to 1,000	D	1/2	5 27/32	4	4	1 5/32	4 1 1/16	5/8	1 3/4	2 1 1/32

¹With Fillister Head Screw.

For torque requirements, see page F-188.