

Armored Cable/Flexible Metallic Conduit Fittings

Steel City® Cable Lok®


- Simple, one-piece installation with no locknuts
- Screw designed for exceptional pullout resistance
- Captive screw ensures that the screw is intact for installation and resists backing out after installation
- Corrosion-resistant, zinc-chromatic plating
- Positive grounding
- Vibration-resistant screw design
- UL Listed and CSA Certified



Simple, fast steps to install the Steel City® Cable Lok®.



1. Simply snap into place. No locknuts required!

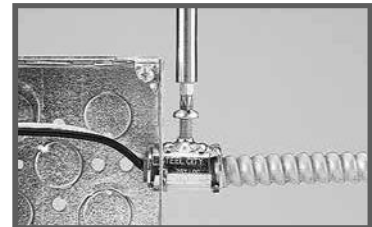

2. Insert cord and twist set screw. Connector tightens as screw is set.

Specifications

- Material: Body: Steel (spring steel);
Finish: Zinc;
Insulator: Nylon;
Temp.: 105° C
- Listing: UL, CSA Listed
- O.D. for over armor .400"–.510"
- No set screws, locknuts or tools are required to attach MC cable to a box or enclosure
- One-piece spring-steel construction
- Accommodates the widest range of MC cable sizes in the industry — 14-2 to 10-3

- Compact, low-profile design saves space in the box or enclosure
- Fittings can be used in adjacent knockouts in the corner of the box
- Removable and reusable
- Ideal for commercial construction or prefabricated electrical wiring assemblies



CAT. NO.	SIZE RANGE (IN.)	AC STEEL	AC ALUMINUM INTERLOCKED	MC (I) STEEL	MC (I) ALUMINUM	FLEX RW	STD. CTN.
XC-730		14/2 14/3 14/4	14/2 14/3 14/4	14/2 14/3 14/4	14/2 14/3 14/4	3/8" Steel & AL	50
	.450/.610	12/2 12/3 12/4	12/2 12/3 12/4	12/2 12/3 12/4	12/2 12/3 12/4		
	1/2" KO	10/2		10/2 10/3	1/2" KO	10/2 10/3	
XC-731		14/2 14/3 14/4	14/2 14/3 14/4	14/2 14/3 14/4	14/2 14/3 14/4	—	50
	.450/.610	12/2 12/3 12/4	12/2 12/3 12/4	12/2 12/3 12/4	12/2 12/3 12/4		
	1/2" KO	10/2		10/2 10/3	1/2" KO	10/2 10/3	
XC-732		10/3 10/4 10/5	—	10/4 10/5	—	3/8" Steel & AL	25
	.610/.875	8/3 8/4		8/3 8/4			
	3/4" KO	6/2		6/2	3/4" KO		
XC-7300		14/2 14/3 14/4	14/2 14/3 14/4	14/2 14/3 14/4	14/2 14/3 14/4	—	25
	.450/.610	12/2 12/3 12/4	12/2 12/3 12/4	12/2 12/3 12/4	12/2 12/3 12/4		
	1/2" KO	10/2		10/2 10/3	1/2" KO	10/2 10/3	

UL File No. E-1383.
CSA File No. LR-12798.

Snap-In Fitting for MC Cable — Steel



CAT. NO.	DESCRIPTION	STD. CTN.
XC-130	Steel Snap-In Fitting for MC Cable (14-2+G to 10-3+G)	500

