



LED Corn Cobs

45CC/LED/3CCT/LS EX39 G3 BB 3/1

Philips Corn Cob LED replacement lamps are perfect LED replacement for a variety of outdoor applications. High intensity illumination, which means you get added visibility for applications like streets, public areas, and much more for a fraction of the energy used by conventional HID.

Product data


General Information	
Lighting Technology	LED
Switching Cycle	50,000
Nominal lifetime	50,000 hour(s)
Cap-Base	EX39 [Exclusionary Mogul Screw]
Light Technical	
Color Code	850 [CCT of 5000K]
Color Designation	Daylight
Correlated Color Temperature (Nom)	Selectable 3000 4000 5000 K
Luminous Efficacy (rated) (Nom)	129.00 lm/W
Color Consistency	ANSI 5000K quadrangle
Color rendering index (CRI)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Line Frequency	50 to 60 Hz
Input Frequency	50 to 60 Hz
Power Consumption	45 W
Lamp Current (Nom)	500 mA
Wattage Equivalent	175 W
Starting Time (Nom)	1 s
Warm-up time to 60% light	1 s

Power Factor (Fraction)	0.9
Voltage (Nom)	100-277 V
Temperature	
T-Case Maximum (Nom)	140 °F
Controls and Dimming	
Dimmable	Preset Dimming
Mechanical and Housing	
Bulb Finish	Clear
Bulb Material	Plastic
Bulb Shape	Corncob
Approval and Application	
EU RoHS compliant	Yes
Product Data	
Order product name	45CC/LED/3CCT/LS EX39 G3 BB 3/1
Order code	570473
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	3
Material number (12NC)	929003065304

LED Corn Cobs



Full product name	45CC/LED/3CCT/LS EX39 G3 BB 3/1
EAN/UPC - Case	50046677570472

Dimensional drawing

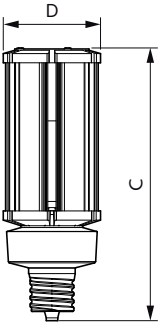


Product	D	C
45CC/LED/3CCT/LS EX39 G3 BB 3/1	85 mm	245 mm

Photometric data

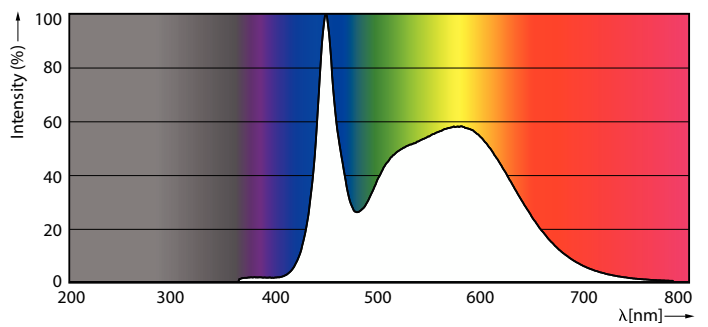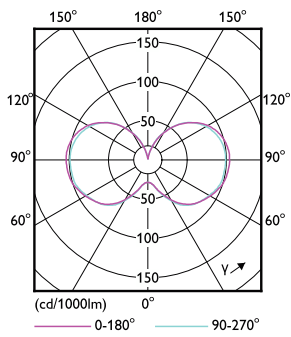

Light Distribution Diagram - 45CC/LED/3CCT/LS EX39 G3 BB 3/1

Spectral Power Distribution Colour - 45CC/LED/3CCT/LS EX39 G3 BB 3/1

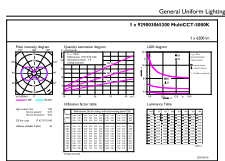

General uniform lighting - 45CC/LED/3CCT/LS EX39 G3 BB 3/1

LED Corn Cobs

Lifetime



Life Expectancy Diagram - 45CC/LED/3CCT/LS EX39 G3 BB 3/1

Lumen Maintenance Diagram - 45CC/LED/3CCT/LS EX39 G3 BB 3/1

