



Switch Start Metal Halide Standard

MH400/U/ED28 12PK

High performance, Long life and Superior light quality. A compact, energy efficient metal halide lamp that provides crisp, sparkling light with long life and high efficiency.

Warnings and Safety

- R "WARNING: These lamps can cause serious skin burn and eye inflammation from short wave ultraviolet radiation if outer envelope of the lamp is broken or punctured. Do not use where people will remain for more than a few minutes unless adequate shielding or other safety precautions are used. Certain lamps that will automatically extinguish when the outer envelope is broken or punctured are commercially available." This lamp complies with FDA radiation performance standard 21 CFR subchapter J. (USA: 21 CFR 1040.30 Canada: SOR/DORS/80-381)
- Lamp contains mercury.
- Manage in Accord with Disposal Laws.
- See: www.lamprecycle.org or 1-800-555-0050

Product data


General Information		Color rendering index (CRI)	
Operating Position	UNIVERSAL [Any or Universal (U)]	57	
Cap-Base	E39 [Single Contact Mogul Screw]		
Light Technical		Operating and Electrical	
Color Code	640 [CCT of 4000K]	Power Consumption	400 W
Color Designation	Cool White (CW)	Lamp Current (Nom)	3.25 A
Chromaticity Coordinate X (Nom)	0.390	Voltage (Nom)	135 V
Chromaticity Coordinate Y (Nom)	0.400	Voltage (Nom)	135 V
Correlated Color Temperature (Nom)	4000 K	Mechanical and Housing	
Luminous Efficacy (Rated) (Min)	80 lm/W	Bulb Finish	Clear
Luminous Efficacy (rated) (Nom)	90 lm/W	Bulb Material	Hard Glass

Switch Start Metal Halide Standard

Bulb Shape	ED28
Approval and Application	
Energy Saving Product	Not Applicable
Mercury (Hg) Content (Max)	52.0 mg
Product Data	
Order product name	MH400/U/ED28 12PK

Order code	426023
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material number (12NC)	928601151303
Full product name	MH400/U/ED28 12PK
EAN/UPC - Case	50046677426021

Dimensional drawing

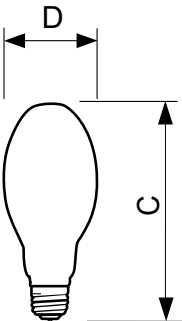

Product	D	C (max)
MH400/U/ED28 12PK	3.5 inch	8.313 inch

