



The Most-Loved Smart Thermostats for Electric Heating or Cooling

Mysa Smart Thermostat for Electric Baseboard Heaters



Part Number: BB.2.0.01.NA-US
Model: MYSA BB V2-0
UPC: 821661113898

Mysa Smart Thermostat for Electric In-Floor Heating



Part Number: IF.1.0.01.NA
Model: MYSA IN-FLOOR V1-0
UPC: 821661208273

Mysa Smart Thermostat for AC and Mini-Split Heat Pumps



Part Number: AC.1.0.01.NA-US
Model: MYSA AC V1-0
UPC: 821661307129

Why Mysa?



Scheduling



Zone Control



Shared Access



Vacation Mode



Geolocation



Energy Insights

Mysa's ecosystem of smart thermostats has your family's heating or cooling comfort covered from the ground up, all year long.



4.5 Star Product Rating | 6500+ Reviews

"Sleek, beautiful, modern, smart, easy to use app. All-around great product."

Reviewed by Corrin T. on getmysa.com

A Smarter Home

Mysa works with your favourite voice assistants and smart home platforms keeping you conveniently connected.



Core Components

Mobile App

Adjust your home heating from anywhere on your Android or iOS device.

Smart Home

Control Mysa through your favourite smart home platforms and home assistants.

Thermostat

Mysa displays the room's current temperature, and the touch buttons allow you to adjust it.

Home Energy Savings

Mysa's innovative mobile app features help you save money by heating your home only when needed.

Control From Anywhere

Mysa helps you stay in control of how and when you heat your home from anywhere, using your smartphone or tablet.

Warranty

Two-year warranty

App Languages

English

French

Certifications


Mysa's smart thermostats pass all applicable electrical safety, WiFi and cybersecurity standards.



Mysa Smart Thermostats
getmysa.com



Full control of electric heating or cooling. One app. **Smart.**

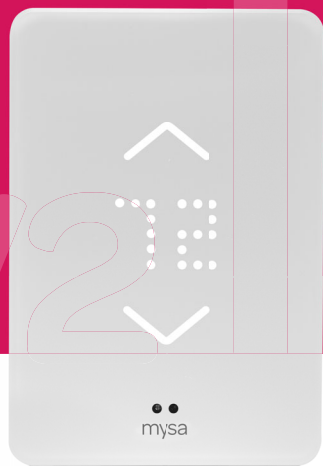

Mysa Smart Thermostat for Electric Baseboard Heaters

Dimensions

Height: 5.1 in / 129 mm
Width: 3.5 in / 88 mm
Depth: 0.8 in / 20 mm

Compatibility

Most high voltage electric heating systems including baseboard and fan-forced heaters.

Power & Voltage

1900 W at 120 VAC /
3800 W at 240 VAC
Current: 16 A Max
Fits standard size gang box.

Mysa Smart Thermostat for Electric In-Floor Heating

Dimensions

Height: 5.1 in / 130 mm
Width: 3.8 in / 90 mm
Depth: 0.75 in / 19 mm

Compatibility

Most high voltage electric in-floor heating systems and flooring types. Includes a 10 kohm Floor Sensor (16 ft / 5 m length).

Works with any existing floor sensor between 5 kohm to 40 kohm.

Power & Voltage

1900 W at 120 VAC /
3800 W at 240 VAC
Current: 16 A Max
Fits standard size gang box.
Includes Class A GFCI (5 mA Level).

Mysa Smart Thermostat for AC and Mini-Split Heat Pumps

Dimensions

Height: 4.3 in / 110 mm
Width: 3.0 in / 75 mm
Depth: 0.6 in / 15 mm

Compatibility

Replaces remotes with displays for most window, ductless mini-split heat pump, or portable air conditioners.

Power & Install

Powered via included 5V micro USB connection AC Adapter. Wall-mount with adhesive strips OR place on a surface with the included stand.

Network and App Compatibility

Mysa Smart Thermostats connect to the Internet via your WiFi. Requires **2.4 GHz WiFi network** and uses optional **NFC pairing** for seamless setup. **Mysa app** available for **Android and iOS**.

