


THE TOP HAT

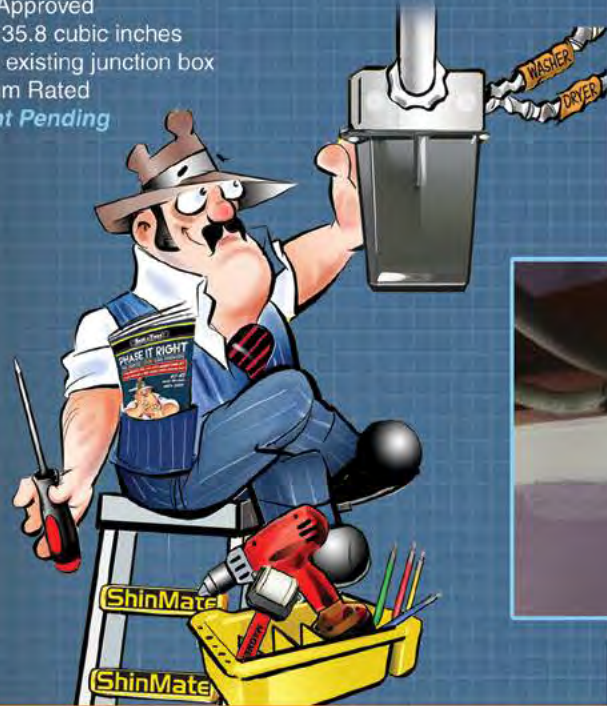

 PART# TC1400
 *PACKAGED IN 50 & 5 PACKS



As a simple box cover, the Top Hat is used instead of a blank cover with several important advantages. It allows installers to leave wires that enter the junction boxes extending straight. With the depth of the Top Hat there is no need to coil wires and stuff them into the smaller parts of the junction box. This will save time during installation and more importantly during troubleshooting. Additionally, this high volume cover makes it easier to access the contents of any junction box.

FEATURES

- ULC Approved
- Adds 35.8 cubic inches to the existing junction box
- Plenum Rated
- Patent Pending



BEFORE



AFTER

6.5 INCH PLATE

FEATURES:

- Installs in seconds with rare earth magnets - snaps in place to metal clips (included)
- White decorative plate covers and 5-1/2" square hole or electrical box
- Can also be used to cover a round hole with up to a 5-1/2" diameter
- Visually appealing white decorative plate - no need to paint metal covers



Part# D612

SC500 - Aircraft Seismic Cable 500'
 SC1000 - Aircraft Seismic Cable 1000'
 SCC116 - Aircraft Seismic Cable Clamps



AIRCRAFT CABLE & WIRE CRIMPS

- AVAILABLE IN 500 AND 1,000 FEET.
- NO NEED TO GO ANYWHERE ELSE - BUY IT FROM US!

BOLT STAR®

POLE POSITIONING TOOL

INTRODUCING BOLT STAR®

An innovative, multi-function reusable bolt template engineered to hold four anchor bolts, rebar cage and conduits securely in place during the pour of a concrete pole base. The result of years of design refinement and testing, BOLT STAR radically improves the productivity of crews in the construction of light pole bases and round column forms. Available for 180 and 240 tube sizes, the tool virtually eliminates the drawbacks of wood templates.



SAVES LABOR - REUSABLE - REDUCES RISK

- Part# 67218 - Small Size 18" - Green
- Part# 67224 - Large Size 24" - Orange
- Part# 67230 - Extra Large Size - Yellow
- Part# 67234 - Extension Set of 4 Pcs. - Black

BOLT TEMPLATE

The Bolt Template helps you easily layout bolts to be used in concrete for future installation of poles or beams. The template is multi-functional and has an easy guide for centering bolts.



- Has a whopping 41 templates!
- Quick, easy, and reusable
- Weather resistant ABS plastic
- Sets poles and beams 8" - 24"

Part# 67441



DRYCONN®

WATERPROOF CONNECTORS

FILLED CONNECTORS FOR OUTDOOR USE



FILLED CONNECTORS FOR DIRECT BURY USE

Part #	Selling Unit	Wire Range
KI62110	Card of 6	22 — 12
KI62125	Bag of 25	22 — 12
KI62210	Card of 5	22 — 8
KI62225	Bag of 20	22 — 8
KI62310	Card of 3	14 — 6
KI62335	Bag of 50	14 — 6

Part #	Selling Unit	Wire Range
KI10600	Card of 2	22 — 8
KI10666	Bag of 10	22 — 8
KI10999	Bag of 8	14 — 6
KI10444	Bag of 10	18 — 12
KI10555	Bag of 10	14 — 10



"One-Step"® Installations
 Corrosion Proof
 Reduces Risk of Fire
 CSA certified as a Pressure Type Connector

"One-Step" Installations
 CSA certified as a Pressure Type Connector
 CSA certified as Direct Bury
 Corrosion proof

COUNTERTOP BOXES

FLOOR BOXES



Rack-A-Tiers carries an extensive line of floor and countertop boxes. They all feature a sleek and compact design offering a great option when needing to install an outlet into a countertop or floor.

SQUARE COUNTERTOP POP-UP BOXES

SQUARE COUNTERTOP POP-UP PLATE ASSEMBLY WITH 20 AMP GFI RECEPTACLE

STAINLESS - PART# VPU.SS
 BLACK - PART# VPU.BK
 BRASS - PART# VPU.BR
 OFF WHITE - PART# VPU.WT

SQUARE COUNTERTOP POP-UP PLATE ASSEMBLY WITH 15 AMP W/2 USB

STAINLESS - PART# VPU.SS.2USB
 BLACK - PART# VPU.BK.2USB
 BRASS - PART# VPU.BR.2USB
 OFF WHITE - PART# VPU.WT.2USB



DESKTOP POP-UP BOX

Pop-up desktop box includes: 1 - Decora 15 Amp Duplex Receptacle W/ 2USB and 6 Port Empty Communication Plate. 9 foot power cable.
 Part # VPU.DTB.BK



Part# VKJ.BK - Black Voice Modular Coupler
 Part# VKJIT.BK - Black Cat 5E Modular Coupler
 Part# VKC.BK - Black Blank Modular Fill
 Part# VKJHDMI.BK - Black HDMI Modular Coupler
 Part# VKJUSB.BK - Black USB Pass Through

Features
 - 120 V male cord attached
 - Mounts flush in boardroom tables, desks, etc.
 - 15 Amp Duplex Receptacle W/ 2USB
 - 6 Port Empty Communication Plate

SQUARE FLOOR POP-UP BOXES WITH SLIDE BUTTON

SQUARE POP-UP FLOOR PLATE ASSEMBLY WITH 20 AMP GFI RECEPTACLE

STAINLESS - PART# VFPU.SS.GFI
 BRASS - PART# VFPU.BR.GFI

SQUARE POP-UP FLOOR PLATE ASSEMBLY WITH 15 AMP W/2 USB

STAINLESS - PART# VFPU.SS.2USB
 BRASS - PART# VFPU.BR.2USB

SQUARE POP-UP FLOOR PLATE ASSEMBLY WITH 15 AMP

STAINLESS - PART# VFPU.SS
 BRASS - PART# VFPU.BR

SQUARE FLOOR POP-UP PLATE ASSEMBLY INCLUDE VPU.WB WOOD ENCLOSURE BOX. CONCRETE BOX SOLD SEPARATELY - PART# VPU.CB



ASSEMBLED FLOOR BOXES

HINGED SINGLE GANG

ALUMINUM - PART# VRHC.AL
 BRASS - PART# VRHC.BR



MEDALLION SINGLE GANG

ALUMINUM - PART# VRMC.AL
 BRASS - PART# VRMC.BR



PLASTIC QUICK INSTALL FLOOR BOXES

HINGED ROUND

ALUMINUM - PART# VRHB.AL
 BRASS - PART# VRHB.BR



MEDALLION ROUND

ALUMINUM - PART# VRMB.AL
 BRASS - PART# VRMB.BR



*** NOT FOR USE IN CONCRETE**

ROUND FLOOR BOXES

ROUND FLOOR POP-UP PLATE ASSEMBLY WITH 15 AMP DECORA

STAINLESS - PART# VPU.FD.SS
 BRASS - PART# VPU.FD.BR

ROUND FLOOR POP-UP PLATE ASSEMBLY WITH 15 AMP GFI

STAINLESS - PART# VPU.FB.SS
 BRASS - PART# VPU.FB.BR

ROUND FLOOR POP-UP PLATE ASSEMBLY WITH 6 DATA PORTS

STAINLESS - PART# VPU.FC.SS
 BRASS - PART# VPU.FC.BR

ROUND FLOOR POP-UP PLATE ASSEMBLIES DO NOT INCLUDE ENCLOSURE BOX. WOOD BOX, PART# VPU.WB AND CONCRETE BOX, PART# VPU.CB, SOLD SEPARATELY.



ULTRA-SIDEWINDER[®]

CABLE PROTECTION SYSTEMS



FEATURES:

- ARTICULATION PIECES OFFER FLEXIBLE DESIGN - CURVES, CORNERS & S-CURVES ARE EASILY MADE WHILE MAINTAINING A COMPLETELY FLAT PROFILE.
- SIMPLE INSTALLATION. NO TOOLS REQUIRED.
- AVAILABLE IN BLACK, YELLOW, BROWN, AND GRAY.
- FULLY-CUSTOMIZABLE LENGTH - FROM 4.5" TO AN UNLIMITED LENGTH.

Cavity Size: 3/4" W x 3/8" H

Part#

- U1830BY - 3 ft. with end caps black/yellow
- U1832BK - 3 ft. with end caps black
- U1804BR - 3 ft. with end caps - Brown
- U1806G - 3 ft. System with end caps - Gray
- U1801BY - 1 ft. Extension System - Black & Yellow
- U1803BK - 1 ft. Extension System - Black
- U1805BR - 1 ft. Extension System - Brown
- U1807G - 1 ft. Extension System - Gray

TEMPORARY CABLE GUARD



5' LONG X 10.5" WIDE X 2.75" HIGH
Accommodates a cable/bundle up to 2.25".
Withstands heavy vehicle traffic.
Part# TPG5

5' LONG X 4.5" WIDE X 1.25" HIGH
Accommodates cable up to .75" in diameter.
Withstands heavy vehicle traffic.
Part# TCG5

The Temporary Cable Guard withstands heavy vehicle traffic without damaging cable. Easily anchored with concrete screws if needed. The Temporary Cable Guard helps you restore services quickly by allowing you to run temporary cables over most any surface. It reduces truck rolls and eliminates downtime due to cable cuts, storm damage, traffic or roadway activities.

FILLERS & CONNECTORS

KO KILLERS: PLASTIC KNOCKOUT FILLERS

Fits thin (1/32") and thick (1/8") wall thickness.

Features:

- No tools required
- Snap in and out with ease
- Non-conductive, safer



- Part# KOK50 - 1/2" Filler (50/bag)
- Part# KOK75 - 3/4" Filler (50/bag)
- Part# KOK100 - 1" Filler (25/bag)
- Part# KOK125 - 1 1/4" Filler (25/bag)
- Part# KOK150 - 1 1/2" Filler (25/bag)
- Part# KOK200 - 2" Filler (25/bag)
- Part# KOK999 - Assorted Fillers Kit (25/bag)



RAT 500

Rapid Fire NMSC connector (100 Pack)

Suitable for all 1/2" knockouts
Fast and Easy. No tools required

Features:

- 50/bag
- Single cables
- Two cables
- Install from outside

RAT 750

Rapid Fire NMSC connector (50 pack)

Suitable for all 3/4" knockouts
Fast and Easy. No tools required

Features:

- 50/bag
- Single cables
- Install from outside

Part#

- RAT500 1/2" Connector
- RAT750 3/4" Connector



TT500

NMSC Two Way 1/2" Connector (100 Pack)

Installs from inside and outside the box

Features:

- 100/bag
- Single cables
- Two cables

Part#
TT500



STUD BUDDIES

(100 Pack)

- Why Square Bushing? 70% More cross sectional area! More cables, easier pulls.
- One piece
- One hand installation
- Fits all standard steel studs & punches
- Fire rated V.O.
- Faster, easier to use

Part#

- SB220 - ROUND
- SB240 - SQUARE



CROWS FEET

3/8" Metal Flange

Part# SCF38

Crow's Feet are a galvanized steel ceiling flange designed to accommodate 3/8" threaded rod.

Part#

- LJ50R - 1/2" (30 pack)
- LJ58R - 5/8" (25 Pack)
- LJ100R - 1" (15 Pack)



LEVEL JACK

HOW DOES IT WORK?

Alignment tabs reach across wood/metal studs to level low voltage outlets with A.C. boxes.

NO TAPE MEASURE • NO LEVEL REQUIRED

Available in 1/2", 5/8" and 1" rise

If you're fussy about your rough-in layout, the Level Jack makes life easy. If you're not, no one will notice because you can't screw up with the Level Jack.

Just clip it on to the AC box and screw it down. No level, no tape measure, no special boxes, no special fittings required. Level Jacks fit most AC boxes.



ELASCO PRODUCTS

Our Ultra Guards Collection can be used from light duty to heavy duty projects.

Elasco Dropover: Single channel that is 4 inches wide by 1 inch tall. Offered in a black color and solves your basic needs in the office or on site.

Elasco's UltraGuard collection cable guards come in standard 3-foot lengths. If your projects needs are to go in multiple directions, our 45 degree right angled turns assist in configuring your layout.

The LiteGuard collection offers 1" to 1.38" size channels. While smaller in size and weight, these products are still designed for significant load bearing strength. Commonly used in vehicle or pedestrian settings, the LiteGuard collection provides invaluable protection.

NOT ALL OPTIONS PICTURED. FOR FULL RANGE OF ITEMS AND PART NUMBERS VISIT RACK-A-TIERS.COM