



LED Corn Cobs

54CC/LED/840/ND EX39 G2 BB 6/1

Philips Corn Cob LED replacement lamps are perfect LED replacement for a variety of outdoor applications. High intensity illumination, which means you get added visibility for applications like streets, public areas, and much more for a fraction of the energy used by conventional HID.

Product data

General information	
Base	EX39 [Exclusionary Mogul Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	50000 h
Switching Cycle	50000X
Technical Type	54-250W
Light technical	
Color Code	841 [CCT of 4100K (841)]
Initial lumen (Nom)	7800 lm
Color Designation	Cool White (CW)
Correlated Color Temperature (Nom)	4000 K
Luminous Efficacy (rated) (Nom)	144.00 lm/W
Color Consistency	ANSI 4000K quadrangle
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	50 to 60 Hz
Power (Rated) (Nom)	54 W
Lamp Current (Nom)	600 mA
Wattage Equivalent	150-250 W
Starting Time (Nom)	1 s

Warm Up Time to 60% Light (Nom)	1 s
UL Type	Type B - bypass the ballast
Power Factor (Nom)	0.9
Voltage (Nom)	100-277 V
Temperature	
T-Case Maximum (Nom)	65 °C
Controls and dimming	
Dimmable	No
Mechanical and housing	
Bulb Finish	Clear
Bulb Material	Plastic
Bulb Shape	Corncob
Approval and application	
Energy Consumption kWh/1000 h	54 kWh
Product data	
Order product name	54CC/LED/840/ND EX39 G2 BB 6/1
EAN/UPC - Product	046677559793
Order code	559799

LED Corn Cobs

Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929002396804



Net Weight (Piece)	0.758 kg
--------------------	----------

Dimensional drawing

Product	D	C
54CC/LED/840/ND EX39 G2 BB 6/1	85 mm	245 mm

54CC/LED/840/ND EX39 G2 BB 6/1

Photometric data

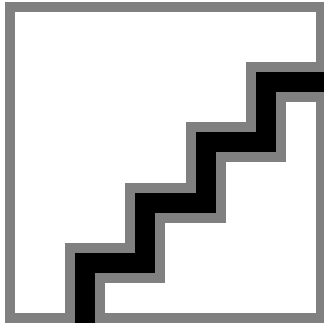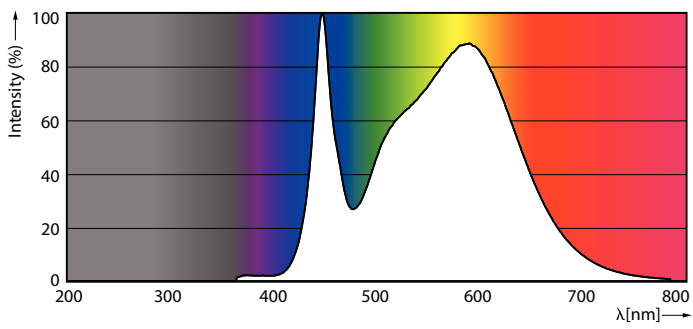

LEDTForce 54W Corncob EX39 840

LEDTForce 54W Corncob EX39 840

LEDTForce 54W Corncob EX39

LED Corn Cobs

Lifetime



50K

50K

