



Everything you value in a Halogen PAR38 with the benefits of LED. Accent your merchandise or space without distraction.

LED PAR38

Philips LED spots with a single optic beam, provide a clean beam that's free from shadows with beam angles from 15 and 40 degrees to suit every general lighting application.

Benefits

- Up to 80% energy saving compared with halogen lamps
- Lower maintenance costs
- Will not cause fading or damage

Features

- Lifetime of upto 40,000 hours
- Emit virtually no UV/IR light in the beam
- Upto CRI95
- Ranging between 3 to 5-year limited warranty
- Contains no mercury

LED PAR38

Application

- Hotels, restaurants, bars, cafés, lobbies
- Museums, exhibitions
- Retail shops

Versions



PAR30L



PAR38



PAR38



Single Contact Medium Screw PAR
4.75 inch/121mm Clear



Single Contact Medium Screw PAR
4.75 inch/121mm Clear






Single Contact Medium Screw PAR
4.75 inch/121mm Clear



Single Contact Medium Screw PAR
4.75 inch/121mm Clear

LED PAR38

Dimensional drawing

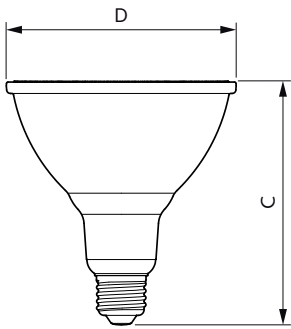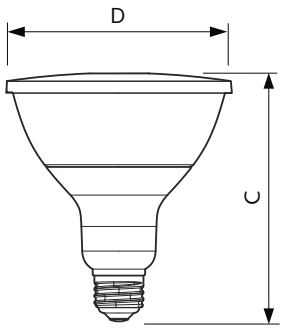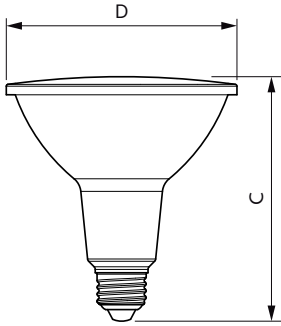


| Product | D | C |
|--|------------|-----------|
| 10PAR38/COR/930/F40/DIM/120V T20 6/1FB | 4-15/16 in | 5-3/16 in |
| 14PAR38/COR/927/F25/DIM/120V T20 6/1FB | 4-15/16 in | 5-3/16 in |
| 14PAR38/COR/927/F40/DIM/120V T20 6/1FB | 4-15/16 in | 5-3/16 in |
| 14PAR38/COR/930/F25/DIM/120V T20 6/1FB | 4-15/16 in | 5-3/16 in |
| 14PAR38/COR/930/F40/DIM/120V T20 6/1FB | 4-15/16 in | 5-3/16 in |
| 14PAR38/COR/935/F25/DIM/120V/T20 6/1FB | 4-7/8 in | 5-1/8 in |
| 14PAR38/COR/940/F25/DIM/120V/T20 6/1FB | 4-7/8 in | 5-1/8 in |

| Product | D | C |
|--|----------|------------|
| 17PAR38/EXPERTCOLOR/F40/940/DIM | 3-3/4 in | 3-11/16 in |
| 17PAR38/EXPERTCOLOR/S8/940/DIM/120V | 4-3/4 in | 5-5/16 in |
| 17PAR38/EXPERTCOLOR/F40/927/DIM | 4-3/4 in | 5-5/16 in |
| 17PAR38/EXPERTCOLOR/S8/927/DIM/120V | 4-3/4 in | 5-5/16 in |
| 17PAR38/EXPERTCOLOR/F25/927/DIM/120V | 4-3/4 in | 5-5/16 in |
| 17PAR38/EXPERTCOLOR/F25/927/DIM B | 4-3/4 in | 5-5/16 in |
| 17PAR38/EXPERTCOLOR/F25/940/DIM | 3-3/4 in | 3-11/16 in |
| 17PAR38/EXPERTCOLOR RETAIL/F25/930/DIM | 4-3/4 in | 5-5/16 in |
| 17PAR38/EXPERTCOLOR RETAIL/F40/930/DIM | 4-3/4 in | 5-5/16 in |
| 17PAR38/EXPERTCOLOR RETAIL/F25/930/DIM B | 4-3/4 in | 5-5/16 in |
| 17PAR38/EXPERTCOLOR RETAIL/S8/930/DIM | 4-3/4 in | 5-5/16 in |

| Product | D | C |
|--|------------|----------|
| 10PAR38/LED/930/F25/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 13PAR38/LED/950/F40/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 13PAR38/LED/940/F25/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 13PAR38/LED/927/F40/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 10PAR38/LED/940/F40/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 10PAR38/LED/950/F25/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 10PAR38/LED/927/F25/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 10PAR38/LED/930/F40/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 13PAR38/LED/927/F25/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 13PAR38/LED/940/F40/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 13PAR38/LED/950/F25/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 10PAR38/LED/940/F25/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |
| 13PAR38/LED/930/F25/DIM/GULW/T20 6/1FB | 4-13/16 in | 5-1/8 in |

LED PAR38

Dimensional drawing

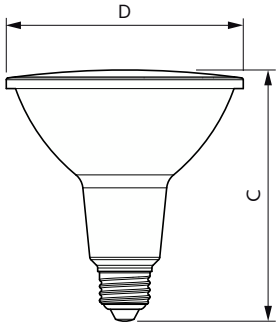

| Product | D | C |
|---|------------|-----------|
| 14PAR38/COR/930/F25/D/P/B/ULW/T20 6/1FB | 4-15/16 in | 5-3/16 in |

| Operating and electrical | |
|---------------------------------------|-------|
| Voltage (Nom) | 120 V |
| Starting Time (Nom) | 0.5 s |
| General information | |
| Cap-Base | E26 |
| Light technical | |
| Llmf At End Of Nominal Lifetime (Nom) | 70 % |
| Mechanical and housing | |
| Bulb Finish | Clear |
| Bulb Shape | PAR38 |

Approval and application

| Order Code | Full Product Name | Energy Consumption kWh/1000 h |
|------------|--|-------------------------------|
| 470996 | 17PAR38/EXPERTCOLOR RETAIL/S8/930/DIM | - kWh |
| 471003 | 17PAR38/EXPERTCOLOR RETAIL/F25/930/DIM | - kWh |
| 471011 | 17PAR38/EXPERTCOLOR RETAIL/F40/930/DIM | - kWh |
| 470823 | 17PAR38/EC/S8/927/DIM/120V 10/1 | - kWh |
| 470831 | 17PAR38/EC/F25/927/DIM/120V 6/1 | - kWh |
| 470849 | 17PAR38/EXPERTCOLOR/F40/927/DIM | - kWh |
| 471797 | 17PAR38/EXPERTCOLOR/S8/940/DIM/120V 6/1 | - kWh |
| 471029 | 17PAR38/EXPERTCOLOR RETAIL/F25/930/DIM B | - kWh |
| 470864 | 17PAR38/EXPERTCOLOR/F25/927/DIM B | - kWh |
| 470872 | 17PAR38/EXPERTCOLOR/F25/940/DIM | - kWh |
| 470880 | 17PAR38/EXPERTCOLOR/F40/940/DIM | - kWh |
| 546929 | 14PAR38/COR/927/F25/DIM/120V T20 6/1FB | - kWh |
| 546937 | 14PAR38/COR/927/F40/DIM/120V T20 6/1FB | - kWh |
| 546945 | 14PAR38/COR/930/F25/DIM/120V T20 6/1FB | - kWh |
| 546950 | 14PAR38/COR/930/F40/DIM/120V T20 6/1FB | - kWh |
| 551895 | 10PAR38/COR/930/F40/DIM/120V T20 6/1FB | - kWh |
| 577734 | 14PAR38/COR/935/F25/DIM/120V/T20 6/1FB | - |

| Order Code | Full Product Name | Energy Consumption kWh/1000 h |
|------------|---|-------------------------------|
| 577742 | 14PAR38/COR/940/F25/DIM/120V/T20 6/1FB | - |
| 567859 | 10PAR38/LED/927/F25/DIM/GULW/T20 6/1FB | - |
| 567867 | 10PAR38/LED/930/F25/DIM/GULW/T20 6/1FB | - |
| 567875 | 10PAR38/LED/940/F25/DIM/GULW/T20 6/1FB | - |
| 567883 | 10PAR38/LED/950/F25/DIM/GULW/T20 6/1FB | - |
| 567750 | 13PAR38/LED/927/F25/DIM/GULW/T20 6/1FB | - |
| 567768 | 13PAR38/LED/930/F25/DIM/GULW/T20 6/1FB | - |
| 567776 | 13PAR38/LED/940/F25/DIM/GULW/T20 6/1FB | - |
| 567784 | 13PAR38/LED/950/F25/DIM/GULW/T20 6/1FB | - |
| 567891 | 10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB | - |
| 567909 | 10PAR38/LED/930/F40/DIM/GULW/T20 6/1FB | - |
| 567917 | 10PAR38/LED/940/F40/DIM/GULW/T20 6/1FB | - |
| 567792 | 13PAR38/LED/927/F40/DIM/GULW/T20 6/1FB | - |
| 567800 | 13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB | - |
| 567818 | 13PAR38/LED/940/F40/DIM/GULW/T20 6/1FB | - |
| 567826 | 13PAR38/LED/950/F40/DIM/GULW/T20 6/1FB | - |
| 576470 | 14PAR38/COR/930/F25/D/P/B/ULW/T20 6/1FB | - |

Controls and dimming

LED PAR38

| Order Code | Full Product Name | Dimmable |
|------------|--|----------------------------|
| 470996 | 17PAR38/EXPERTCOLOR RETAIL/S8/930/DIM | Yes |
| 471003 | 17PAR38/EXPERTCOLOR RETAIL/F25/930/DIM | Yes |
| 471011 | 17PAR38/EXPERTCOLOR RETAIL/F40/930/DIM | Yes |
| 470823 | 17PAR38/EC/S8/927/DIM/120V 10/1 | Yes |
| 470831 | 17PAR38/EC/F25/927/DIM/120V 6/1 | Yes |
| 470849 | 17PAR38/EXPERTCOLOR/F40/927/DIM | Yes |
| 471797 | 17PAR38/EXPERTCOLOR/S8/940/DIM/120V 6/1 | Yes |
| 471029 | 17PAR38/EXPERTCOLOR RETAIL/F25/930/DIM B | Yes |
| 470864 | 17PAR38/EXPERTCOLOR/F25/927/DIM B | Yes |
| 470872 | 17PAR38/EXPERTCOLOR/F25/940/DIM | Yes |
| 470880 | 17PAR38/EXPERTCOLOR/F40/940/DIM | Yes |
| 546929 | 14PAR38/COR/927/F25/DIM/120V T20 6/1FB | Yes |
| 546937 | 14PAR38/COR/927/F40/DIM/120V T20 6/1FB | Yes |
| 546945 | 14PAR38/COR/930/F25/DIM/120V T20 6/1FB | Yes |
| 546950 | 14PAR38/COR/930/F40/DIM/120V T20 6/1FB | Yes |
| 551895 | 10PAR38/COR/930/F40/DIM/120V T20 6/1FB | Yes |
| 577734 | 14PAR38/COR/935/F25/DIM/120V/T20 6/1FB | Only with specific dimmers |
| 577742 | 14PAR38/COR/940/F25/DIM/120V/T20 6/1FB | Only with specific dimmers |
| 567859 | 10PAR38/LED/927/F25/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 567867 | 10PAR38/LED/930/F25/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 567875 | 10PAR38/LED/940/F25/DIM/GULW/T20 6/1FB | Only with specific dimmers |

| Order Code | Full Product Name | Dimmable |
|------------|---|----------------------------|
| 567883 | 10PAR38/LED/950/F25/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 567750 | 13PAR38/LED/927/F25/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 567768 | 13PAR38/LED/930/F25/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 567776 | 13PAR38/LED/940/F25/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 567784 | 13PAR38/LED/950/F25/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 567891 | 10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 567909 | 10PAR38/LED/930/F40/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 567917 | 10PAR38/LED/940/F40/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 567792 | 13PAR38/LED/927/F40/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 567800 | 13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 567818 | 13PAR38/LED/940/F40/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 567826 | 13PAR38/LED/950/F40/DIM/GULW/T20 6/1FB | Only with specific dimmers |
| 576470 | 14PAR38/COR/930/F25/D/P/B/ULW/T20 6/1FB | Only with specific dimmers |

Operating and electrical

| Order Code | Full Product Name | Input Frequency | Wattage Equivalent | Power (Nom) |
|------------|--|-----------------|--------------------|-------------|
| 470996 | 17PAR38/EXPERTCOLOR RETAIL/S8/930/DIM | 60 Hz | 100 W | 17 W |
| 471003 | 17PAR38/EXPERTCOLOR RETAIL/F25/930/DIM | 60 Hz | 120 W | 17 W |
| 471011 | 17PAR38/EXPERTCOLOR RETAIL/F40/930/DIM | 60 Hz | 120 W | 17 W |
| 470823 | 17PAR38/EC/S8/927/DIM/120V 10/1 | 60 Hz | 100 W | 17 W |
| 470831 | 17PAR38/EC/F25/927/DIM/120V 6/1 | 60 Hz | 120 W | 17 W |
| 470849 | 17PAR38/EXPERTCOLOR/F40/927/DIM | 60 Hz | 120 W | 17 W |
| 471797 | 17PAR38/EXPERTCOLOR/S8/940/DIM/120V 6/1 | 60 Hz | 100 W | 17 W |
| 471029 | 17PAR38/EXPERTCOLOR RETAIL/F25/930/DIM B | 60 Hz | 120 W | 17 W |
| 470864 | 17PAR38/EXPERTCOLOR/F25/927/DIM B | 60 Hz | 120 W | 17 W |
| 470872 | 17PAR38/EXPERTCOLOR/F25/940/DIM | 60 Hz | 120 W | 17 W |

| Order Code | Full Product Name | Input Frequency | Wattage Equivalent | Power (Nom) |
|------------|--|-----------------|--------------------|-------------|
| 470880 | 17PAR38/EXPERTCOLOR/F40/940/DIM | 60 Hz | 120 W | 17 W |
| 546929 | 14PAR38/COR/927/F25/DIM/120V T20 6/1FB | 50 to 60 Hz | 120 W | 14 W |
| 546937 | 14PAR38/COR/927/F40/DIM/120V T20 6/1FB | 50 to 60 Hz | 120 W | 14 W |
| 546945 | 14PAR38/COR/930/F25/DIM/120V T20 6/1FB | 50 to 60 Hz | 120 W | 14 W |
| 546950 | 14PAR38/COR/930/F40/DIM/120V T20 6/1FB | 50 to 60 Hz | 120 W | 14 W |
| 551895 | 10PAR38/COR/930/F40/DIM/120V T20 6/1FB | 50 to 60 Hz | 90 W | 10 W |
| 577734 | 14PAR38/COR/935/F25/DIM/120V/T20 6/1FB | 50 to 60 Hz | 120 W | 14 W |
| 577742 | 14PAR38/COR/940/F25/DIM/120V/T20 6/1FB | 50 to 60 Hz | 120 W | 14 W |
| 567859 | 10PAR38/LED/927/F25/DIM/GULW/T20 6/1FB | 50 to 60 Hz | 90 W | 10 W |
| 567867 | 10PAR38/LED/930/F25/DIM/GULW/T20 6/1FB | 50 to 60 Hz | 90 W | 10 W |

LED PAR38

| Order Code | Full Product Name | Input Frequency | Wattage Equivalent | Power (Nom) |
|------------|--|-----------------|--------------------|-------------|
| 567875 | 10PAR38/LED/940/F25/DIM/ GULW/T20 6/1FB | 50 to 60 Hz | 90 W | 10 W |
| 567883 | 10PAR38/LED/950/F25/DIM/ GULW/T20 6/1FB | 50 to 60 Hz | 90 W | 10 W |
| 567750 | 13PAR38/LED/927/F25/DIM/ GULW/T20 6/1FB | 50 to 60 Hz | 120 W | 13 W |
| 567768 | 13PAR38/LED/930/F25/DIM/ GULW/T20 6/1FB | 50 to 60 Hz | 120 W | 13 W |
| 567776 | 13PAR38/LED/940/F25/DIM/ GULW/T20 6/1FB | 50 to 60 Hz | 120 W | 13 W |
| 567784 | 13PAR38/LED/950/F25/DIM/ GULW/T20 6/1FB | 50 to 60 Hz | 120 W | 13 W |
| 567891 | 10PAR38/LED/927/F40/DIM/ GULW/T20 6/1FB | 50 to 60 Hz | 90 W | 10 W |

| Order Code | Full Product Name | Input Frequency | Wattage Equivalent | Power (Nom) |
|------------|---|-----------------|--------------------|-------------|
| 567909 | 10PAR38/LED/930/F40/DIM/ GULW/T20 6/1FB | 50 to 60 Hz | 90 W | 10 W |
| 567917 | 10PAR38/LED/940/F40/DIM/ GULW/T20 6/1FB | 50 to 60 Hz | 90 W | 10 W |
| 567792 | 13PAR38/LED/927/F40/DIM/ GULW/T20 6/1FB | 50 to 60 Hz | 120 W | 13 W |
| 567800 | 13PAR38/LED/930/F40/DIM/ GULW/T20 6/1FB | 50 to 60 Hz | 120 W | 13 W |
| 567818 | 13PAR38/LED/940/F40/DIM/ GULW/T20 6/1FB | 50 to 60 Hz | 120 W | 13 W |
| 567826 | 13PAR38/LED/950/F40/DIM/ GULW/T20 6/1FB | 50 to 60 Hz | 120 W | 13 W |
| 576470 | 14PAR38/COR/930/F25/D/P/ B/ULW/T20 6/1FB | 50 to 60 Hz | 120 W | 14 W |

General information

| Order Code | Full Product Name | Nominal Lifetime (Nom) | Switching Cycle |
|------------|--|------------------------|-----------------|
| 470996 | 17PAR38/EXPERTCOLOR RETAIL/ S8/930/DIM | 25000 h | 50000 |
| 471003 | 17PAR38/EXPERTCOLOR RETAIL/ F25/930/DIM | 25000 h | 50000 |
| 471011 | 17PAR38/EXPERTCOLOR RETAIL/ F40/930/DIM | 25000 h | 50000 |
| 470823 | 17PAR38/EC/S8/927/DIM/120V 10/1 | 40000 h | 50000 |
| 470831 | 17PAR38/EC/F25/927/DIM/120V 6/1 | 40000 h | 50000 |
| 470849 | 17PAR38/EXPERTCOLOR/F40/927/DIM | 40000 h | 50000 |
| 471797 | 17PAR38/EXPERTCOLOR/S8/940/DIM/ 120V 6/1 | 40000 h | 50000 |
| 471029 | 17PAR38/EXPERTCOLOR RETAIL/ F25/930/DIM B | 25000 h | 50000 |
| 470864 | 17PAR38/EXPERTCOLOR/F25/927/DIM B | 40000 h | 50000 |
| 470872 | 17PAR38/EXPERTCOLOR/F25/940/DIM | 40000 h | 50000 |
| 470880 | 17PAR38/EXPERTCOLOR/F40/940/DIM | 40000 h | 50000 |
| 546929 | 14PAR38/COR/927/F25/DIM/120V T20 6/1FB | 25000 h | 50000 |
| 546937 | 14PAR38/COR/927/F40/DIM/120V T20 6/1FB | 25000 h | 50000 |
| 546945 | 14PAR38/COR/930/F25/DIM/120V T20 6/1FB | 25000 h | 50000 |
| 546950 | 14PAR38/COR/930/F40/DIM/120V T20 6/1FB | 25000 h | 50000 |
| 551895 | 10PAR38/COR/930/F40/DIM/120V T20 6/1FB | 25000 h | 50000 |
| 577734 | 14PAR38/COR/935/F25/DIM/120V/T20 6/1FB | 25000 h | 50000 |
| 577742 | 14PAR38/COR/940/F25/DIM/120V/T20 6/1FB | 25000 h | 50000 |
| 567859 | 10PAR38/LED/927/F25/DIM/GULW/T20 6/1FB | 25000 h | 50000 |

| Order Code | Full Product Name | Nominal Lifetime (Nom) | Switching Cycle |
|------------|--|------------------------|-----------------|
| 567867 | 10PAR38/LED/930/F25/DIM/GULW/T20 6/1FB | 25000 h | 50000 |
| 567875 | 10PAR38/LED/940/F25/DIM/GULW/T20 6/1FB | 25000 h | 50000 |
| 567883 | 10PAR38/LED/950/F25/DIM/GULW/T20 6/1FB | 25000 h | 50000 |
| 567750 | 13PAR38/LED/927/F25/DIM/GULW/T20 6/1FB | 25000 h | 25000 |
| 567768 | 13PAR38/LED/930/F25/DIM/GULW/T20 6/1FB | 25000 h | 25000 |
| 567776 | 13PAR38/LED/940/F25/DIM/GULW/T20 6/1FB | 25000 h | 25000 |
| 567784 | 13PAR38/LED/950/F25/DIM/GULW/T20 6/1FB | 25000 h | 25000 |
| 567891 | 10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB | 25000 h | 50000 |
| 567909 | 10PAR38/LED/930/F40/DIM/GULW/T20 6/1FB | 25000 h | 50000 |
| 567917 | 10PAR38/LED/940/F40/DIM/GULW/T20 6/1FB | 25000 h | 50000 |
| 567792 | 13PAR38/LED/927/F40/DIM/GULW/T20 6/1FB | 25000 h | 50000 |
| 567800 | 13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB | 25000 h | 50000 |
| 567818 | 13PAR38/LED/940/F40/DIM/GULW/T20 6/1FB | 25000 h | 50000 |
| 567826 | 13PAR38/LED/950/F40/DIM/GULW/T20 6/1FB | 25000 h | 50000 |
| 576470 | 14PAR38/COR/930/F25/D/P/B/ULW/T20 6/1FB | 25000 h | 50000 |

LED PAR38

Light technical










| Order Code | Full Product Name | Beam Angle (Nom) | Color Code | Correlated Color Temperature (Nom) | Color | | |
|------------|--|---------------------|---------------|---------------------------------------|--------------------------|------------------------|-----------------------------|
| | | | | | Rendering Index (Nom) | Luminous Flux (Nom) | Luminous Intensity (Nom) |
| 470996 | 17PAR38/EXPERTCOLOR RETAIL/S8/930/DIM | 8 ° | 930 | 3000 K | 90 | 1200 lm | 22000 cd |
| 471003 | 17PAR38/EXPERTCOLOR RETAIL/F25/930/DIM | 25 ° | 930 | 3000 K | 90 | 1200 lm | 6000 cd |
| 471011 | 17PAR38/EXPERTCOLOR RETAIL/F40/930/DIM | 40 ° | 930 | 3000 K | 90 | 1200 lm | 2700 cd |
| 470823 | 17PAR38/EC/S8/927/DIM/120V 10/1 | 8 ° | 927 | 2700 K | 95 | 1150 lm | 21000 cd |
| 470831 | 17PAR38/EC/F25/927/DIM/120V 6/1 | 25 ° | 927 | 2700 K | 95 | 1150 lm | 5800 cd |
| 470849 | 17PAR38/EXPERTCOLOR/F40/927/DIM | 40 ° | 927 | 2700 K | 95 | 1150 lm | 2600 cd |
| 471797 | 17PAR38/EXPERTCOLOR/S8/940/DIM/120V 6/1 | 8 ° | 940 | 4000 K | 95 | 1300 lm | 25000 cd |
| 471029 | 17PAR38/EXPERTCOLOR RETAIL/F25/930/DIM B | 25 ° | 930 | 3000 K | 90 | 1200 lm | 6000 cd |
| 470864 | 17PAR38/EXPERTCOLOR/F25/927/DIM B | 25 ° | 927 | 2700 K | 95 | 1150 lm | 5800 cd |
| 470872 | 17PAR38/EXPERTCOLOR/F25/940/DIM | 25 ° | 940 | 4000 K | 95 | 1300 lm | 6500 cd |
| 470880 | 17PAR38/EXPERTCOLOR/F40/940/DIM | 40 ° | 940 | 4000 K | 95 | 1300 lm | 3000 cd |
| 546929 | 14PAR38/COR/927/F25/DIM/120V T20 6/1FB | 25 ° | 927 | 2700 K | 90 | 1300 lm | 5382 cd |
| 546937 | 14PAR38/COR/927/F40/DIM/120V T20 6/1FB | 40 ° | 927 | 2700 K | 90 | 1300 lm | 2231 cd |
| 546945 | 14PAR38/COR/930/F25/DIM/120V T20 6/1FB | 25 ° | 930 | 3000 K | 90 | 1300 lm | 5382 cd |
| 546950 | 14PAR38/COR/930/F40/DIM/120V T20 6/1FB | 40 ° | 930 | 3000 K | 90 | 1300 lm | 2231 cd |
| 551895 | 10PAR38/COR/930/F40/DIM/120V T20 6/1FB | 40 ° | 930 | 3000 K | 90 | 900 lm | 1533 cd |
| 577734 | 14PAR38/COR/935/F25/DIM/120V/T20 6/1FB | 25 ° | 935 | 3500 K | 90 | 1300 lm | 5382 cd |
| 577742 | 14PAR38/COR/940/F25/DIM/120V/T20 6/1FB | 25 ° | 940 | 4000 K | 90 | 1300 lm | 5382 cd |
| 567859 | 10PAR38/LED/927/F25/DIM/GULW/T20 6/1FB | 25 ° | 927 | 2700 K | 90 | 900 lm | 4100 cd |
| 567867 | 10PAR38/LED/930/F25/DIM/GULW/T20 6/1FB | 25 ° | 930 | 3000 K | 90 | 900 lm | 4100 cd |
| 567875 | 10PAR38/LED/940/F25/DIM/GULW/T20 6/1FB | 25 ° | 940 | 4000 K | 90 | 900 lm | 4100 cd |
| 567883 | 10PAR38/LED/950/F25/DIM/GULW/T20 6/1FB | 25 ° | 950 | 5000 K | 90 | 900 lm | 4100 cd |
| 567750 | 13PAR38/LED/927/F25/DIM/GULW/T20 6/1FB | 25 ° | 927 | 2700 K | 90 | 1200 lm | 5700 cd |
| 567768 | 13PAR38/LED/930/F25/DIM/GULW/T20 6/1FB | 25 ° | 930 | 3000 K | 90 | 1200 lm | 6000 cd |
| 567776 | 13PAR38/LED/940/F25/DIM/GULW/T20 6/1FB | 25 ° | 940 | 4000 K | 90 | 1200 lm | 6000 cd |
| 567784 | 13PAR38/LED/950/F25/DIM/GULW/T20 6/1FB | 25 ° | 950 | 5000 K | 90 | 1200 lm | 6000 cd |
| 567891 | 10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB | 40 ° | 927 | 2700 K | 90 | 900 lm | 1800 cd |
| 567909 | 10PAR38/LED/930/F40/DIM/GULW/T20 6/1FB | 40 ° | 930 | 3000 K | 90 | 900 lm | 1900 cd |
| 567917 | 10PAR38/LED/940/F40/DIM/GULW/T20 6/1FB | 40 ° | 940 | 4000 K | 90 | 900 lm | 1900 cd |
| 567792 | 13PAR38/LED/927/F40/DIM/GULW/T20 6/1FB | 40 ° | 927 | 2700 K | 90 | 1200 lm | 2450 cd |
| 567800 | 13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB | 40 ° | 930 | 3000 K | 90 | 1200 lm | 2500 cd |
| 567818 | 13PAR38/LED/940/F40/DIM/GULW/T20 6/1FB | 40 ° | 940 | 4000 K | 90 | 1200 lm | 2500 cd |
| 567826 | 13PAR38/LED/950/F40/DIM/GULW/T20 6/1FB | 40 ° | 950 | 5000 K | 90 | 1200 lm | 2500 cd |
| 576470 | 14PAR38/COR/930/F25/D/P/B/ULW/T20 6/1FB | 25 ° | 930 | 3000 K | 90 | 1300 lm | 5382 cd |

Temperature











| Order Code | Full Product Name | T-Case Maximum (Nom) | Order Code | Full Product Name | T-Case Maximum (Nom) |
|------------|--|-------------------------|------------|--|-------------------------|
| 470996 | 17PAR38/EXPERTCOLOR RETAIL/S8/930/DIM | 194 °F | 470872 | 17PAR38/EXPERTCOLOR/F25/940/DIM | 194 °F |
| 471003 | 17PAR38/EXPERTCOLOR RETAIL/F25/930/DIM | 194 °F | 470880 | 17PAR38/EXPERTCOLOR/F40/940/DIM | 194 °F |
| 471011 | 17PAR38/EXPERTCOLOR RETAIL/F40/930/DIM | 194 °F | 546929 | 14PAR38/COR/927/F25/DIM/120V T20 6/1FB | 185 °F |
| 470823 | 17PAR38/EC/S8/927/DIM/120V 10/1 | 194 °F | 546937 | 14PAR38/COR/927/F40/DIM/120V T20 6/1FB | 185 °F |
| 470831 | 17PAR38/EC/F25/927/DIM/120V 6/1 | 194 °F | 546945 | 14PAR38/COR/930/F25/DIM/120V T20 6/1FB | 185 °F |
| 470849 | 17PAR38/EXPERTCOLOR/F40/927/DIM | 194 °F | 546950 | 14PAR38/COR/930/F40/DIM/120V T20 6/1FB | 185 °F |
| 471797 | 17PAR38/EXPERTCOLOR/S8/940/DIM/120V 6/1 | 194 °F | 551895 | 10PAR38/COR/930/F40/DIM/120V T20 6/1FB | 176 °F |
| 471029 | 17PAR38/EXPERTCOLOR RETAIL/F25/930/DIM B | 194 °F | 577734 | 14PAR38/COR/935/F25/DIM/120V/T20 6/1FB | 167 °F |
| 470864 | 17PAR38/EXPERTCOLOR/F25/927/DIM B | 194 °F | 577742 | 14PAR38/COR/940/F25/DIM/120V/T20 6/1FB | 167 °F |

LED PAR38











| Order Code | Full Product Name | T-Case Maximum (Nom) |
|------------|---|----------------------|
| 567859 | 10PAR38/LED/927/F25/DIM/GULW/T20 6/1FB | 158 °F |
| 567867 | 10PAR38/LED/930/F25/DIM/GULW/T20 6/1FB | 158 °F |
| 567875 | 10PAR38/LED/940/F25/DIM/GULW/T20 6/1FB | 158 °F |
| 567883 | 10PAR38/LED/950/F25/DIM/GULW/T20 6/1FB | 158 °F |
| 567750 | 13PAR38/LED/927/F25/DIM/GULW/T20 6/1FB | 167 °F |
| 567768 | 13PAR38/LED/930/F25/DIM/GULW/T20 6/1FB | 167 °F |
| 567776 | 13PAR38/LED/940/F25/DIM/GULW/T20 6/1FB | 167 °F |
| 567784 | 13PAR38/LED/950/F25/DIM/GULW/T20 6/1FB | 167 °F |
| 567891 | 10PAR38/LED/927/F40/DIM/GULW/T20 6/1FB | 158 °F |
| 567909 | 10PAR38/LED/930/F40/DIM/GULW/T20 6/1FB | 158 °F |
| 567917 | 10PAR38/LED/940/F40/DIM/GULW/T20 6/1FB | 158 °F |
| 567792 | 13PAR38/LED/927/F40/DIM/GULW/T20 6/1FB | 167 °F |
| 567800 | 13PAR38/LED/930/F40/DIM/GULW/T20 6/1FB | 167 °F |
| 567818 | 13PAR38/LED/940/F40/DIM/GULW/T20 6/1FB | 167 °F |
| 567826 | 13PAR38/LED/950/F40/DIM/GULW/T20 6/1FB | 167 °F |
| 576470 | 14PAR38/COR/930/F25/D/P/B/ULW/T20 6/1FB | 185 °F |

 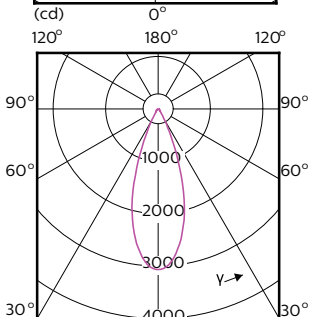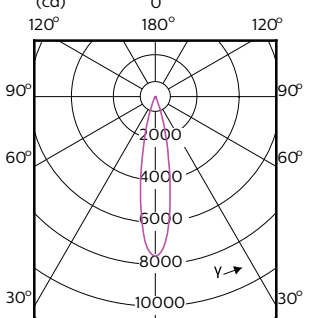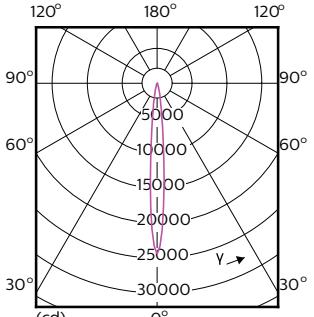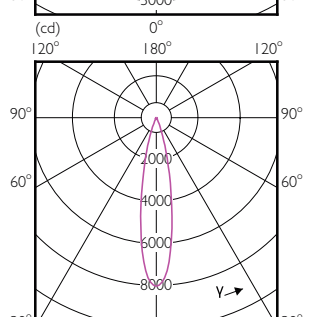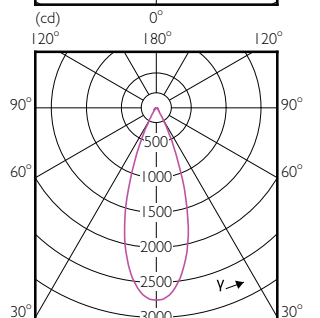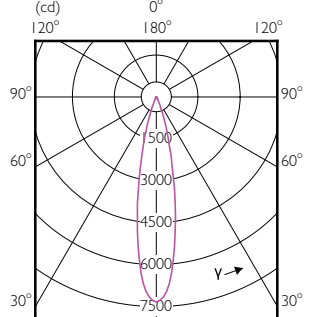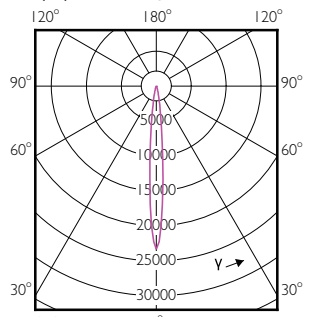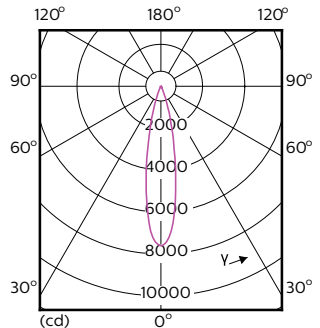



LED PAR38

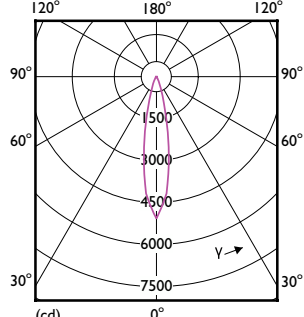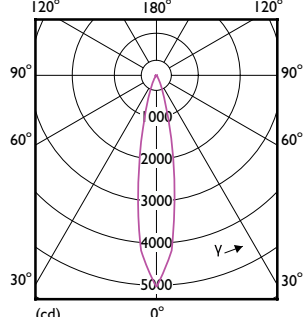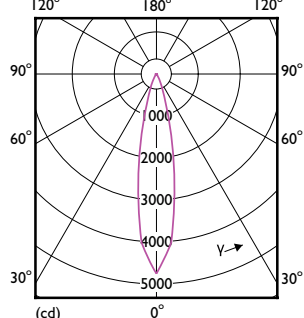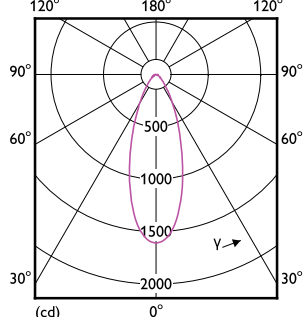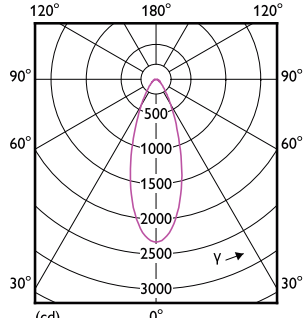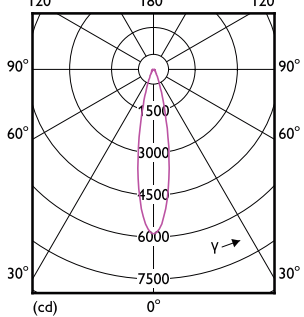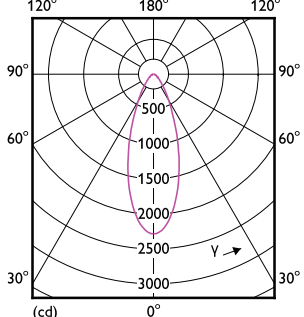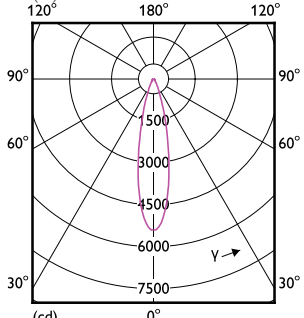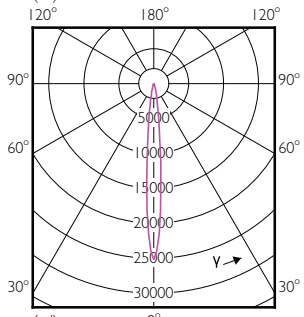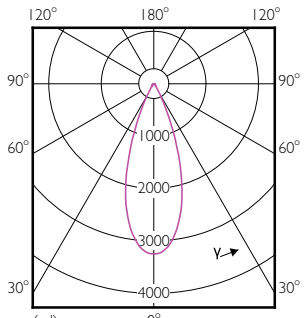


LED PAR38

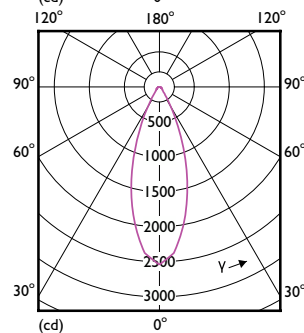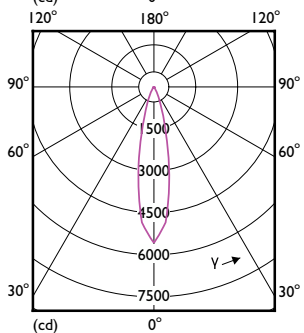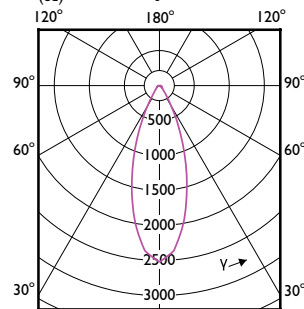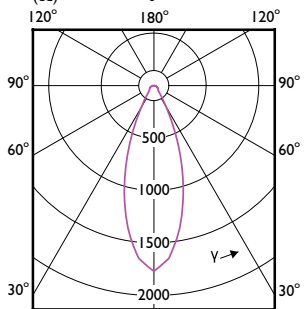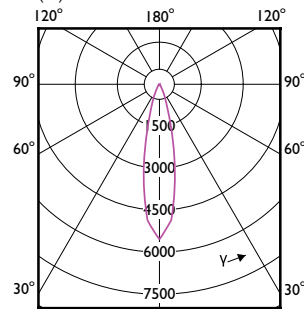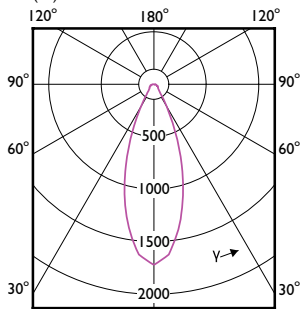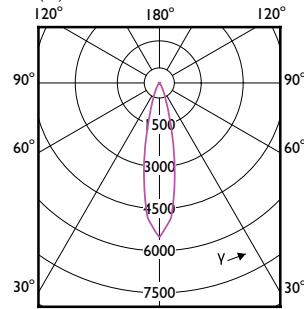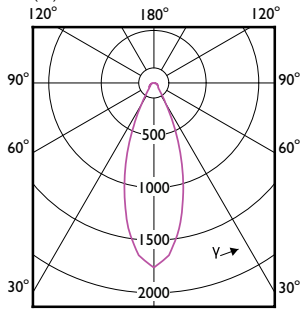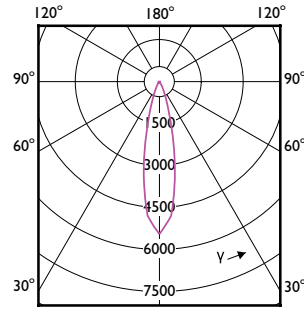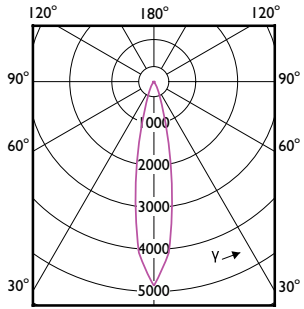


LED PAR38

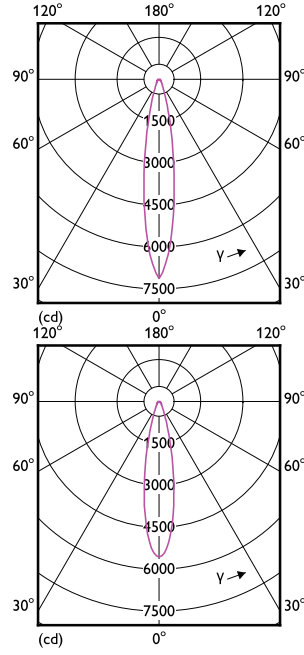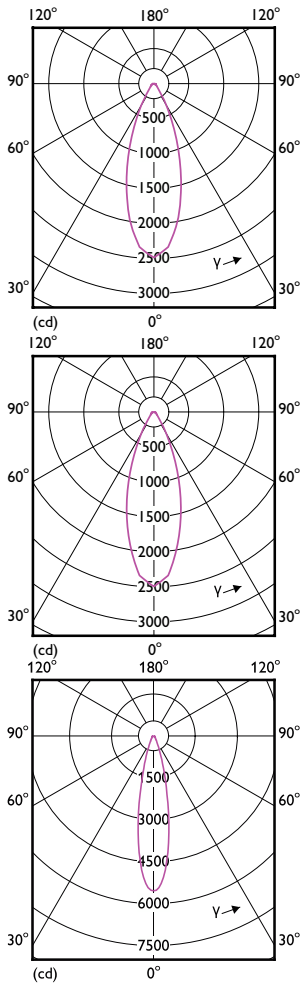


Accent Diagrams

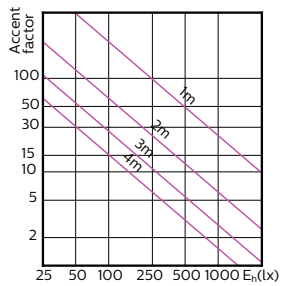

PAR38 120V 17-90W 1200lm 8D 3000K E26 D

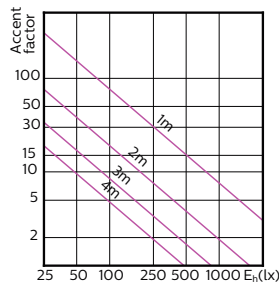


PAR38 120V 17-120W 25D 3000K E26 D WH

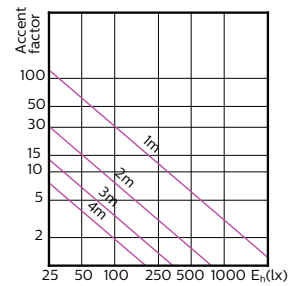


PAR38 120V 17-120W 40D 3000K E26 D

LED PAR38


Accent Diagrams

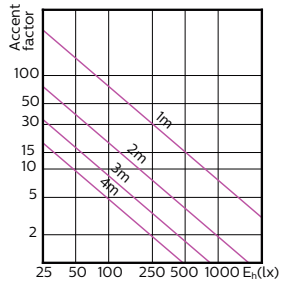


PAR38 120V 17-120W 25D 3000K E26 D BL

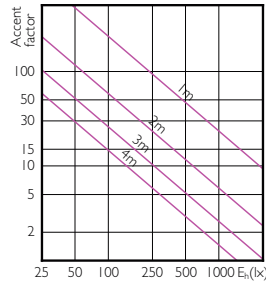


PAR38_17W_1150lm 8D 2700K_E26

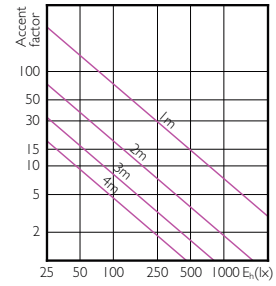


PAR38_17W_1150lm 25D 2700K_E26

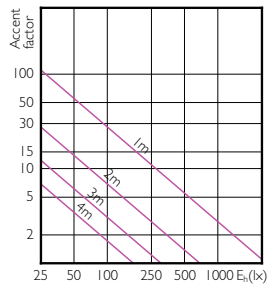


PAR38_17W_1150lm 40D 2700K_E26

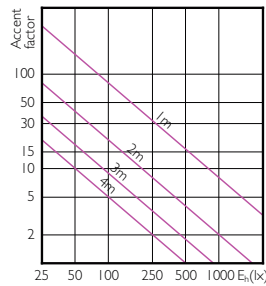


PAR38 17W 1300lm 25D 4000K E26

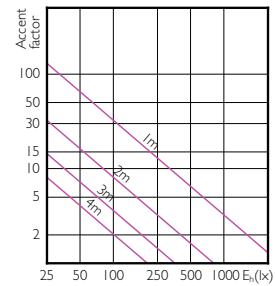


PAR38 17W 1300lm 40D 4000K E26

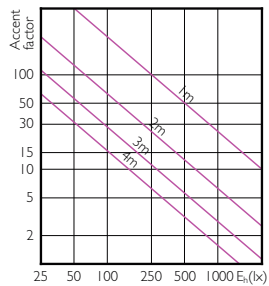


PAR38 17W 1300lm 8D 4000K E26

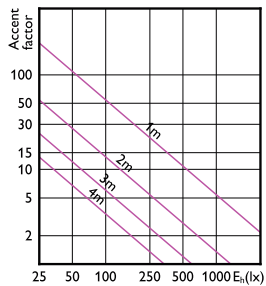


LEDspots 14W PAR38 E26 927 25D

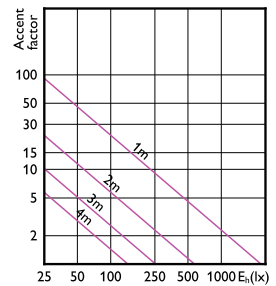


LEDspots 14W PAR38 E26 927 40D

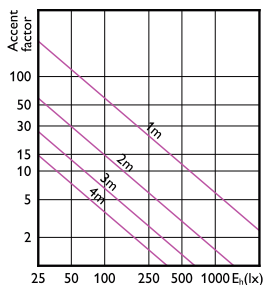

LEDspots 14W PAR38 E26 930 25D

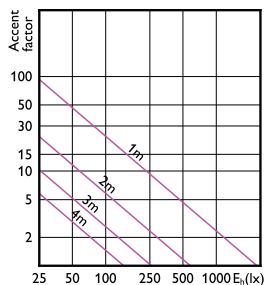


LEDspots 14W PAR38 E26 930 40D

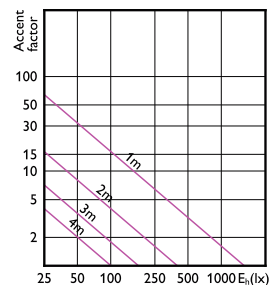


LEDspots 10W PAR38 E26 930 40D

LED PAR38


Accent Diagrams

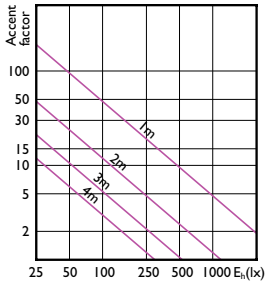


LEDspots N DIM 10W PAR38 E26 927 25D-LA2

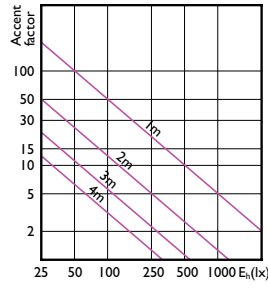


LEDspots N DIM 10W PAR38 E26 930 25D-LA2

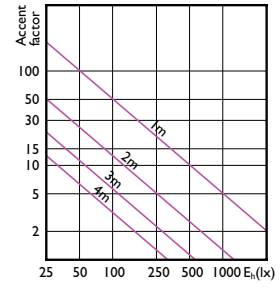


LEDspots N DIM 10W PAR38 E26 940 25D-LA2

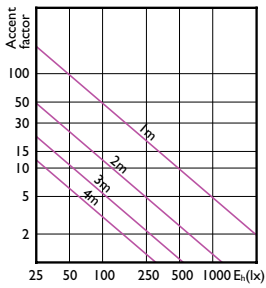


LEDspots N DIM 10W PAR38 E26 950 25D-LA2

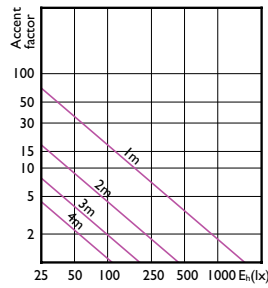


LEDspots N DIM 10W PAR38 E26 927 40D-LA2

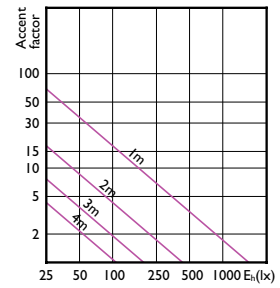


LEDspots N DIM 10W PAR38 E26 930 40D-LA2

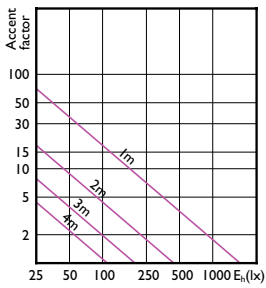


LEDspots N DIM 10W PAR38 E26 940 40D-LA2

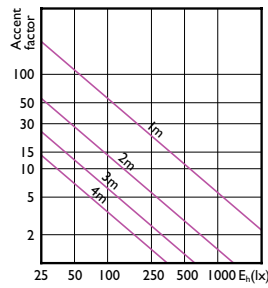


LEDspots N DIM 13W PAR38 E26 927 25D-LA2

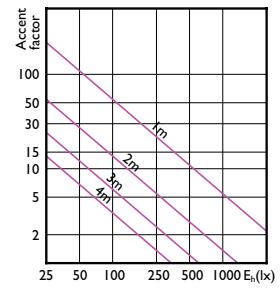


LEDspots N DIM 13W PAR38 E26 930 25D-LA2

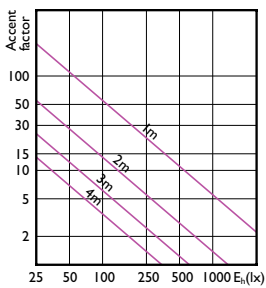

LEDspots N DIM 13W PAR38 E26 940 25D-LA2

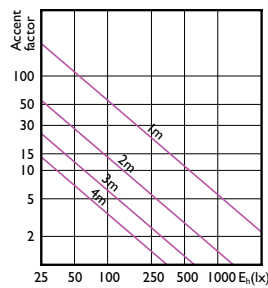


LEDspots N DIM 13W PAR38 E26 950 25D-LA2

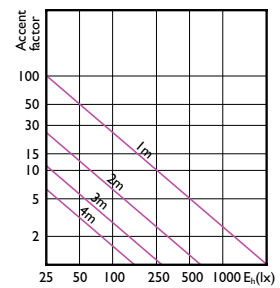


LEDspots N DIM 13W PAR38 E26 927 40D-LA2

LED PAR38


Accent Diagrams

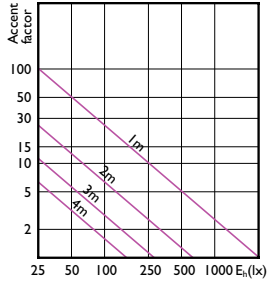


LEDspots N DIM 13W PAR38 E26 930 40D-LA2

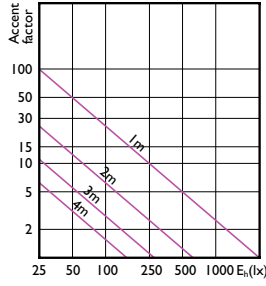


LEDspots N DIM 13W PAR38 E26 940 40D-LA2

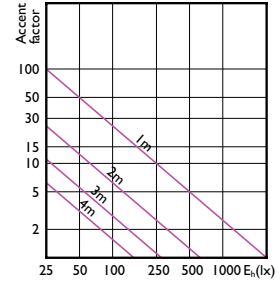


LEDspots N DIM 13W PAR38 E26 950 40D-LA2

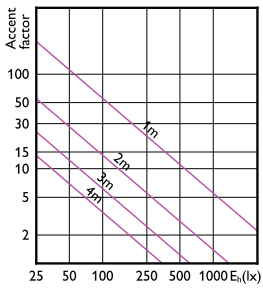

LEDspots BH 14W PAR38 E26 930 25D-LA2

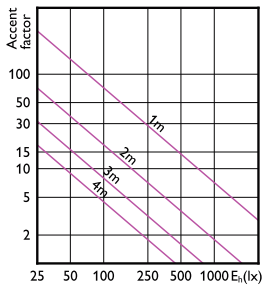


Accent Diagram

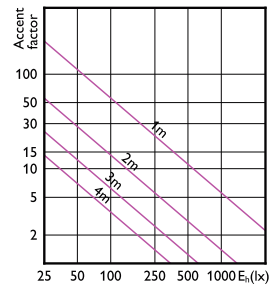

Accent Diagram


Beam Diagrams

PAR38 120V 17-90W 1200lm 8D 3000K E26 D

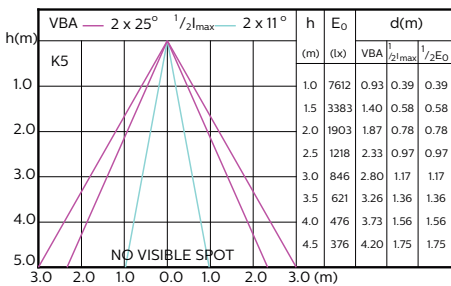


PAR38 120V 17-120W 25D 3000K E26 D BL

PAR38 120V 17-120W 25D 3000K E26 D WH

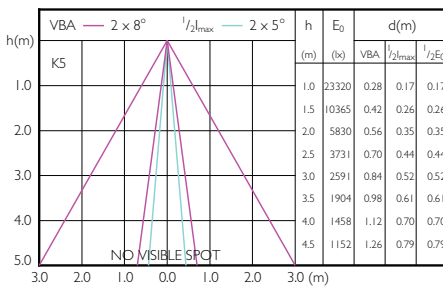

PAR38_17W_1150lm 8D 2700K_E26


PAR38 120V 17-120W 40D 3000K E26 D

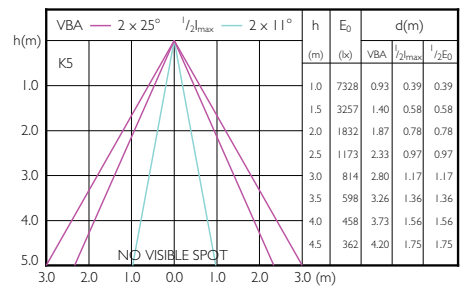


PAR38_17W_1150lm 25D 2700K_E26

LED PAR38


Beam Diagrams

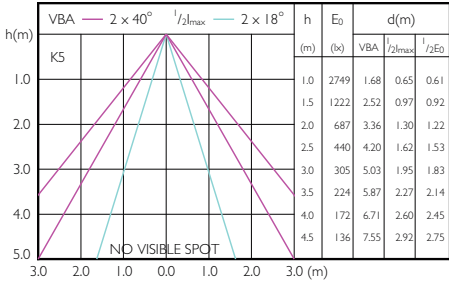


PAR38_17W_1150lm 40D 2700K_E26

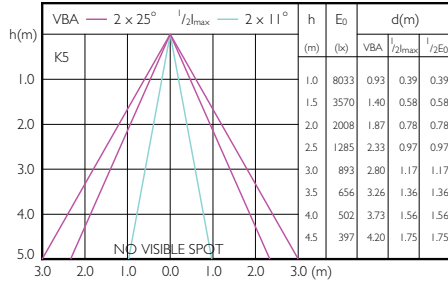


PAR38 17W 1300lm 25D 4000K E26

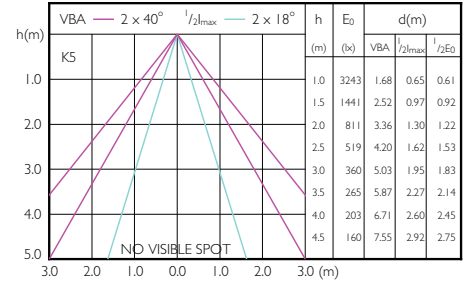


PAR38 17W 1300lm 40D 4000K E26

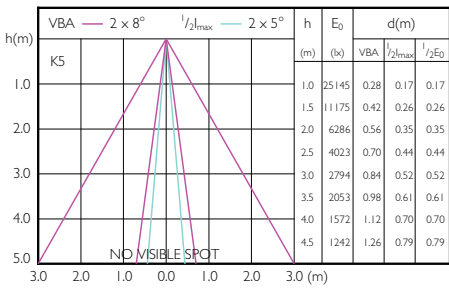


PAR38 17W 1300lm 8D 4000K E26

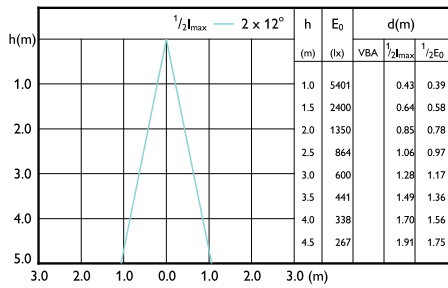


LEDspots 14W PAR38 E26 927 25D

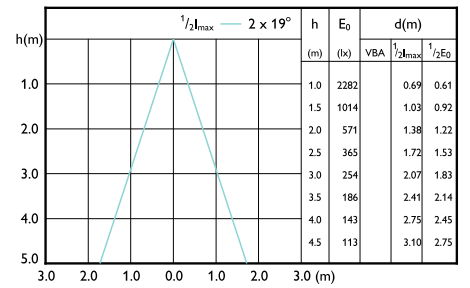


LEDspots 14W PAR38 E26 927 40D

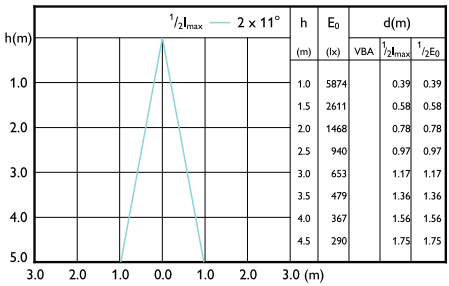


LEDspots 14W PAR38 E26 930 25D

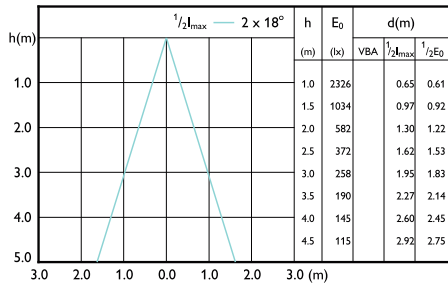


LEDspots 14W PAR38 E26 930 40D

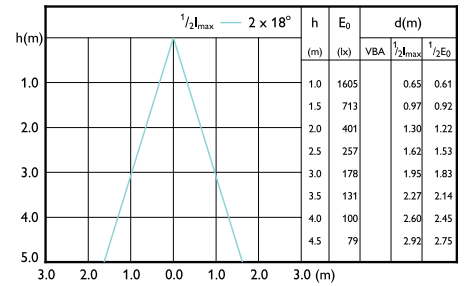


LEDspots 10W PAR38 E26 930 40D

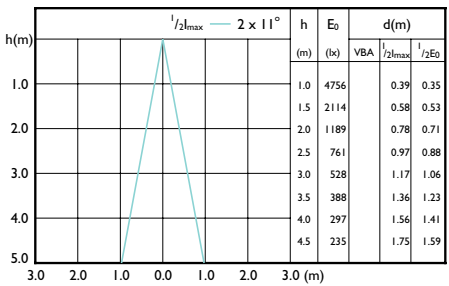

LEDspots N DIM 10W PAR38 E26 927 25D-LBP

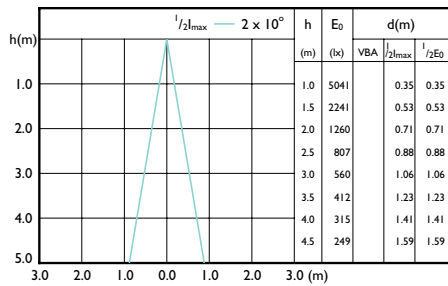


LEDspots N DIM 10W PAR38 E26 930 25D-LBP

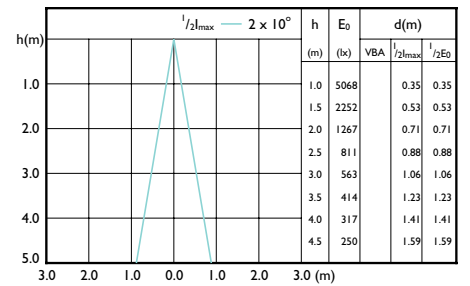


LEDspots N DIM 10W PAR38 E26 940 25D-LBP

LED PAR38


Beam Diagrams

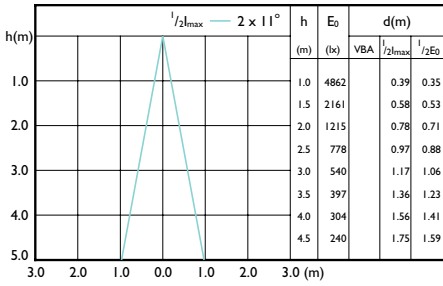


LEDspots N DIM 10W PAR38 E26 950 25D-LBP

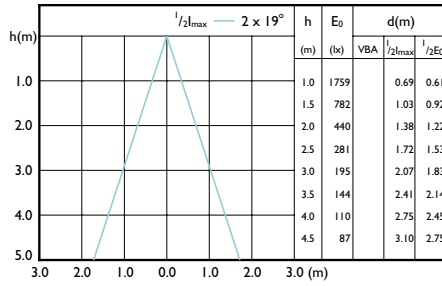


LEDspots N DIM 10W PAR38 E26 927 40D-LBP

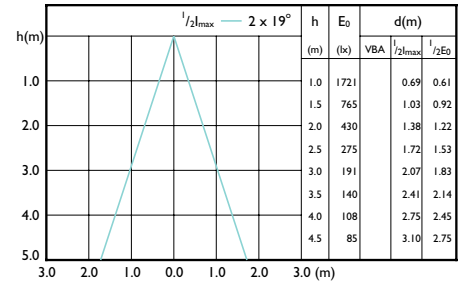


LEDspots N DIM 10W PAR38 E26 930 40D-LBP

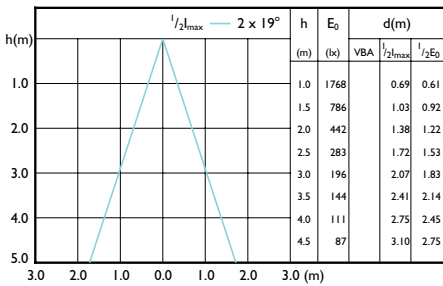


LEDspots N DIM 10W PAR38 E26 940 40D-LBP

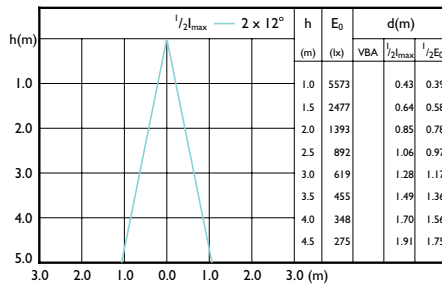


LEDspots N DIM 13W PAR38 E26 927 25D-LBP

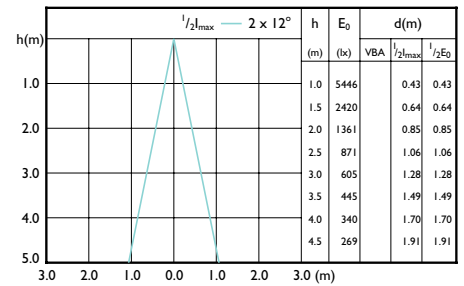


LEDspots N DIM 13W PAR38 E26 930 25D-LBP

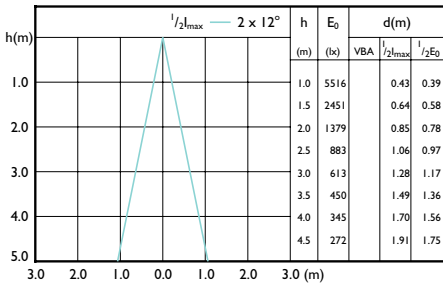


LEDspots N DIM 13W PAR38 E26 940 25D-LBP

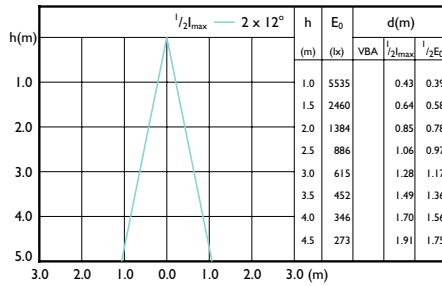


LEDspots N DIM 13W PAR38 E26 950 25D-LBP

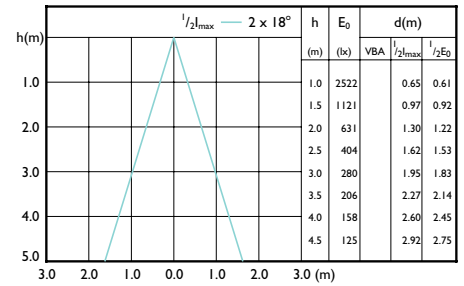


LEDspots N DIM 13W PAR38 E26 927 40D-LBP

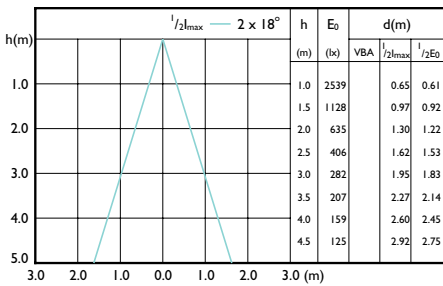

LEDspots N DIM 13W PAR38 E26 930 40D-LBP

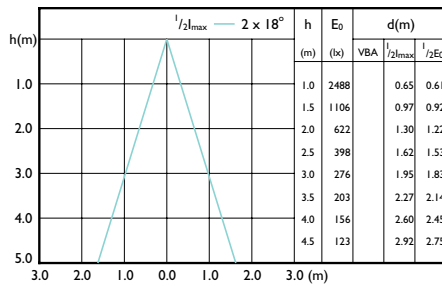


LEDspots N DIM 13W PAR38 E26 940 40D-LBP

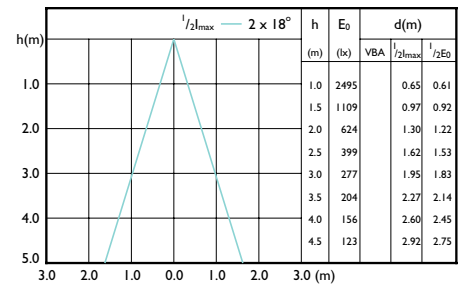


LEDspots N DIM 13W PAR38 E26 950 40D-LBP

LED PAR38


Beam Diagrams

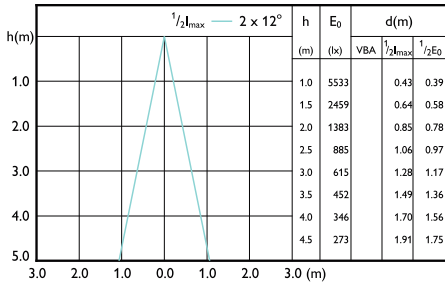

LESSpots BH 14W PAR38 E26 930 25D-LBP

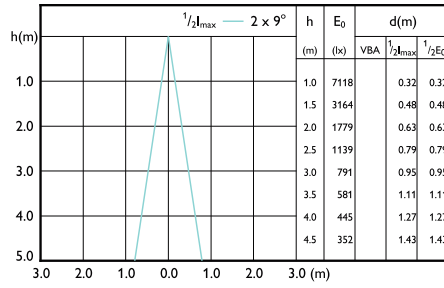

Beam Diagram

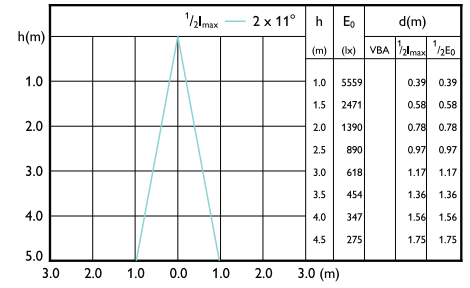

Beam Diagram

