


54151MSBA

By TradeSelect
Catalog Number [54151MSBA](#)

4 In. Steel Stud Octagon Box, 1-1/2 in. Deep, 15 Cu. In., with MSB Metal Stud Bracket, for 2-3/8 and 3-5/8 in. Stud Size, 1/2 in. KO, Cable Pryouts Ends, Raised Ground Screw, AC90 (25-Pack).

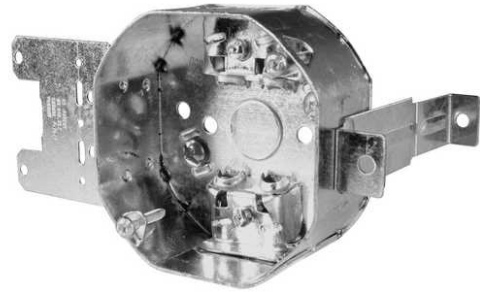

Application

Steel stud boxes are used in Commercial, Residential and Industrial construction.

General

Bracket Setback	0.4375
Bracket Type	MSB, for Steel Stud
Color	<ul style="list-style-type: none"> • Gray • Gris
Drawn or Welded	Welded
Ends Cable	8
Gangable	No
Knockouts	1 x 1/2 in
Knockouts - Bottom	1 x 1/2in
Material	Steel
Number of Gang(s)	1-Gang
Plaster Ears	No
Type	Octagonal Box, Box
Wiring System	Armoured Cable (AC) 14/2 8/3

Dimensions

Actual Depth	1.5 in
Raised Ground	Yes
Weight	0.52 lb

Conductor Related

Cable Entry	AC clamp
-------------	----------

Certifications and Compliance

Certified Listed	CSA
------------------	-----

Logistics

Carton Quantity	25
Pallet Quantity	875

Product Assets

[3D Product View](#)

