


Compression Splice

By Burndy
Catalog # YSP39T

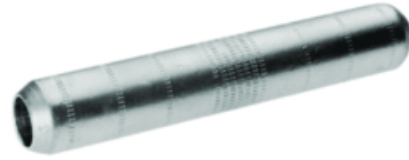

750 kcmil CU, Tapered End, Internal Chamfer, Tin Plated,
UL/CSA, 90°C, Up to 35kV, BLACK Color Code, 24 Die Index.

Application

Wire Splice

General

Color Code	Black
Connector Type	LONG BARREL
Die Index	24
EU RoHS Indicator	Yes
Feature - Barrel Style	Tapered
Feature - Barrel Type	Standard
Finish Type	Tin-Plated
Material	COPPER
Plated	Y
Plating Type	Electro Tin plated
Sub Brand	HYLINK
Trade Name	HYLINK™
Type	YSP-T, High Voltage, Long Barrel
UPC	781810001349

Dimensions

Dimension - B Length inch	2.03 in
Dimension - L Length Overall mm	106 mm
Dimension - Length Overall inch	4.19 in
Dimension - Strip Length inch	2-1/8 in

Electrical Ratings

Voltage Rating	35 kV
----------------	-------

Conductor Related

Conductor - Copper Str Size	750 kcmil
Conductor - Copper Str Size Range	750 kcmil
Conductor - Material	COPPER
Conductor Size	750 KCMIL
Conductor Type	CODE
Wire Size	750 kcmil

Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	15
Minimum Pack Quantity	1
Pallet Quantity	2220

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - sc20445-01](#)