


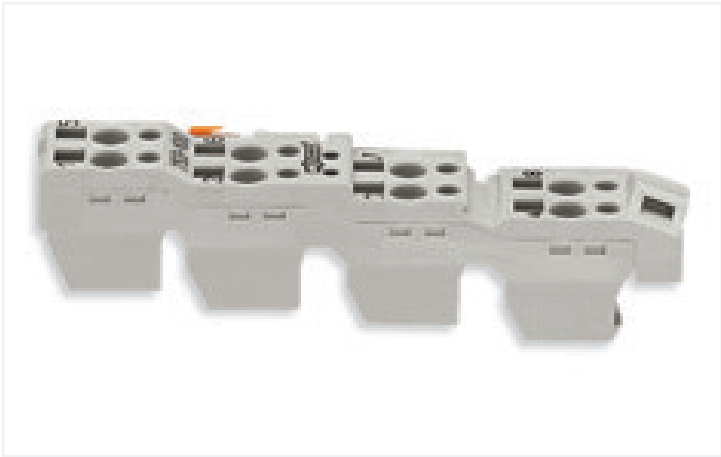

Color: light gray

Technical data		
Rated current		10 A
Connection data		
Solid conductor		0.08 ... 2.5 mm² / 28 ... 14 AWG
Fine-stranded conductor		0.08 ... 2.5 mm² / 28 ... 14 AWG
Strip length		9 ... 10 mm / 0.35 ... 0.39 inches
Physical data		
Width		12 mm / 0.472 inches
Depth		74.3 mm / 2.925 inches
Mechanical data		
Pluggable connector		pluggable
Material data		
Color		light gray
Fire load		0.204 MJ
Weight		11.2 g
Environmental requirements		
Ambient temperature (operation)		0 ... +55 °C
Ambient temperature (storage)		-25 ... +85 °C
Protection type		IP20



Commercial data		
Product Group	15 (I/O System)	
eCl@ss 10.0	27-24-26-92	
eCl@ss 9.0	27-24-26-92	
ETIM 8.0	EC002584	
ETIM 7.0	EC002584	
PU (SPU)	25 (1) pcs	
Packaging type	Box	
Country of origin	CN	
GTIN	4050821043928	
Customs tariff number	85366990990	

Environmental Product Compliance		
RoHS Compliance Status	Compliant, No Exemption	

Approvals / Certificates

General approvals			Approvals for marine applications		
					
Approval	Standard	Certificate Name	Approval	Standard	Certificate Name
UL Underwriters Laboratories Inc.	UL 1059	E45172	ABS American Bureau of Ship- ping	-	22-2219060
			BSH Bundesamt fuer See- schifffahrt und Hydrogra- phie	-	1104
			BV Bureau Veritas S.A.	-	13453/E0 BV
			DNV DNV GL SE	DNV-CG-0339,Aug.2021	TAA0000194
			KR Korean Register of Ship- ping	-	KR HMB05880-AC001
			LR Lloyds Register EMEA	-	LR22180952TA
			PRS Polski Rejestr Statków	-	TE/2236/880590/19
			RINA RINA Germany GmbH	-	ELE343521XG001

Downloads		
Environmental Product Compliance		



Compliance Search			
Environmental Product Compliance 753-110			↓

Documentation				
Manual			Bid Text	
System Manual WAGO I/O System 750/753	V 3.3.3 29.08.2023	pdf 8512.61 KB	753-110	↓
			09.01.2019	docx 13.23 KB ↓
			753-110	↓
			19.02.2019	xml 2.99 KB ↓

CAD/CAE-Data		
CAD data		CAE data
2D/3D Models 753-110		EPLAN Data Portal 753-110
↓		↓
		WSCAD Universe 753-110
		↓
		ZUKEN Portal 753-110
		↓