








shunt trip left 110-127V AC 50/60Hz/DC accessory for: 3VA4/5/6

Model			
product brand name	SENTRON		
product designation	Accessories		
design of the product	auxiliary release		
accessories	Auxiliary release		
General technical data			
degree of pollution	3		
overvoltage category	III		
apparent power consumption / maximum	40 VA		
consumed active power / at DC / maximum	40 W		
Voltage			
surge voltage resistance	4 kV		
Mechanical Design			
height	65.1 mm		
width	25.7 mm		
number of slots	3		
depth	31.2 mm		
net weight	91 g		
tightening torque / with screw-type terminals / minimum	0.4 N·m		
tightening torque / with screw-type terminals / maximum	0.5 N·m		
Connections according IEC			
stripped length	10 mm		
AWG number / as coded connectable conductor cross section / for auxiliary contacts			
• minimum	20		
• maximum	16		
Connections according UL			
stripped length [in]	0.4 in		
tightening torque [lbf·in] / with screw-type terminals / minimum	3.5 lbf·in		
tightening torque [lbf·in] / with screw-type terminals / maximum	4.4 lbf·in		
Certificates			
General Product Approval	EMC	Declaration of Conformity	
			
Miscellaneous			
UL	RCM	EG-Konf.	
Test Certificates	Marine / Shipping	other	Environment

Further information

Siemens has decided to exit the Russian market (see here).

<https://press.siemens.com/global/en/pressrelease/siemens-wind-down-russian-business>

Siemens is working on the renewal of the current EAC certificates.

Please contact your local Siemens office on the status of validity of the EAC certification if you intend to import or offer to supply these products to an EAC relevant market (other than the sanctioned EAEU member states Russia or Belarus).

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9978-0BL32>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9978-0BL32>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9978-0BL32


CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

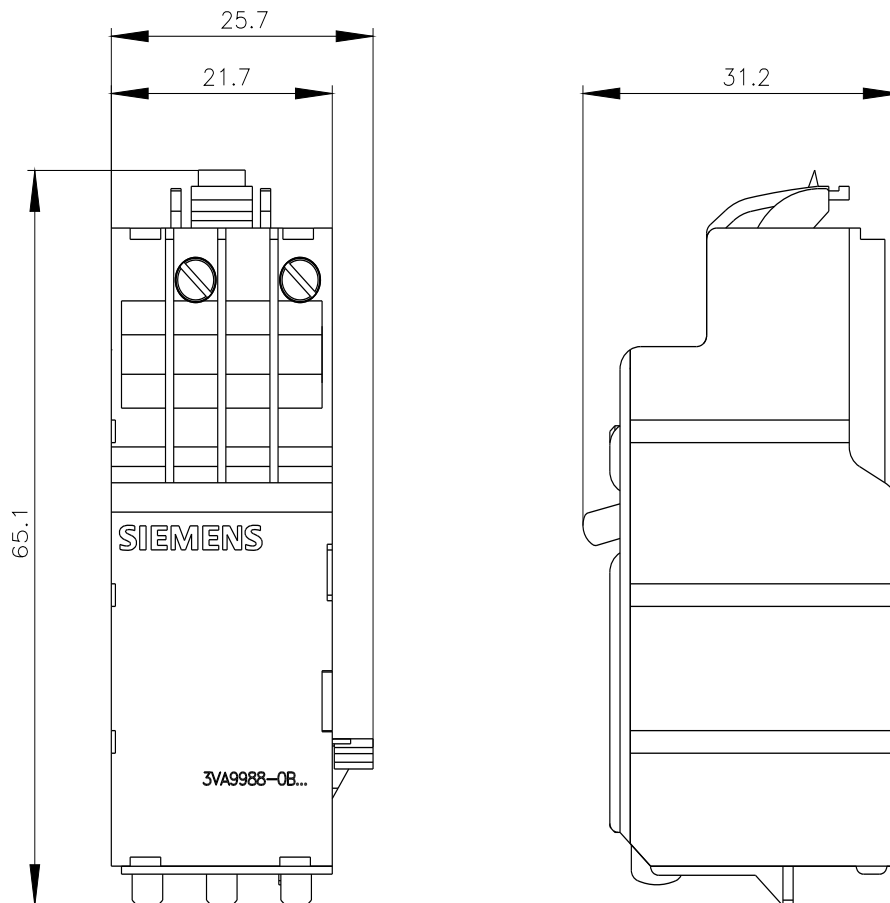

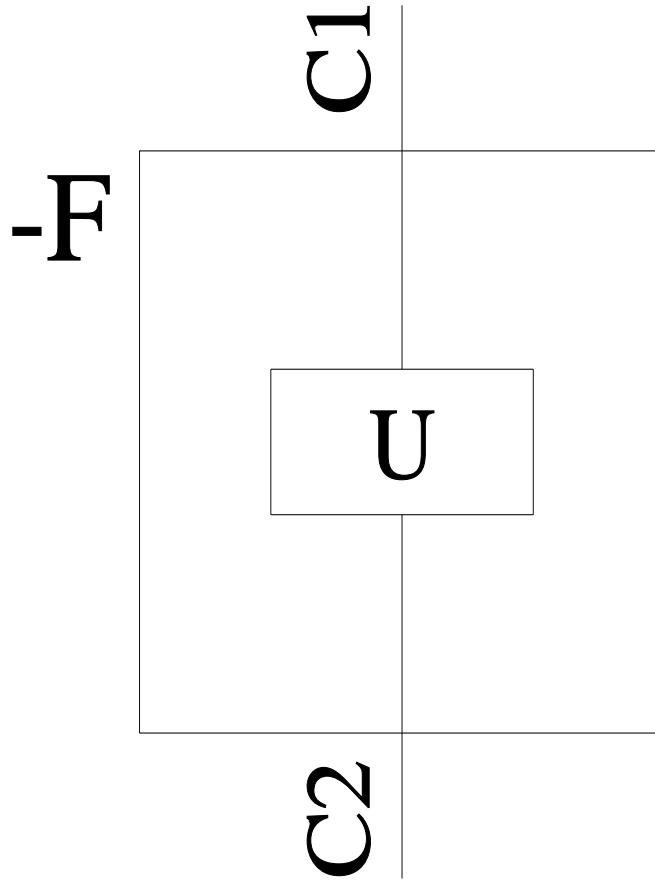

last modified:

8/15/2023 [↗](#)

