

CF

CEILING FAN HEATER



THE SPACE-SAVER

Stelpro has the perfect space-saving solution for heating small entryways, hallways and lobbies: the sturdy, reliable CF ceiling fan heater. Built to last, the CF pushes heat downward so that it mixes with the cold air below. It can be surface mounted or recessed into conventional ceilings or recessed in suspended ceilings. Whether installed in an entryway or hallway, the CF provides all the heat you need in an enclosed space.

- **GRILLE WITH ROUNDED SIDES**
DURABLE AND STYLISH
- **THE PERFECT SOLUTION FOR ENTRYWAYS AND HALLWAYS**
- **CEILING MOUNTED**
PREVENTS VANDALISM
- **MULTIPLE INSTALLATION OPTIONS**
CAN BE SURFACE MOUNTED OR RECESSED – OR RECESSED IN A SUSPENDED CEILING
- **OPTIONAL DISCONNECT SWITCH AVAILABLE**



ROUNDED SIDES

IDEAL FOR:

entryway, hallway, corridor, office building

COLOURS

- **standard:** white, soft white
- **Orora (optional):** refer to www.stelpro.com/en-CA/Orora

FINISH

- epoxy-polyester powdercoat

MANUFACTURING

- 20-gauge steel cabinet and 18-gauge steel grille
- fan: 1 x 160 CFM (single unit) – 2 x 160 CFM (double unit)
- closed and permanently lubricated motor
- thermal protection with automatic reset

ELEMENT

- nichrome element producing instant heat

CONTROL

- connection of multiple units to the same thermostat is possible with a relay kit without transformer (optional) and an external transformer (not provided)
- built-in thermostat (optional), 3 control knobs included (white, soft white and black) for standard installation, without knob for tamper-proof installation

INSTALLATION

- ceiling
- recessed or surface mounted with surface adapter (optional)
- T-Bar adapter (optional)

WARRANTY

- three years

°STELPRO

Stelpro reserves the right to modify descriptions, manufacturing specifications or prices without prior notice. No returns accepted on optional-colour products. For all the latest models and prices, please refer to our website at www.stelpro.com.



FC_CF_EN_200623

TECHNICAL SPECIFICATIONS

WITHOUT CONTROL	BUILT-IN THERMOSTAT	240 V CONTROL	24 V CONTROL	POWER	VOLTAGE	WEIGHT		MODEL
CODE	CODE	CODE	CODE	WATTS	VOLTS	KG	LB	UNIT
CF1501	CF1501T	---	CF1501C24	1500	120	9	20	SINGLE
CF1508	CF1508T	CF1508C	CF1508C24	1500	208	9	20	SINGLE
CF1502	CF1502T	CF1502C	CF1502C24	1500/1125	240/208	9	20	SINGLE
CF1503	CF1503T	CF1503C	CF1503C24	1500	347	9	20	SINGLE
---	CF1506T	CF1506C	CF1506C24	1500	600	10	22	SINGLE
CF2008	CF2008T	CF2008C	CF2008C24	2000	208	9	20	SINGLE
CF2002	CF2002T	CF2002C	CF2002C24	2000/1500	240/208	9	20	SINGLE
CF2003	CF2003T	CF2003C	CF2003C24	2000	347	9	20	SINGLE
---	CF2006T	CF2006C	CF2006C24	2000	600	10	22	SINGLE
CF3008	CF3008T	CF3008C	CF3008C24	3000	208	9	20	SINGLE
CF3002	CF3002T	CF3002C	CF3002C24	3000/2250	240/208	9	20	SINGLE
CF3003	CF3003T	CF3003C	CF3003C24	3000	347	9	20	SINGLE
---	CF3006T	CF3006C	CF3006C24	3000	600	10	22	SINGLE
CF4008	CF4008T	CF4008C	CF4008C24	4000	208	9	20	SINGLE
CF4002	CF4002T	CF4002C	CF4002C24	4000/3000	240/208	9	20	SINGLE
CF4003	CF4003T	CF4003C	CF4003C24	4000	347	9	20	SINGLE
---	CF4006T	CF4006C	CF4006C24	4000	600	10	22	SINGLE
---	CF6008CT	CF6008C	CF6008C24	6000	208	18	40	DOUBLE
---	CF6002T	CF6002C	CF6002C24	6000/4500	240/208	18	40	DOUBLE
---	CF6003T	CF6003C	CF6003C24	6000	347	18	40	DOUBLE
---	CF6006T	CF6006C	CF6006C24	6000	600	20	44	DOUBLE
---	CF8008CT	CF8008C	CF8008C24	8000	208	18	40	DOUBLE
---	CF8002CT	CF8002C	CF8002C24	8000/6000	240/208	18	40	DOUBLE
---	CF8003CT	CF8003C	CF8003C24	8000	347	18	40	DOUBLE
---	CF8006CT	CF8006C	CF8006C24	8000	600	20	44	DOUBLE

Add W for white or SW for soft white (consult the optional colours chart or contact your Stelpro representative for all other colours).

Models also available in 277 V and 480 V.

--- not available

ACCESSORIES

PRODUCT	DESCRIPTION
WFT1	built-in single pole thermostat [120 V-600 V] (standard or tamper-proof)
WFT2	built-in double pole thermostat [120 V-600 V] (standard or tamper-proof)
WFS A1*	surface adapter (single unit)
WFS A2*	surface adapter (double unit)
WFDIS-30*	disconnect switch kit 600 V/30 A, 2 poles
WFDIS-40*	disconnect switch kit 600 V/40 A, 2 poles/3 poles
WFDIS-60*	disconnect switch kit 600 V/60 A, 2 poles/3 poles
CFTBA1*	T-Bar adapter (single unit)
CFTBA2*	T-Bar adapter (double unit)
WFC24RX*	relay kit without transformer 24 V

* Add W for white or SW for soft white.


* Factory installation

THROW DISTANCE AND HEAT RISE

UNITS	THROW DISTANCE		HEAT RISE	
KW	M	FT	°C	°F
1.5	4.1	13'7"	17	30
2	4.1	13'7"	22	40
3	4.1	13'7"	33	59
4	4.1	13'7"	44	79
6	4.1	13'7"	33	59
8	4.1	13'7"	44	79
9	4.1	13'7"	33	59
12	4.1	13'7"	44	79

TECHNICAL DRAWINGS

SINGLE UNIT

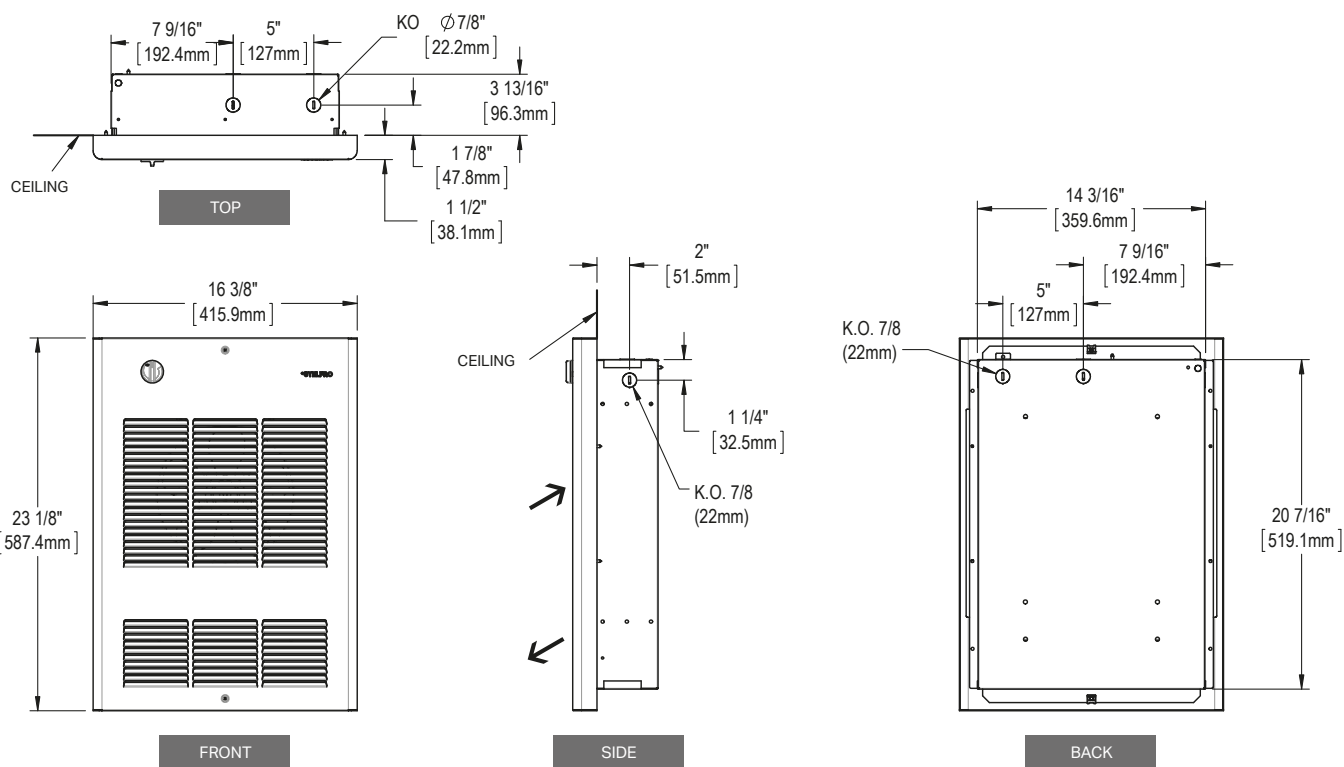

DOUBLE UNIT

