

RWF | PULSAIR™

WALL FAN HEATER



PULSAIR™

THE CLASSIC FAN HEATER

You won't find anything better than this efficient, durable and low noise fan heater. The Pulsair is extremely popular for many reasons. First, it can be recessed or surface mounted with a surface adapter (optional). It can also be mounted vertically or horizontally so that air can flow either up and down or right and left. Finally, the slim-line Pulsair can be recessed into a wall thickness of 2 in. to 3 in. While it's a winning heating solution for hallways or bathrooms, it can also be installed anywhere in the house, such as the office, or in commercial spaces. Its nichrome element provides instant heat. Available from 500 W to 2000 W, and from 120 V to 347 V, the Pulsair is recognized and recommended by those in the know.

■ VERY QUIET FAN HEATER

■ THE MOST RESISTANT GRILLE ON THE MARKET

■ INSTANT HEAT NICHROME ELEMENT

■ MULTIPLE INSTALLATION OPTIONS RECESSED, SURFACE MOUNTED, HORIZONTAL OR VERTICAL

■ ADAPTS TO MULTIPLE MARKETS AVAILABLE IN: 120 V, 208 V, 240 V AND 347 V

COLOURS

- **standard:** white, soft white
- **Orora (optional):** refer to www.stelpro.com/en-CA/Orora

FINISH

- epoxy-polyester powdercoat

MANUFACTURING

- 20-gauge steel cabinet and 18-gauge steel grille
- quiet fan – 40 CFM (500 W to 1000 W models) – 75 CFM (1250 W to 2000 W models)
- thermal protection with automatic reset

ELEMENT

- nichrome element produces instant heat

CONTROL

- built-in thermostat (optional), 3 control knobs included (white, soft white and black)
- wall thermostat (not included) – the use of an electronic thermostat is strongly recommended


INSTALLATION

- wall mounted
- recessed (wall must have a depth of 2 3/8 in. minimum)
- surface mounted with surface adapter (optional)
- four installation positions

WARRANTY

- five years

FOUR INSTALLATION OPTIONS

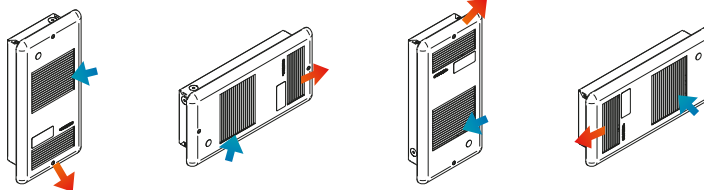

IDEAL FOR:

hallway, bathroom, locker room, office

°STELPRO

Stelpro reserves the right to modify descriptions, manufacturing specifications or prices without prior notice. No returns accepted on optional-colour products. For all the latest models and prices, please refer to our website at www.stelpro.com.



FC_RWF_EN_020623

TECHNICAL SPECIFICATIONS

WITHOUT CONTROL	BUILT-IN THERMOSTAT	24 V CONTROL	POWER	VOLTAGE	FLOW	THROW DISTANCE	HEAT RISE	WEIGHT
CODE	CODE	CODE	WATTS	VOLTS	CFM	M FT.	°C °F	KG LB
RWF0501	---	---	500	120	40	2 6'6"	22 39	2.7 6
RWF0508	---	---	500	208	40	2 6'6"	22 39	2.7 6
RWF0502	---	---	500/375	240/208	40	2 6'6"	22 39	2.7 6
RWF0503	RWF0503T	RWF0503C24	500	347	40	2 6'6"	22 39	2.7 6
RWF0751	---	---	750	120	40	2 6'6"	33 59	2.7 6
RWF0758	---	---	750	208	40	2 6'6"	33 59	2.7 6
RWF0752	---	---	750/563	240/208	40	2 6'6"	33 59	2.7 6
RWF0753	RWF0753T	RWF0753C24	750	347	40	2 6'6"	33 59	2.7 6
RWF1001	---	---	1000	120	40	2 6'6"	44 79	2.7 6
RWF1008	---	---	1000	208	40	2 6'6"	44 79	2.7 6
RWF1002	---	---	1000/750	240/208	40	2 6'6"	44 79	2.7 6
RWF1003	RWF1003T	RWF1003C24	1000	347	40	2 6'6"	44 79	2.7 6
RWF1251	---	---	1250	120	75	2.1 6'10"	29 53	2.7 6
RWF1258	---	---	1250	208	75	2.1 6'10"	29 53	2.7 6
RWF1252	---	---	1250/938	240/208	75	2.1 6'10"	29 53	2.7 6
RWF1253	RWF1253T	RWF1253C24	1250	347	75	2.1 6'10"	29 53	2.7 6
RWF1501	---	---	1500	120	75	2.1 6'10"	35 63	2.7 6
RWF1508	---	---	1500	208	75	2.1 6'10"	35 63	2.7 6
RWF1502	---	---	1500/1125	240/208	75	2.1 6'10"	35 63	2.7 6
RWF1503	RWF1503T	RWF1503C24	1500	347	75	2.1 6'10"	35 63	2.7 6
---	---	---	2000	120	75	2.1 6'10"	47 89	2.7 6
RWF2002	---	---	2000/1500	240/208	75	2.1 6'10"	47 89	2.7 6
RWF2008	---	---	2000	208	75	2.1 6'10"	47 89	2.7 6
RWF2003	RWF2003T	RWF2003C24	2000	347	75	2.1 6'10"	47 89	2.7 6


Add W for white or SW for soft white (consult the optional colours chart or contact your Stelpro representative for all other colours).
Models also available in 277 V. --- not available

ACCESSORIES

PRODUCT	DESCRIPTION
RWFT1*	built-in single pole thermostat [120 V-347 V]
RWFT2	built-in double pole thermostat [120 V-347 V]
RWFSA*	surface adapter

* Add W for white or SW for soft white.

TECHNICAL DRAWINGS

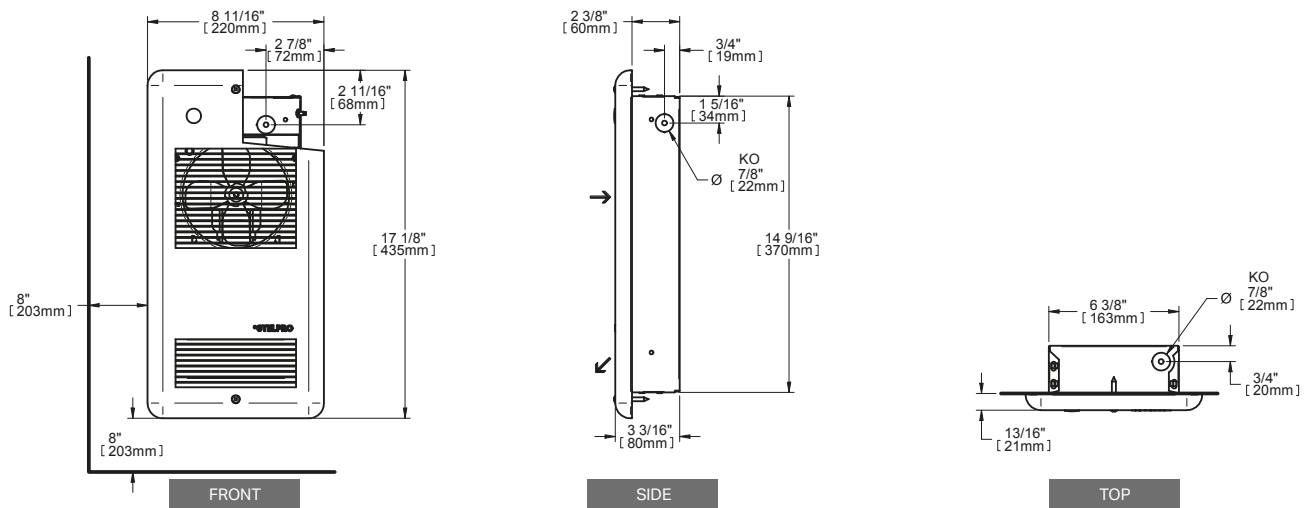

Stelpro reserves the right to modify descriptions, manufacturing specifications or prices without prior notice. No returns accepted on optional-colour products.
For all the latest models and prices, please refer to our website at www.stelpro.com.