

WFA | ALUX™

ALUMINUM WALL FAN HEATER



WHEN DURABILITY AND PERFORMANCE MEET DESIGN

In need of a solid, stylish heater to warm your clients in the lobby or entrance of your business? The Alux series wall fan heater (WFA) with its remarkable rush of warm air is the solution. It has an aluminum extrusion grille that is striking, modern and unbelievably resistant. Imagine no more dents or rust! The WFA is suitable for recessed installation or can be surface mounted on a wall and is available in a large array of wattages to meet all your needs.

- **EXTRUDED ALUMINUM PROFILE WITH A UNIQUE, LUXURY DESIGN**
- **EXTREMELY SOLID, IMPACT AND RUST RESISTANT**
- **WIDE RANGE OF MODELS AND HEATING CAPACITIES INCLUDING A SINGLE 4800 W MODEL**
- **SIGNATURE NICHROME ELEMENT OFFERS SUPERIOR PERFORMANCE AND IMMEDIATE HEAT**

COLOURS

- **standard:** white, soft white
- **Orora (optional):** refer to www.stelpro.com/en-CA/Orora

FINISH

- epoxy-polyester powdercoat

MANUFACTURING

- 22-gauge steel cabinet
- extruded aluminum grille with a thickness equivalent to 13 gauge
- top air intake with bottom air discharge
- quiet helicoidal fan: single unit 1 x 160 CFM – double unit 2 x 160 CFM – triple unit 3 x 160 CFM
- closed and permanently lubricated motor
- thermal protection with automatic reset

ELEMENT

- high-quality nichrome element producing instant heat

CONTROL

- connection of multiple units to the same thermostat is possible with a relay kit without transformer (optional) and an external transformer (not provided)
- built-in thermostat (optional), 3 control knobs included (white, soft white and black) for standard installation, without knob for tamper-proof installation

INSTALLATION

- wall mounted
- recessed or surface mounted with surface adapter (optional)

WARRANTY

- three years

IDEAL FOR:

lobby, entrance, corridor, factory, warehouse, stairwell



Stelpro reserves the right to modify descriptions, manufacturing specifications or prices without prior notice. No returns accepted on optional-colour products. For all the latest models and prices, please refer to our website at www.stelpro.com.



TECHNICAL SPECIFICATIONS

WITHOUT CONTROL	BUILT-IN THERMOSTAT	240 V CONTROL	24 V CONTROL	POWER	VOLTAGE	WEIGHT		MODEL
CODE	CODE	CODE	CODE	WATTS	VOLTS	KG	LB	UNIT
WFA1501	WFA1501T	---	WFA1501C24	1500	120	9.1	20	SINGLE
WFA1508	WFA1508T	WFA1508C	WFA1508C24	1500	208	9.1	20	SINGLE
WFA1502	WFA1502T	WFA1502C	WFA1502C24	1500/1125	240/208	9.1	20	SINGLE
WFA1503	WFA1503T	WFA1503C	WFA1503C24	1500	347	9.1	20	SINGLE
---	WFA1506T	WFA1506C	WFA1506C24	1500	600	12	27	SINGLE
WFA2008	WFA2008T	WFA2008C	WFA2008C24	2000	208	10.4	23	SINGLE
WFA2002	WFA2002T	WFA2002C	WFA2002C24	2000/1500	240/208	10.4	23	SINGLE
WFA2003	WFA2003T	WFA2003C	WFA2003C24	2000	347	10.4	23	SINGLE
---	WFA2006T	WFA2006C	WFA2006C24	2000	600	12	27	SINGLE
WFA3008	WFA3008T	WFA3008C	WFA3008C24	3000	208	10.4	23	SINGLE
WFA3002	WFA3002T	WFA3002C	WFA3002C24	3000/2250	240/208	10.4	23	SINGLE
WFA3003	WFA3003T	WFA3003C	WFA3003C24	3000	347	10.4	23	SINGLE
---	WFA3006T	WFA3006C	WFA3006C24	3000	600	12	27	SINGLE
WFA4008	WFA4008T	WFA4008C	WFA4008C24	4000	208	10.4	23	SINGLE
WFA4002	WFA4002T	WFA4002C	WFA4002C24	4000/3000	240/208	10.4	23	SINGLE
WFA4003	WFA4003T	WFA4003C	WFA4003C24	4000	347	10.4	23	SINGLE
---	WFA4006T	WFA4006C	WFA4006C24	4000	600	12	27	SINGLE
WFA4808	WFA4808T	WFA4808C	WFA4808C24	4800	208	10.4	23	SINGLE
WFA4802	WFA4802T	WFA4802C	WFA4802C24	4800/3600	240/208	10.4	23	SINGLE
WFA4803	WFA4803T	WFA4803C	WFA4803C24	4800	347	10.4	23	SINGLE
---	WFA4806T	WFA4806C	WFA4806C24	4800	600	12	27	SINGLE
---	WFA6008CT	WFA6008C	WFA6008C24	6000	208	20	44	DOUBLE
---	WFA6002T	WFA6002C	WFA6002C24	6000/4500	240/208	20	44	DOUBLE
---	WFA6003T	WFA6003C	WFA6003C24	6000	347	20	44	DOUBLE
---	WFA6006T	WFA6006C	WFA6006C24	6000	600	22	48	DOUBLE
---	WFA60083CT*	WFA60083C*	WFA60083C24*	6000	208	36	80	TRIPLE
---	WFA60063CT*	WFA60063C*	WFA60063C24*	6000	600	36	80	TRIPLE
---	WFA8008CT	WFA8008C	WFA8008C24	8000	208	20	44	DOUBLE
---	WFA8002CT	WFA8002C	WFA8002C24	8000/6000	240/208	20	44	DOUBLE
---	WFA8003CT	WFA8003C	WFA8003C24	8000	347	20	44	DOUBLE
---	WFA8006CT	WFA8006C	WFA8006C24	8000	600	22	48	DOUBLE
---	WFA90083CT*	WFA90083C*	WFA90083C24*	9000	208	36	80	TRIPLE
---	WFA90063CT*	WFA90063C*	WFA90063C24*	9000	600	36	80	TRIPLE
---	WFA12008CT	WFA12008C	WFA12008C24	12 000	208	36	80	TRIPLE
---	WFA12002CT	WFA12002C	WFA12002C24	12 000/9000	240/208	36	80	TRIPLE
---	WFA12003CT	WFA12003C	WFA12003C24	12 000	347	36	80	TRIPLE
---	WFA12006CT	WFA12006C	WFA12006C24	12 000	600	36	80	TRIPLE
---	WFA120083CT*	WFA120083C*	WFA120083C24*	12 000	208	36	80	TRIPLE
---	WFA120063CT*	WFA120063C*	WFA120063C24*	12 000	600	36	80	TRIPLE

Add W for white or SW for soft white (consult the optional colours chart or contact your Stelpro representative for all other colours).

* Three-phase unit

Models also available in 277 V and 480 V. --- not available

ACCESSORIES

PRODUCT	DESCRIPTION
WFAT1	built-in single pole thermostat [120 V-600 V] (standard or tamper-proof)
WFAT2	built-in double pole thermostat [120 V-600 V] (standard or tamper-proof)
WFASA1*	surface adapter (single unit)
WFASA2*	surface adapter (double unit)
WFASA3*	surface adapter (triple unit)
WFADIS-30*	disconnect switch kit 600 V/30 A, 2 poles
WFADIS-40*	disconnect switch kit 600 V/40 A, 2 poles/3 poles
WFADIS-60*	disconnect switch kit 600 V/60 A, 2 poles/3 poles
WFC24RX*	relay kit without transformer 24 V

* Add W for white or SW for soft white.

* Factory installation




THROW DISTANCE AND HEAT RISE


UNITS	THROW DISTANCE		HEAT RISE	
	M	FT	°C	°F
1.5	4.1	13'7"	17	30
2	4.1	13'7"	22	40
3	4.1	13'7"	33	59
4	4.1	13'7"	44	79
4.8	4.1	13'7"	53	95
6	4.1	13'7"	33	59
8	4.1	13'7"	44	79
9	4.1	13'7"	33	59
12	4.1	13'7"	44	79

TECHNICAL DRAWINGS

SINGLE UNIT

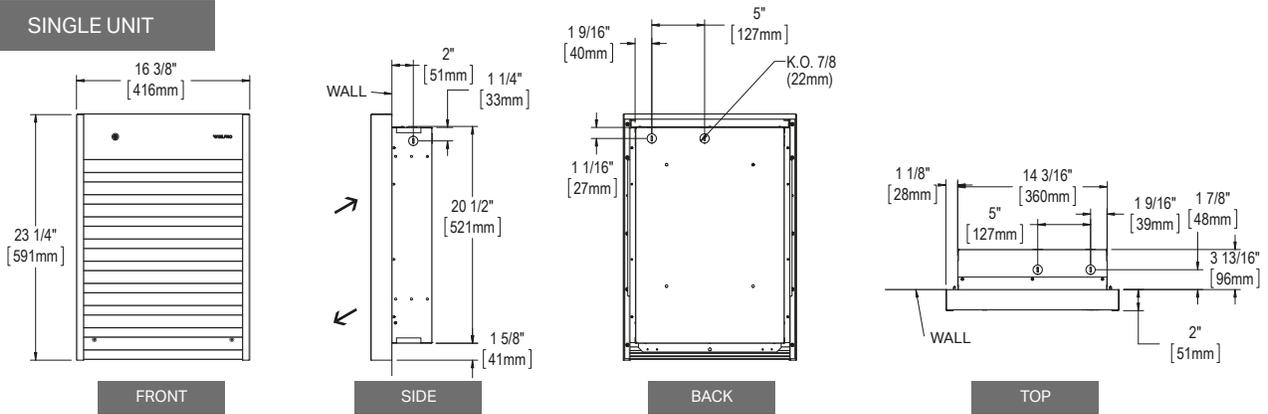

DOUBLE UNIT

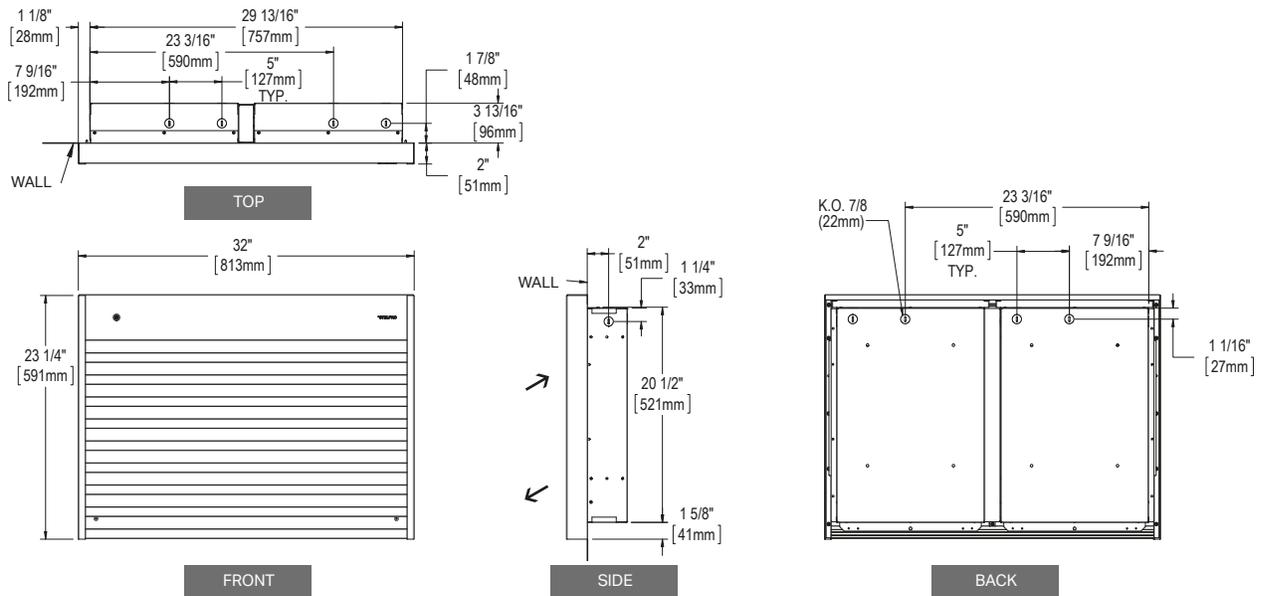

TRIPLE UNIT

